


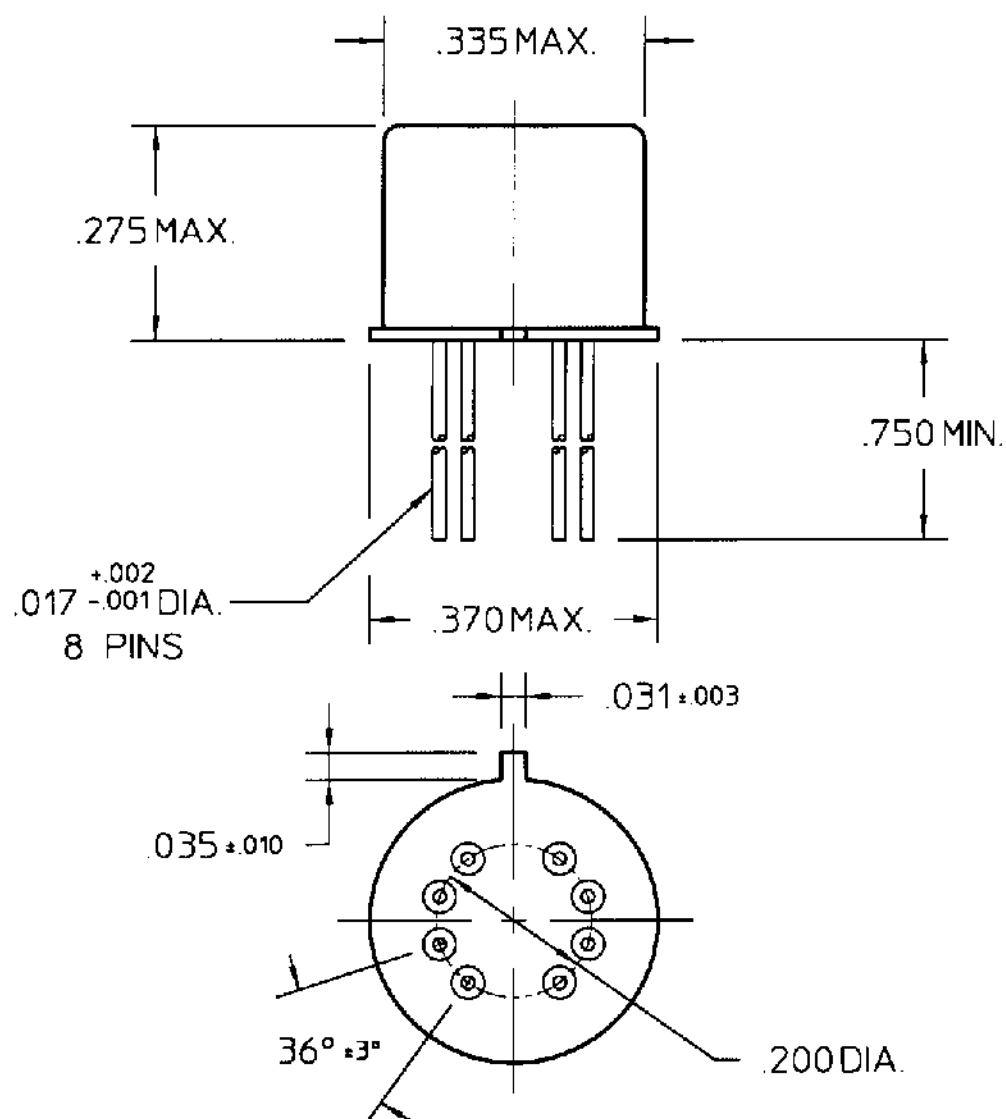

REV 2 11/21/97

COIL:

RESISTANCE 390 OHMS $\pm$ 10%

NOMINAL VOLTAGE 12.0 VDC

MUST OPERATE 8.4 VDC

MUST RELEASE

ENVIRONMENT:


VIBRATION 10 CPS TO 500 CPS @ 10 g's

SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 6.0 MS MAX.

CUSTOMER DATA SHEET

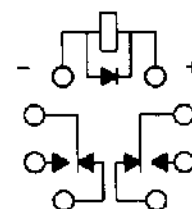

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 1/15/92 *CK* 11/21/97

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I. STD.

CUST. NO.

TYPE HMD RELAY

HMD-12B