

DTS26F15-97SN [V001] ✓ ACTIVE

TE Internal #: YDTS26F15-97SNV001

TE Internal Description: PLUG ASSY

Mil-Spec: [D38999/26FD97SN]

Straight Plug: D38999, 15-97 Insert, Electroless Nickel Plating

[View on TE.com >](#)



All Straight Plug: D38999, 15-97 Insert, Electroless Nickel Plating (0)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2024 (240) SVHC > Threshold: Pb (1.2% in Contact Lead-Copper Alloy) Decamethylcyclpentasiloxane (D5) (5% in Insert subassembly) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # YDTS21H15-97XNV001
HERM RECP



TE Part # YDTS20N15-97PNV001
HERM RECP



TE Part # YDTS20N15-97CNV001
HERM RECP



TE Part # YDTS23H15-97XNV001
HERM RECP




TE Part # YDTS23H15-97CNV001
HERM RECP



TE Part # DTS24N15-97PN
HERM RECP



TE Part # YDTS23N15-97XNV001
HERM RECP

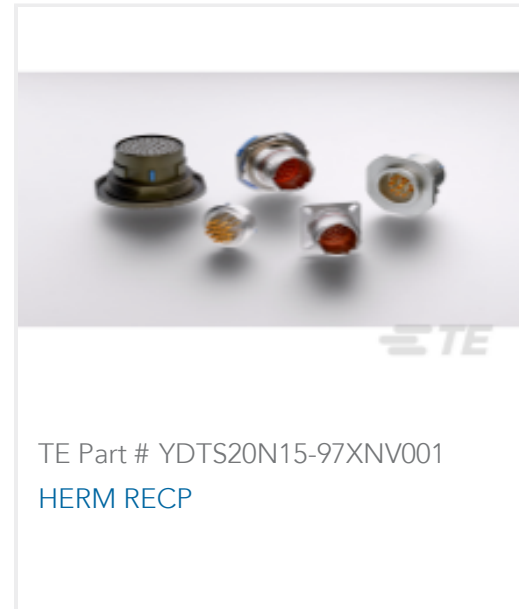

TE Part # YDTS20N15-97XNV001
HERM RECP




TE Part # YDTS23N15-97PNV001
HERM RECP




TE Part # YDTS20Y15-97PN0000
HERM RECP



TE Part # CAT-D38999-DTS1L
D38999: Square Flange, 15-97 insert

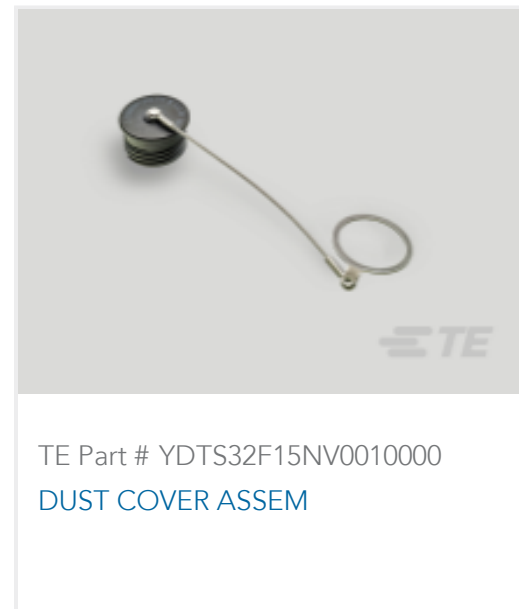

TE Part # YDTS32F15NV0010000
DUST COVER ASSEM



TE Part # YDTS21N15-97PNV001
HERM RECP



TE Part # YDTS24N15-97XNV001
HERM RECP



TE Part # YDTS23N15-97CNV001
HERM RECP



TE Part # YDTS21N15-97XNV001
HERM RECP



TE Part # YDTS21Y15-97XNV001
HERM RECP



TE Part # YDTS24Y15-97CNV001
HERM RECP



TE Part # YDTS20Y15-97XNV001
HERM RECP



TE Part # CAT-D38999-DTS10E
D38999: Jam Nut, 15-97 Insert,
Electroless Nickel Plating

Customers Also Bought



TE Part #5510320002
PD-CAP-1/8-0



TE Part #CN1021-000
D-436-37-COLD



TE Part #5-446405-1
AMPLIMITE PLUG ASSY,SZ 4,COAX 8C8



 
TE Part #1-770246-0
UMNL II PIN AUNIPHZ LP 12-10




TE Part #1-770252-0
UMNL II PIN LP 14-18




TE Part #1658640-2
RECP. ASSEMBLY SIZE 5




TE Part #YCTJ722E01CC017000
MODULE ASSY

 

TE Part #YCTJ720E01BC017000
MODULE ASSY

 

TE Part #YCTJ716E01DC017000
MODULE ASSY

 

TE Part #CTJ716E01D-7067
MODULE ASSY

Documents

Datasheets & Catalog Pages

[DEUTSCH MIL-DTL-38999 CIRCULAR CONNECTORS](#)

English

[DEUTSCH DTS Series Connectors for 38999 QRG](#)

English