

DTS26W17-26PN [V001] ✓ ACTIVE

TE Internal #: YDTS26W17-26PNV001

TE Internal Description: PLUG ASSY

Mil-Spec: [D38999/26WE26PN]

D38999: Straight Plug, 17-26 Insert

[View on TE.com >](#)



All D38999: Straight Plug, 17-26 Insert (1)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Not Compliant
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-D38999-DTS15K
Jam Nut: D38999, 17-26 Insert




TE Part # CAT-D38999-DTS6U
D38999: Square Flange, 17-26 insert


Customers Also Bought



TE Part #YDTS26W23-35SNV001
PLUG ASSY

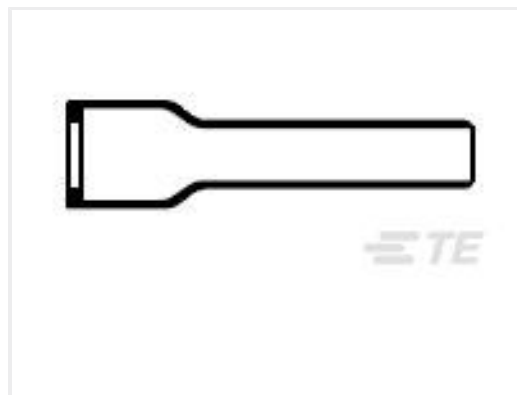


TE Part #807551-000
202D221-4/42-0

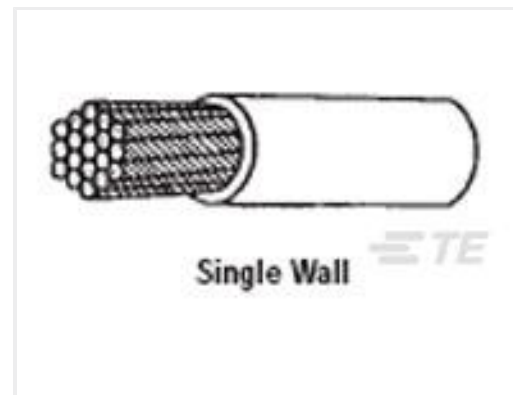

TE Part #562243-000
82A0111-16-9
Single Wall



 
TE Part #YDTS26W11-35PNV001
PLUG ASSY



TE Part #504791-000
303A021-4-0



TE Part #531872-000
S03-05-R

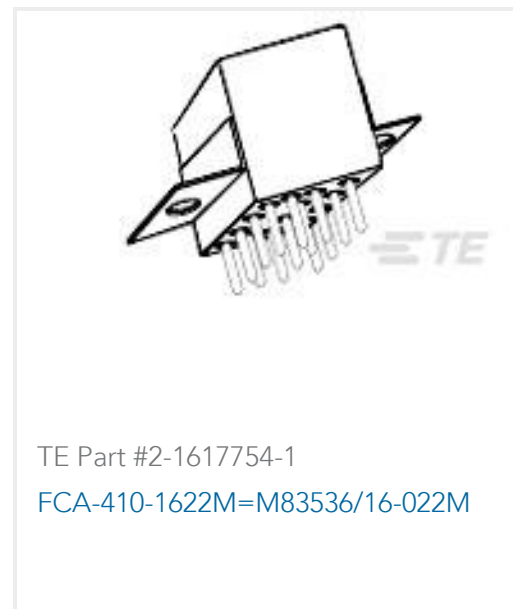


TE Part #2-1617754-1
FCA-410-1622M=M83536/16-022M



TE Part #1757824-6
AMPLIMITE,ASY,RCPT,STD,90,ZN,6



TE Part #2176347-8
CRGCO 2010 39R 1%

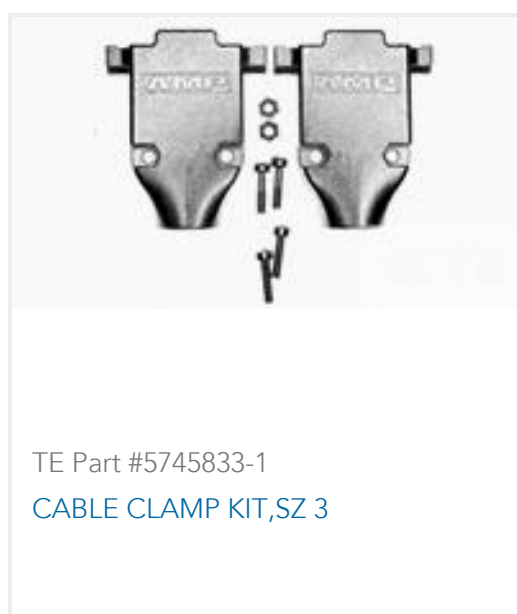

TE Part #5745833-1
CABLE CLAMP KIT,SZ 3

Documents

Datasheets & Catalog Pages

[DEUTSCH DTS Series Connectors for 38999 QRG](#)

English