

[Home](#) > [5511801F](#)


Search For

Part Number: **5511801F**

| General Description |                      |
|---------------------|----------------------|
| Series              | 551                  |
| Configuration       | 3 mm Lens            |
| Description         | 3 mm CBI Right Angle |
| Package Options     | Bulk Packaging       |
| Sizes               | 3mm                  |
| Lamp Type           | Single Housing       |
| Viewing             | Right Angle          |
| Polarity            | Cathode Left         |
| Lens Style          | Tinted, Diffused     |
| Viewing Angle       | 60                   |
| LED Centerline      | 5.0mm                |

| Absolute Maximum Ratings (Ta = 25Å °) |                |
|---------------------------------------|----------------|
| Reverse Current                       | 100 @ Vr = 4V  |
| Derating                              | 0.5 (mA/degC)  |
| Reverse Voltage                       | 4              |
| Solder Temperature                    | 260 for 5 secs |
| Operating Temperature                 | -40 to +100    |
| Storage Temperature                   | -55 to +100    |

| Operating Characteristics  |                 |
|----------------------------|-----------------|
| Color                      | Red             |
| LED Type                   | High Efficiency |
| Peak Wave Length           | 660             |
| Luminous Intensity Min     | 19              |
| Luminous Intensity Typical | 60              |
| Forward Voltage Typical    | 2.4             |
| Test Current mA            | 20mA            |
| Power Dissipation Max      | 100mW           |

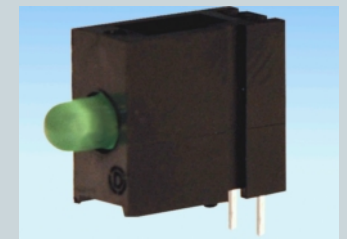

5511801F

[check stock](#)



[This is a  
RoHS Compliant Product.  
To learn more click here](#)