


Part Number: **5513207F**

General Description	
Series	551
Configuration	3 mm Lens
Description	3 mm CBI
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Single Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Untinted, Diffused
Viewing Angle	80
LED Centerline	5.08mm


Absolute Maximum Ratings (Ta = 25Å °)	
Solder Temperature	260 for 5 secs
Operating Temperature	-55 to +100
Storage Temperature	-55 to +100

Operating Characteristics		
Color	Red	Yellow
Peak Wave Length	630	585
Luminous Intensity Min	1.7	1.7
Luminous Intensity Typical	5.6	5.6
Forward Voltage Typical	2	2.1
Forward Voltage Max	2.8	2.8
Power Dissipation Max	100mW	60mW

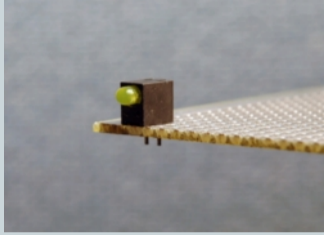

5513207F

[check stock](#)



[This is a RoHS Compliant Product](#)
[To learn more click here](#)