

[Home](#) > [5530127300F](#)

Search For Part Number

Part Number: **5530127300F**

General Description


Series	553
Configuration	3 mm Lens
Description	3 mm Bi-Level CBI
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Bi-Level Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Tinted, Diffused
Viewing Angle	45
LED Centerline	2.54mm

Absolute Maximum Ratings (Ta = 25)

Solder Temperature	260 for 5 secs
Operating Temperature	-25 to +85
Storage Temperature	-30 to +100

Operating Characteristics

	LED Position: 1	LED Position: 2
Color	Green	Orange
LED Type	High Efficiency	High Efficiency
Peak Wave Length	563	600
Luminous Intensity Min	5.6	3.4
Luminous Intensity Typical	16	7
Forward Voltage Typical	2.1	1.9
Forward Voltage Max	3	2.4
Power Dissipation Max	75mW	135mW

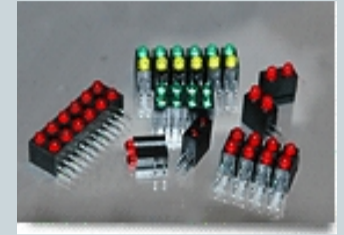

5530127300F

[check stock](#)



[This is a
RoHS Compliant Product
To learn more click here](#)