

[Home](#) > [5616002100F](#)

Search For Part Number

Part Number: **5616002100F**

General Description	
Color	White
Series	561
Configuration	5 mm Lens
Description	5 mm Stand -Off 1.000" WC Wht
Package Options	Bulk Packaging
Sizes	5mm
Lamp Type	Single Color
Viewing	Top View
Polarity	Cathode Right
Lens Style	Non - Diffused


Absolute Maximum Ratings (Ta = 25Å °)	
Derating	from 40Å° @ .5 mA/Å°C
Solder Temperature	260Å° for 5 sec
Operating Temperature	-30 to +85
Storage Temperature	-40 to +100

Operating Characteristics	
Color	White
LED Type	High Efficiency
Luminous Intensity Min	1.5
Luminous Intensity Typical	2.5
Luminous Intensity Max	4.25
Test Current mA	20mA
Emitted Color	White
Power Dissipation Max	120mW



5616002100F

[check stock](#)

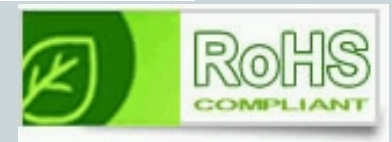

[This is a RoHS Compliant Product](#)
[To learn more click here](#)