

[Home](#) > [5642210123F](#)

Search For Part Number

Part Number: **5642210123F**

General Description


Series	564
Configuration	3 mm Lens
Description	3 mm Red/Green/Yellow Backlighting Tri -Level CBI Non -Diffused
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Tri-Level Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Tinted, Non -Diffused
Viewing Angle	60
LED Centerline	2.54mm

Absolute Maximum Ratings (Ta = 25Å °)

Solder Temperature	260 for 5 secs
Operating Temperature	-55 to +100
Storage Temperature	-55 to +100

Operating Characteristics

	LED Position: 1	LED Position: 2	LED Position: 3
Color	Red	Green	Yellow
LED Type	Standard Efficiency	Standard Efficiency	Standard Efficiency
Peak Wave Length	635	565	585
Luminous Intensity Min	8.7	32	10
Luminous Intensity Typical	29	50	
Forward Voltage Typical	2	2.1	2.1
Forward Voltage Max	2.8	2.8	2.8
Power Dissipation Max	100mW	100mW	60mW

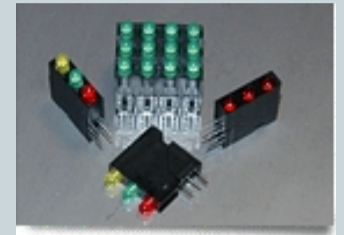

5642210123F

[check stock](#)



This is a
[RoHS Compliant Product](#)
[To learn more click here](#)