

# Product Selector Guide




## LED Vehicle Lighting

### MARKER LAMPS

13 Series


Fig. 1

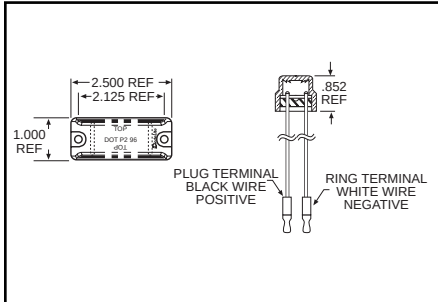

Smallest LED lamp available  
Low current draw

14 Series


Fig. 2

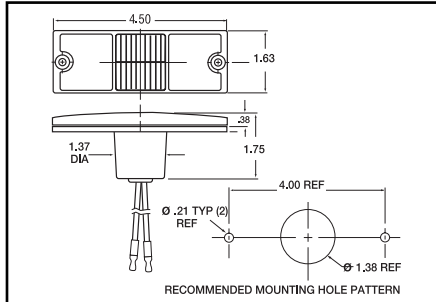

Includes mounting gasket  
Sealed acrylic lens/ABS housing  
Flush mount with reflex

15 Series


Fig. 3

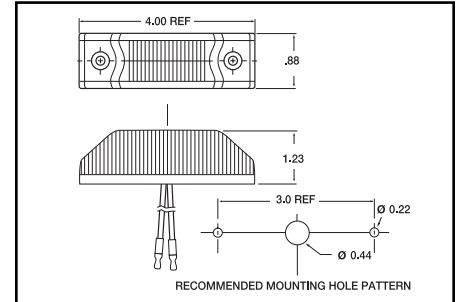

Includes mounting gasket  
Surface mount  
Branch deflector available

16 Series


Fig. 4

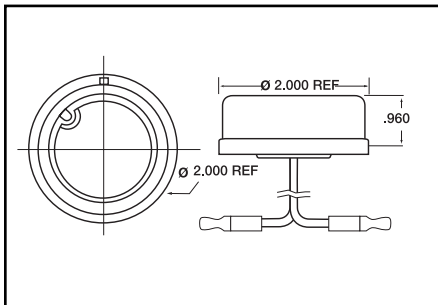

2" Round  
Fits industry standard grommets  
Surface mount adapter available

17 Series


Fig. 5

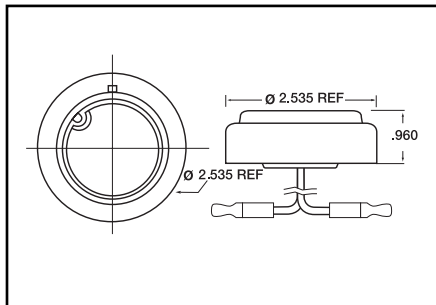

2-1/2" Round  
Fits industry standard grommets  
Surface mount adapter available

New 17 Series


Fig. 6

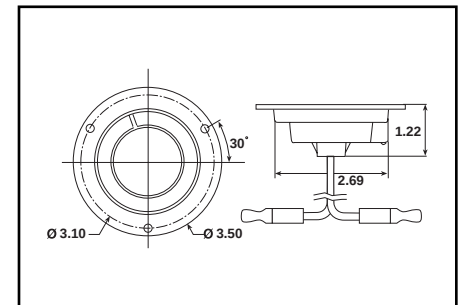

2-1/2" Round Lens Area  
Flange Mount

18 Series


Fig. 7

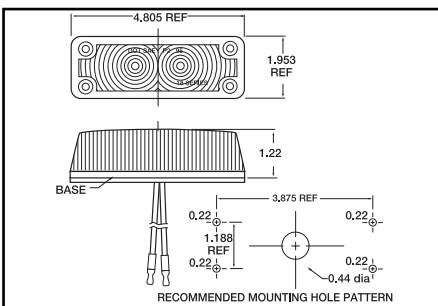

Surface mount  
Includes mounting gasket/screws  
Branch deflector available  
Available in 12V and 24V

19 Series


Fig. 8

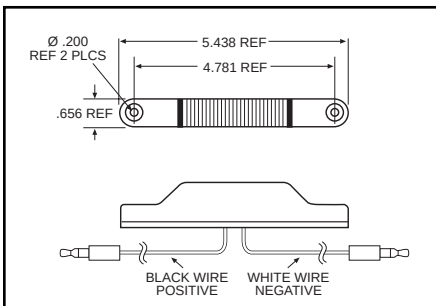

Thinnest marker lamp available  
Fits narrow rail applications

20 Series

Fig. 9

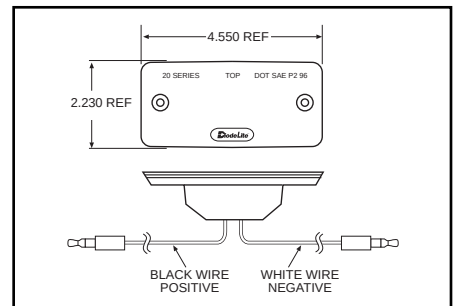

Available in Amber only  
Fits Freightliner/Mack/Navistar  
Cab fronts

### Features:

- 6" **integral** 18 AWG wire leads with .180" male bullet
- Sealed polycarbonate assembly (except 14 series-Acrylic)
- Long life
- Reduced current draw
- Lifetime limited warranty

# Product Selector Guide



## LED Vehicle Lighting

### MARKER LAMPS\* (.180" MALE BULLETS)

| Part No. | Description                                         | Figure |
|----------|-----------------------------------------------------|--------|
| 13071A   | Mini Marker, Amber                                  | 1      |
| 13071R   | Mini Marker, Red                                    | 1      |
| 14071A   | Rectangular Marker, Recess Mount with Reflex, Amber | 2      |
| 14071R   | Rectangular Marker Recess Mount with Reflex, Red    | 2      |
| 15071A   | Standard Thinline Marker, Amber                     | 3      |
| 15071R   | Standard Thinline Marker, Red                       | 3      |
| 16071A   | 2 Inch Round Marker, Amber                          | 4      |
| 16071R   | 2 Inch Round Marker, Red                            | 4      |
| 17071A   | 2-1/2 Inch Round Marker, Amber, Grommet Mount       | 5      |
| 17071R   | 2-1/2 Inch Round Marker, Red, Grommet Mount         | 5      |
| 17101A   | 2-1/2 Inch Marker, Black Flange Mount, Amber        | 6      |
| 17101R   | 2-1/2 Inch Marker, Black Flange Mount, Red          | 6      |
| 18071A   | Rectangular Marker, Surface Mount, Amber            | 7      |
| 18071R   | Rectangular Marker, Surface Mount, Red              | 7      |
| 18111A   | Rectangular Marker, Surface Mount 24V, Amber        | 7      |
| 18111R   | Rectangular Marker, Surface Mount 24V, Red          | 7      |
| 19071A   | Ultra Thinline Marker, Amber                        | 8      |
| 19071R   | Ultra Thinline Marker, Red                          | 8      |
| 20071A   | Cab Recessed Roof Marker, Amber                     | 9      |

\* 12 volts, unless otherwise specified. Include integral wiring with .180 Male bullets.  
Alternative terminations available upon request.

## ACCESSORIES

### MARKER LAMPS

| Part No. | Description                                     |
|----------|-------------------------------------------------|
| 91502A   | 15 Series Lamp Guard                            |
| 91601A   | 16 Series Mounting Grommet                      |
| 91605A   | 16 Series Surface Mount Adapter                 |
| 91701A   | 17 Series Mounting Grommet (Figure 5 only)      |
| 91705A   | 17 Series Surface Mount Adapter (Figure 5 only) |
| 91802A   | 18 Series Lamp Armor Guard                      |