

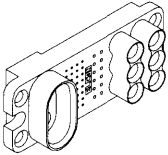
TOP DRAWER & DOUBLE DRAWER



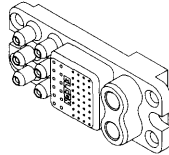
		TOP DRAWER	DOUBLE DRAWER
Dimensions		4.24" × 1.60" (107.82 × 40.64 mm)	
Available contacts	Size #20	32 contacts	24 contacts
	Size #16	12 contacts	—
	Size #12	6 contacts	11 contacts
	Size #0	2 contacts	4 contacts
Housing variations		Various guide pin configurations available. See chart below for details.	
Current		Up to 200A per size #0 contact	

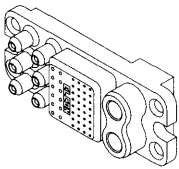
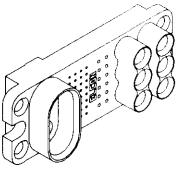
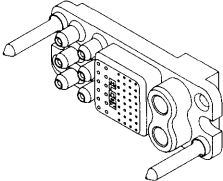
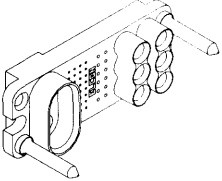
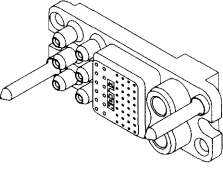
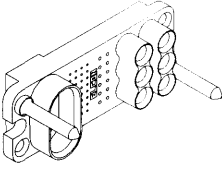
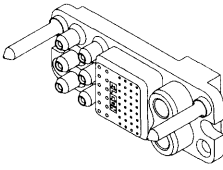
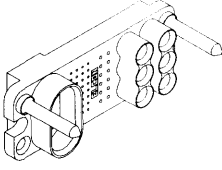
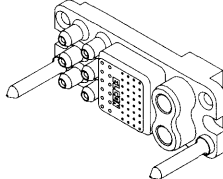
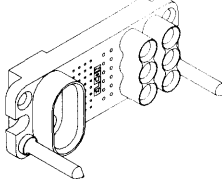
		TOP DRAWER	DOUBLE DRAWER
True Hot Plug support		Special size #12 contact allows current interruption under load	
Contact sequencing		Multilevel for power and signal	
Standard contact terminations	Size #20	Solder cup, crimp and PCB tail	
	Size #16	Solder cup, crimp and PCB tail	—
	Size #12	Solder cup, crimp and PCB tail	
	Size #0	Internal/external thread and crimp	

HOUSING VARIATIONS

Pin Side Housing	
DOUBLE DRAWER 295-0049-01100	TOP DRAWER 291-10-01100
	

NOTE: Only TOP DRAWER housings shown below. The same configurations are available for the DOUBLE DRAWER.	
---	--

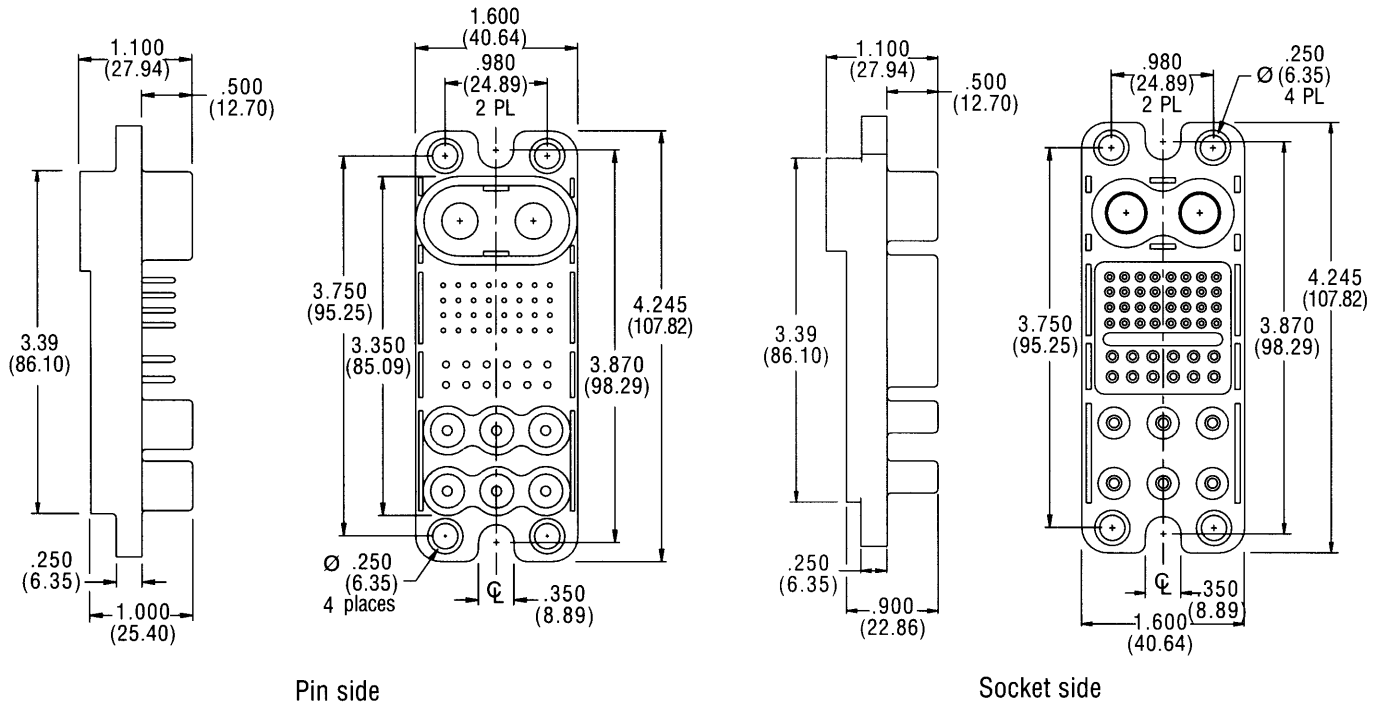
Socket Side Housing	
TOP DRAWER 292-10-01100	DOUBLE DRAWER 296-0049-01100
	

Part Numbers		Mating Socket Side Housing	Mating Pin Side Housing	Part Numbers	
DOUBLE DRAWER	TOP DRAWER			TOP DRAWER	DOUBLE DRAWER
296-0049-01100	292-10-01100			291-10-01100	295-0049-01100
#6-32 thread 296-0050-01100 M3 × 0.5 thread 296-0051-01100	#6-32 thread 296-20-01100 M3 × 0.5 thread 296-21-01100			#6-32 thread 295-20-01100 M3 × 0.5 thread 295-21-01100	#6-32 thread 295-0050-01100 M3 × 0.5 thread 295-0051-01100
#6-32 thread 296-0052-01100 M3 × 0.5 thread 296-0053-01100	#6-32 thread 296-22-01100 M3 × 0.5 thread 296-23-01100			#6-32 thread 295-22-01100 M3 × 0.5 thread 295-23-01100	#6-32 thread 295-0052-01100 M3 × 0.5 thread 295-0053-01100
#6-32 thread 296-0054-01100 M3 × 0.5 thread 296-0055-01100	#6-32 thread 296-24-01100 M3 × 0.5 thread 296-25-01100			#6-32 thread 295-24-01100 M3 × 0.5 thread 295-25-01100	#6-32 thread 295-0054-01100 M3 × 0.5 thread 295-0055-01100
#6-32 thread 296-0056-01100 M3 × 0.5 thread 296-0057-01100	#6-32 thread 296-26-01100 M3 × 0.5 thread 296-27-01100			#6-32 thread 295-26-01100 M3 × 0.5 thread 295-27-01100	#6-32 thread 295-0056-01100 M3 × 0.5 thread 295-0057-01100

■ GENERAL DIMENSIONS

Units: inches (mm)

TOP DRAWER



DOUBLE DRAWER

