

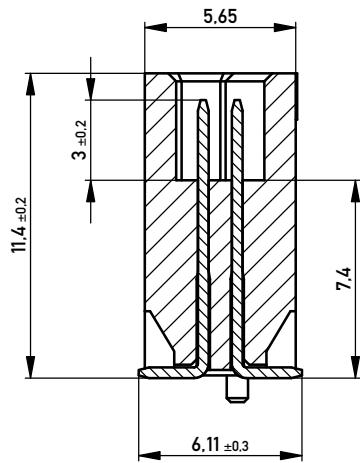



SCHNITT A-A

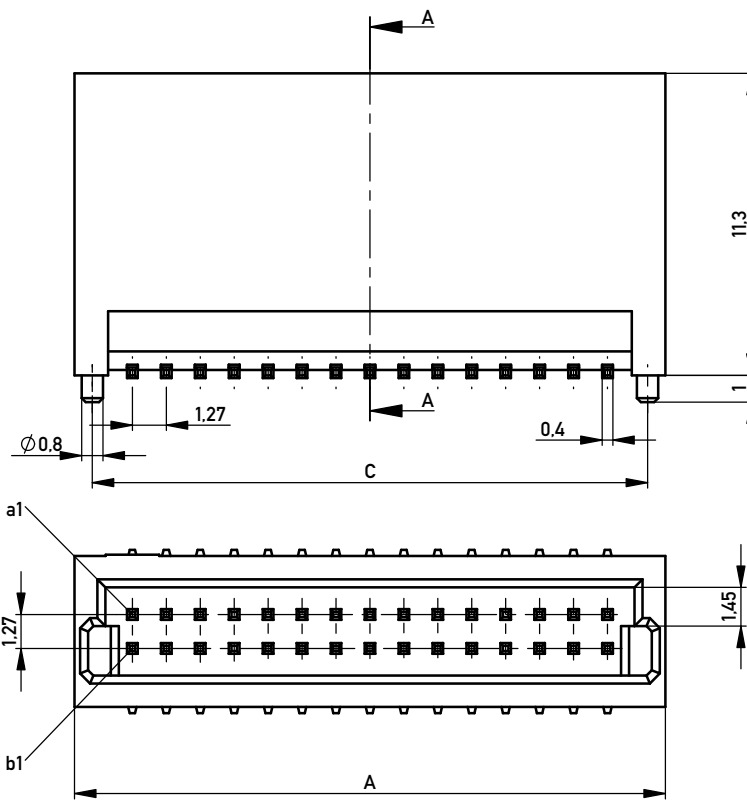


M 2 : 1

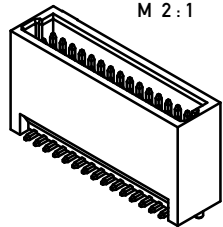

Verpackt in Gurtverpackung  
Tape on Reel Packaging  
Verpackungseinheit: 250 Stück  
Packaging unit: 250 pcs

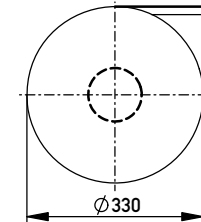

Abspulrichtung - Reel off Direction

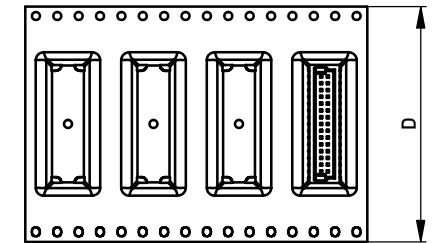


Verpackung Stange / Stange & Ansaughaube  
packaging tube / tube & cap

|                             |                |
|-----------------------------|----------------|
| 100                         | 9              |
| 80                          | 11             |
| 70                          | 12             |
| 60                          | 14             |
| 50                          | 17             |
| 40                          | 21             |
| 30                          | 27             |
| 20                          | 38             |
| 10                          | 64             |
| Polzahl<br>No. of positions | Stück / pieces |

Masse und Toleranzen in Übereinstimmung mit ANSI Y15.5M-1994 /  
Interpret dimensions according to ANSI Y15.5M-1994

|                                              |                                             |                                             |                                            |                                         |                                        |                            |        |        |        |        |
|----------------------------------------------|---------------------------------------------|---------------------------------------------|--------------------------------------------|-----------------------------------------|----------------------------------------|----------------------------|--------|--------|--------|--------|
| 109219                                       | 109210                                      | 109201                                      | 109192                                     | 109183                                  | 109174                                 | 100                        | 66.56  | 62.23  | 65.23  | 88     |
| 109218                                       | 109209                                      | 109200                                      | 109191                                     | 109182                                  | 109173                                 | 80                         | 53.86  | 49.53  | 52.53  | 72     |
| 109217                                       | 109208                                      | 109199                                      | 109190                                     | 109181                                  | 109172                                 | 70                         | 47.51  | 43.18  | 46.18  | 72     |
| 109216                                       | 109207                                      | 109198                                      | 109189                                     | 109180                                  | 109171                                 | 60                         | 41.16  | 36.83  | 39.83  | 56     |
| 109215                                       | 109206                                      | 109197                                      | 109188                                     | 109179                                  | 109170                                 | 50                         | 34.81  | 30.48  | 33.48  | 56     |
| 109214                                       | 109205                                      | 109196                                      | 109187                                     | 109178                                  | 109169                                 | 40                         | 28.46  | 24.13  | 27.13  | 44     |
| 109213                                       | 109204                                      | 109195                                      | 109186                                     | 109177                                  | 109168                                 | 30                         | 22.11  | 17.78  | 20.78  | 44     |
| 109212                                       | 109203                                      | 109194                                      | 109185                                     | 109176                                  | 109167                                 | 20                         | 15.76  | 11.43  | 14.43  | 32     |
| 109211                                       | 109202                                      | 109193                                      | 109184                                     | 109175                                  | 109166                                 | 10                         | 9.41   | 5.08   | 8.08   | 24     |
| Id-Nr.<br>tape&reel<br>100 mating-<br>cycles | Id-Nr.<br>tape&reel<br>10 mating-<br>cycles | Id-Nr.<br>tube&cap<br>100 mating-<br>cycles | Id-Nr.<br>tube&cap<br>10 mating-<br>cycles | Id-Nr.<br>tube<br>100 mating-<br>cycles | Id-Nr.<br>tube<br>10 mating-<br>cycles | Polzahl<br>no of positions | Mass A | Mass B | Mass C | Mass D |

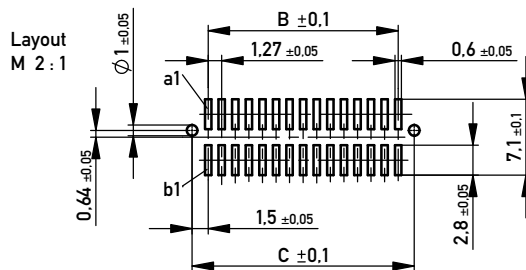

Bei Gurtverpackung ist Ansaughaube immer montiert.  
Tape & reel packaging is always with assembly cap.

Copyright by ERNI GmbH  
Proprietary notice pursuant to ISO 9006 to be observed.

Information:

All rights reserved.  
Only for Information.  
To ensure that this is the latest  
version of this drawing, please  
contact one of the ERNI companies  
before using.

Tolerances



Scale 5:1

Subject to modification without  
prior notice.  
Drawing will not be updated.

ERNI www.ERNI.com

Designation

MiniMez Vertical Male SMT  
with locating pegs 7.4mm

109165

I  
A3

Class MINIMEZ