


Datasheet

Item No. 70.374.2435.1

Hood BAS GOT GK 24 M32 50 A1

revos BASIC 500V size 24 hood for cable-to-cable couplings with threaded collar M32, top cable entry, double locking lever

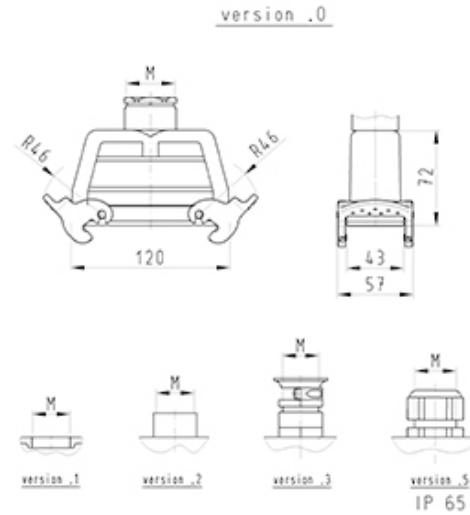

Item No.	70.374.2435.1
EAN	4015573819153
order unit	1 Piece(s)

Approvals

Technical data
General

Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24
Model	Cable coupler
Locking mechanism	Double locking levers
Cable entry	Above
Type of cable	Thread
With cable screw gland	No
Thread size M	32
Hinged lid	No
EMC-version	No