


Datasheet

Item No. 71.342.2435.1

Bottom BAS GUT GT 24 M25 50 A1

revos BASIC 500V size 24 closed-bottom base with threaded collar M25, right, with cover, single locking lever

version .0

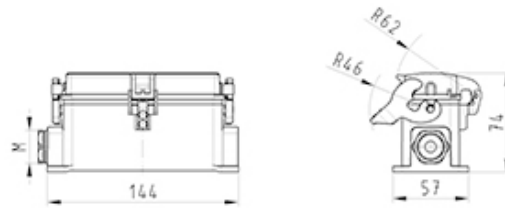

version .1

Item No.	71.342.2435.1
EAN	4015573624962
order unit	1 Piece(s)

Approvals



Technical data

General

Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24
Model	Surface mounting (base)
Locking mechanism	Single locking lever
Cable entry	Sideways
Type of cable	Thread
With cable screw gland	No
Thread size M	25
Hinged lid	Yes
EMC-version	No