


Datasheet

Art.No. 76.335.6435.1

Bottom GUT GM 24HM32 A1

revos BASIC 500V size 24H closed-bottom base with threaded collar M32, left, high design, single locking lever

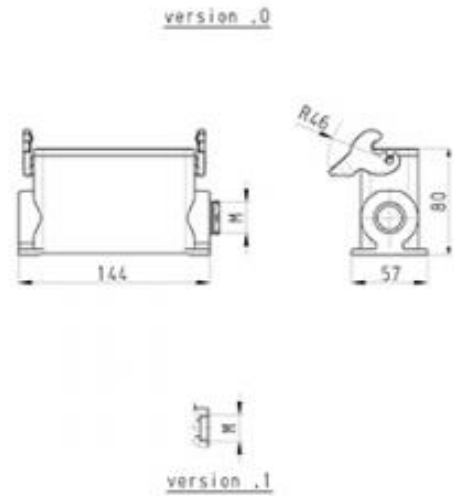

Art.No.	76.335.6435.1
EAN	4015573624658
Order unit	1 pieces

Approvals

Technical data

General

Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24H
Model	Surface mounting (base)
Locking mechanism	Single locking lever
Cable entry	Sideways
Type of cable	Thread
With cable screw gland	No
Thread size M	32
Hinged lid	No
EMC-version	No

Classification

ECLASS 8.1	27440202: Housing for industrial connectors
ETIM 5.0	EC000437: Housing for industrial connectors
ETIM 4.0	EC000437: Housing for industrial connectors
ETIM 3.0	EC000437: Housing for industry plug connectors