


## Datasheet

Item No. 76.354.1035.2

Hood BAS GOT GI 10HM32 50 A2

revos BASIC 500V size 10H hood with intermediate support M32, top cable entry, high design, single locking lever

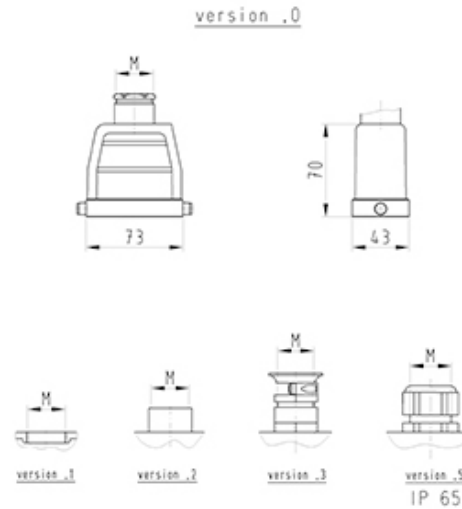

Item No.	76.354.1035.2
EAN	4015573686663
order unit	1 Piece(s)

## Approvals



## Technical data

### General

Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	Other
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

### Model

DIN-size	10H
Model	Plug
Locking mechanism	Single locking lever
Cable entry	Above
Type of cable	Intermediate support
With cable screw gland	No
Thread size M	32
Hinged lid	No
EMC-version	No