


Datasheet

Art.No. 73.354.3235.1

Hood HD GOT GC 32 M32 69 A1

revos HD size 32/50 hood with threaded collar M32, top cable entry, double locking lever

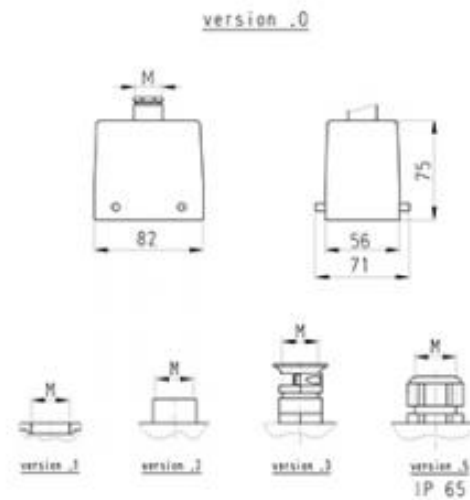

| | |
|------------|---------------|
| Art.No. | 73.354.3235.1 |
| EAN | 4015573759336 |
| Order unit | 1 pieces |

Approvals



Technical data

General

| | |
|--|---------------------|
| Nominal voltage | 690 |
| Housing material | Aluminium |
| Colour | Grey |
| Surface | With powder coating |
| Degree of protection (IP) | Other |
| UV resistant | Yes |
| Inflammability class of insulation material acc. with UL94 | Other |
| Operating temperature range min. | -40 °C |
| Operating temperature range max. | 120 °C |

Model

| | |
|------------------------|-----------------------|
| DIN-size | 32/50 |
| Model | male |
| Locking mechanism | Double locking levers |
| Cable entry | Above |
| Type of cable | Thread |
| With cable screw gland | No |
| Thread size M | 32 |
| Hinged lid | No |
| EMC-version | No |

