

**Direct Links**

- Cross Reference
- RoHS/LF P/N search
- Document & Drawing search
- Application tooling

**Services**


- Contact us
- Distributor list
- Pricing request
- Order samples

**Literature**

- Brochures & catalogs
- Product documentation
- Technical library

**HM2P65PCT260N9**

[Assistant](#) [Add to Favorites](#)

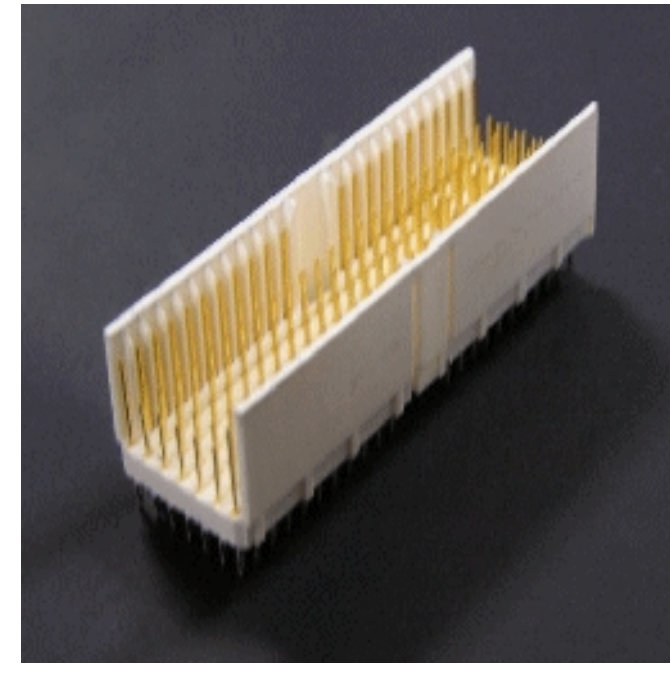

**HM2P65PCT260N9 - Millipacs™**

**2 mm Hardmetric Series 5 Row  
Straight Press-Fit Header Type AB25  
with 125 Signal pins**

[Email Datasheet](#)  [Print Datasheet](#)

**FCI Brings You More**

- [Contact our sales/technical support](#)
- [Sample request](#)
- [Price request](#)
- [Check distributor stock](#)

ACTIVE

[Customer Drawing](#)

Electronics division

**Download document**

**Technical Resources**

- [> 3D IGES](#)
- [> Product Specification...](#)
- [> 3D PROE](#)

**Literature**

- [> Connectors for Medical Devices Brochure](#)
- [> Connector Overview Brochure...](#)

**Application Tooling**

- [> Asia Pacific Application Tooling..](#)
- [> Americas Application Tooling....](#)
- [> Europe Application Tooling....](#)

**Specifications**

General Dimensional Electrical Mechanical Mounting Physical Approvals / Certifications

<b>General</b>	
Gender	Header
Number of contacts	125
Number of rows	5
Orientation	Straight
Product Type	Header
Series	Module Type AB (15.4 mm) 25 Po.
Shielded	No
Number of levels (Contact)	Refer to Customer Drawing
<b>Dimensional</b>	
Length (Tail)	Short Tail (4.5 mm)
<b>Electrical</b>	
Current rating	1.5A @ 20°C, 1A @ 70°C
Resistance (Contact)	20 milli ohms max
Resistance (Insulation)	10000 mega ohms min
Voltage rating	750V rms
<b>Mechanical</b>	
Withdrawal Force	0.15N min. Per contact pai
Hertz stress	200 Kpsi min.
Mating force (Signal)	0.75N max. Per contact pai
Normal force (Signal)	0.75N min. (EOL
<b>Mounting</b>	
Mounting style (Board)	Press-Fit
<b>Physical</b>	
Finish (Contact)	Level 2
Material (Contact)	Phospher Bronze
Material (Housing)	Thermoplastic (UL94 V-0)
Temperature (Operating)	-55°C to +125°C
<b>Approvals / Certifications</b>	
Approvals / Certifications	UL and CSA Certifiec