

RCA AUDIO CONNECTORS

RCA AUDIO CONNECTORS KIT

RCA audio connectors, and their color bands, are included in this heavy duty plastic kit. Each kit contains 10 of each of the connector part numbers and 100 of each of the color band part numbers listed below. When the connectors and color bands run out, the parts are easily replaced by ordering each individually or in bulk packages of 10 (add “-BU” to end of order for bulk packages. (See pages 201-203 for more information)).

RCA Audio Connectors Kit Part No.: **65-650** 2.8 mm Cable O.D. Kit
65-651 4.0 mm Cable O.D. Kit
65-652 6.0 mm Cable O.D. Kit
65-653 8.0 mm Cable O.D. Kit



Fig.1

RCA Audio Connectors Kit

Retail Part No.	Bulk Part No.	Figure No.	Type 1 Color Bands	Type 2 Color Bands	RCA Epitome® Audio Connectors (Good)	RCA Epitome®-Pro Audio Connectors (Better)			RCA Epitome®-Pro + Audio Connectors (Best)
65-650 or 65-651 or 65-652 or 65-653		1	65-630-BK 65-630-BL 65-630-GN 65-630-RD 65-630-WH 65-630-YL 65-630-VL	65-631-BK 65-631-BL 65-631-GN 65-631-RD 65-631-WH 65-631-YL 65-631-VL	30-1230 30-1231 30-1232 30-534 30-534-3	65-632-X-XX 65-633-X-XX 65-634-X-XX 65-635-X-XX	65-636-X-XX 65-637-X-XX 65-638-X-XX 65-639-X-XX	65-640-X-XX 65-642-X-XX 65-643-X-XX 65-644-X-XX	65-645-X-XX 65-646-X-XX 65-647-X-XX 65-648-X-XX
			Quantities of 100 in each kit.	Quantities of 15 in each kit.	Quantities of 10 each. These (Good) connectors appear in kit 65-653 only.	Quantities of 10 in each kit			Quantities of 10 in each kit

Notes: X=size: X=2 (for 2.8 mm), X=4 (for 4.0 mm), X= 6 (for 6.0 mm) and X=8 (for 8.0 mm). (Example = 65-232-2-XX)

XX= without Color Band; for Colored Band Order, Replace “XX” with “BK” (Black), “BL” (Blue), “GN” (Green), “RD” (Red), “WH” (White), “YL” (Yellow), “VL” (Violet) (Example = 65-232-2-RD)

RCA EPITOME® AUDIO CONNECTORS (GOOD)

Epitome® RCA connectors have all metal shells to shield the cable ends from EMI/RFI and provide a good grip for plugging and unplugging the connectors. All GC Electronics Epitome® RCA connectors are Gold* Plated for corrosion resistance and low electrical resistance and are soldered** to the wire.

Note: * With the exception of the 30-534 which is nickel plated.

** (compatible leaded and some Lead Free Solders for RoHS compliance)



Fig.2



Fig.3



Fig.4



Fig.5

Fig.6

RCA Epitome® Audio Connectors (Good)

Retail Part No.	Bulk Part No.	Figure No.	Outside Color	Outer Diameter Wire Size
30-1230		2	Platinum	8 mm
30-1231		3	Black	8 mm
30-1232		4	Red	8 mm
30-534	30-534-BU	5	Nickel	8 mm
30-534-3		6	Gold	8 mm

RCA AUDIO CONNECTORS (Cont.)

RCA EPITOME®-PRO AUDIO CONNECTORS (BETTER)

Epitome® Pro Connectors like the Epitome® connectors have all metal shells for EMI/RFI protection and are Gold Plated for corrosion resistance and low electrical resistance and are soldered** to the wire. The GC Electronics Epitome® Pro Connectors also have a split center contact that spreads the center contact apart for better connector to connector connection.

Note: ** (compatible leaded and some Lead Free Solders for RoHS compliance)



Fig.1



Fig.2



Fig.3



Fig.4



Fig.5



Fig.6



Fig.7



Fig.8



Fig.9



Fig.10



Fig.11



Fig.12

RCA Epitome®-Pro Audio Connectors (Better)

Retail Part No.	Bulk Part No.	Figure No.	Band Type	Outer Diameter Wire Size
65-632-2-XX	65-632-2-XX-BU	1	1	2.8mm
65-632-4-XX	65-632-4-XX-BU	1	1	4mm
65-632-6-XX	65-632-6-XX-BU	1	1	6mm
65-632-8-XX	65-632-8-XX-BU	1	1	8mm
65-633-2-XX	65-633-2-XX-BU	2	1	2.8mm
65-633-4-XX	65-633-4-XX-BU	2	1	4mm
65-633-6-XX	65-633-6-XX-BU	2	1	6mm
65-633-8-XX	65-633-8-XX-BU	2	1	8mm
65-634-2-XX	65-634-2-XX-BU	3	1	2.8mm
65-634-4-XX	65-634-4-XX-BU	3	1	4mm
65-634-6-XX	65-634-6-XX-BU	3	1	6mm
65-634-8-XX	65-634-8-XX-BU	3	1	8mm
65-635-2-XX	65-635-2-XX-BU	4	1	2.8mm
65-635-4-XX	65-635-4-XX-BU	4	1	4mm
65-635-6-XX	65-635-6-XX-BU	4	1	6mm
65-635-8-XX	65-635-8-XX-BU	4	1	8mm
65-636-2-XX	65-636-2-XX-BU	5	1	2.8mm
65-636-4-XX	65-636-4-XX-BU	5	1	4mm
65-636-6-XX	65-636-6-XX-BU	5	1	6mm
65-636-8-XX	65-636-8-XX-BU	5	1	8mm
65-637-2-XX	65-637-2-XX-BU	6	1	2.8mm
65-637-4-XX	65-637-4-XX-BU	6	1	4mm
65-637-6-XX	65-637-6-XX-BU	6	1	6mm
65-637-8-XX	65-637-8-XX-BU	6	1	8mm

RCA Epitome®-Pro Audio Connectors (Better) (Cont.)

Retail Part No.	Bulk Part No.	Figure No.	Band Type	Outer Diameter Wire Size
65-638-2-XX	65-638-2-XX-BU	7	1	2.8mm
65-638-4-XX	65-638-4-XX-BU	7	1	4mm
65-638-6-XX	65-638-6-XX-BU	7	1	6mm
65-638-8-XX	65-638-8-XX-BU	7	1	8mm
65-639-2-XX	65-639-2-XX-BU	8	1	2.8mm
65-639-4-XX	65-639-4-XX-BU	8	1	4mm
65-639-6-XX	65-639-6-XX-BU	8	1	6mm
65-639-8-XX	65-639-8-XX-BU	8	1	8mm
65-640-2-XX	65-640-2-XX-BU	9	1	2.8mm
65-640-4-XX	65-640-4-XX-BU	9	1	4mm
65-640-6-XX	65-640-6-XX-BU	9	1	6mm
65-640-8-XX	65-640-8-XX-BU	9	1	8mm
65-642-2-XX	65-642-2-XX-BU	10	2	2.8mm
65-642-4-XX	65-642-4-XX-BU	10	2	4mm
65-642-6-XX	65-642-6-XX-BU	10	2	6mm
65-642-8-XX	65-642-8-XX-BU	10	2	8mm
65-643-2-XX	65-643-2-XX-BU	11	2	2.8mm
65-643-4-XX	65-643-4-XX-BU	11	2	4mm
65-643-6-XX	65-643-6-XX-BU	11	2	6mm
65-643-8-XX	65-643-8-XX-BU	11	2	8mm
65-644-2-XX	65-644-2-XX-BU	12	1 & 2	2.8mm
65-644-4-XX	65-644-4-XX-BU	12	1 & 2	4mm
65-644-6-XX	65-644-6-XX-BU	12	1 & 2	6mm
65-644-8-XX	65-644-8-XX-BU	12	1 & 2	8mm

Notes: XX= without Color Band; for Colored Band Order, Replace "XX" with "BK" (Black), "BL" (Blue), "GN" (Green), "RD" (Red), "WH" (White), "YL" (Yellow), "VL" (Violet) (Example = 65-232-2-RD)

RCA AUDIO CONNECTORS (Cont.)

RCA EPITOME®-PRO + AUDIO CONNECTORS (BEST)

Epitome® Pro Plus Connectors Like the *Epitome®* and *Epitome® Pro* RCA Connectors have all metal shells for EMI/RFI protection and are Gold Plated for corrosion resistance and low electrical resistance and are soldered** to the wire. The GC Electronics *Epitome® Pro Plus* like the *Epitome® Pro* Connectors also have a split center contact that spreads the center contact apart for better connector to connector connection. The *Epitome® Pro Plus* connectors also have a twist lock* mechanism that locks the male plug to the female connector. Note: ** (compatible leaded and some Lead Free Solders for RoHS compliance)



Fig.1



Fig.2



Fig.3



Fig.4

RCA Epitome®-Pro + Audio Connectors (Best)

Retail Part No.	Bulk Part No.	Figure No.	Band Type	Outer Diameter Wire Size
65-645-2-XX	65-645-2-XX-BU	1	2	2.8mm
65-645-4-XX	65-645-4-XX-BU	1	2	4mm
65-645-6-XX	65-645-6-XX-BU	1	2	6mm
65-645-8-XX	65-645-8-XX-BU	1	2	8mm
65-646-2-XX	65-646-2-XX-BU	2	1	2.8mm
65-646-4-XX	65-646-4-XX-BU	2	1	4mm
65-646-6-XX	65-646-6-XX-BU	2	1	6mm
65-646-8-XX	65-646-8-XX-BU	2	1	8mm

RCA Epitome®-Pro + Audio Connectors (Best) (Cont.)

Retail Part No.	Bulk Part No.	Figure No.	Band Type	Outer Diameter Wire Size
65-647-2-XX	65-647-2-XX-BU	3	1	2.8mm
65-647-4-XX	65-647-4-XX-BU	3	1	4mm
65-647-6-XX	65-647-6-XX-BU	3	1	6mm
65-647-8-XX	65-647-8-XX-BU	3	1	8mm
65-648-2-XX	65-648-2-XX-BU	4	1	2.8mm
65-648-4-XX	65-648-4-XX-BU	4	1	4mm
65-648-6-XX	65-648-6-XX-BU	4	1	6mm
65-648-8-XX	65-648-8-XX-BU	4	1	8mm

Notes: XX= without Color Band; for Colored Band Order, Replace "XX" with "BK" (Black), "BL" (Blue), "GN" (Green), "RD" (Red), "WH" (White), "YL" (Yellow), "VL" (Violet) (Example = 65-232-2-RD) *65-645Does Not Have Twist Lock Feature

RCA COLOR BANDS

GC Electronics offer a wide array of color bands for to fit GC Electronic RCA plugs. The color Bands allow the custom cable builder to build a custom cable using the correct color for each connection. The Type1 Bands are thin for that minimalist look while the Type2 bands are wide to aid in handling of the cables.



Fig.5



Fig.6



Fig.7



Fig.8



Fig.9



Fig.10



Fig.11



Fig.12



Fig.13



Fig.14



Fig.15



Fig.16

 


Fig.17



Fig.18

RCA Plug Color Bands–Type 1

Retail Part No.	Bulk Part No.	Fig. No.	Description	Band Color
65-630-BK	65-630-BK-BU	5	Color Bands Type 1–Black	Black
65-630-BL	65-630-BL-BU	6	Color Bands Type 1–Blue	Blue
65-630-GN	65-630-GN-BU	7	Color Bands Type 1–Green	Green
65-630-RD	65-630-RD-BU	8	Color Bands Type 1–Red	Red
65-630-WH	65-630-WH-BU	9	Color Bands Type 1–White	White
65-630-YL	65-630-YL-BU	10	Color Bands Type 1–Yellow	Yellow
65-630-VL	65-630-VL-BU	11	Color Bands Type 1–Violet	Violet

RCA Plug Color Bands–Type 2

Retail Part No.	Bulk Part No.	Fig. No.	Description	Band Color
65-631-BK	65-631-BK-BU	12	Color Bands Type 2–Black	Black
65-631-BL	65-631-BL-BU	13	Color Bands Type 2–Blue	Blue
65-631-GN	65-631-GN-BU	14	Color Bands Type 2–Green	Green
65-631-RD	65-631-RD-BU	15	Color Bands Type 2–Red	Red
65-631-WH	65-631-WH-BU	16	Color Bands Type 2– White	White
65-631-YL	65-631-YL-BU	17	Color Bands Type 2–Yellow	Yellow
65-631-VL	65-631-VL-BU	18	Color Bands Type 2–Violet	Violet

G&H AUDIO CONNECTORS

G&H AUDIO CONNECTORS

The *Epitome*®-Pro+ line is proud to introduce the very finest 1/4" Mono and Stereo Phone Jacks available. By eliminating a series of friction-fitted low conductive metals and instead designing a solid copper core, the signal is kept at its purest. The result is maximum signal transfer and a drastic reduction of pops, hisses, and sound coloration. To top off a great performance, these plugs are finished in your choice of fine Oak, or rare Cocobolo wood. These wooden sleeves are available with a smooth or grooved surface. All conductive surfaces are 24 CT. gold plated. Give your Headphones, microphones and mixers the performance and aesthetics they deserve!

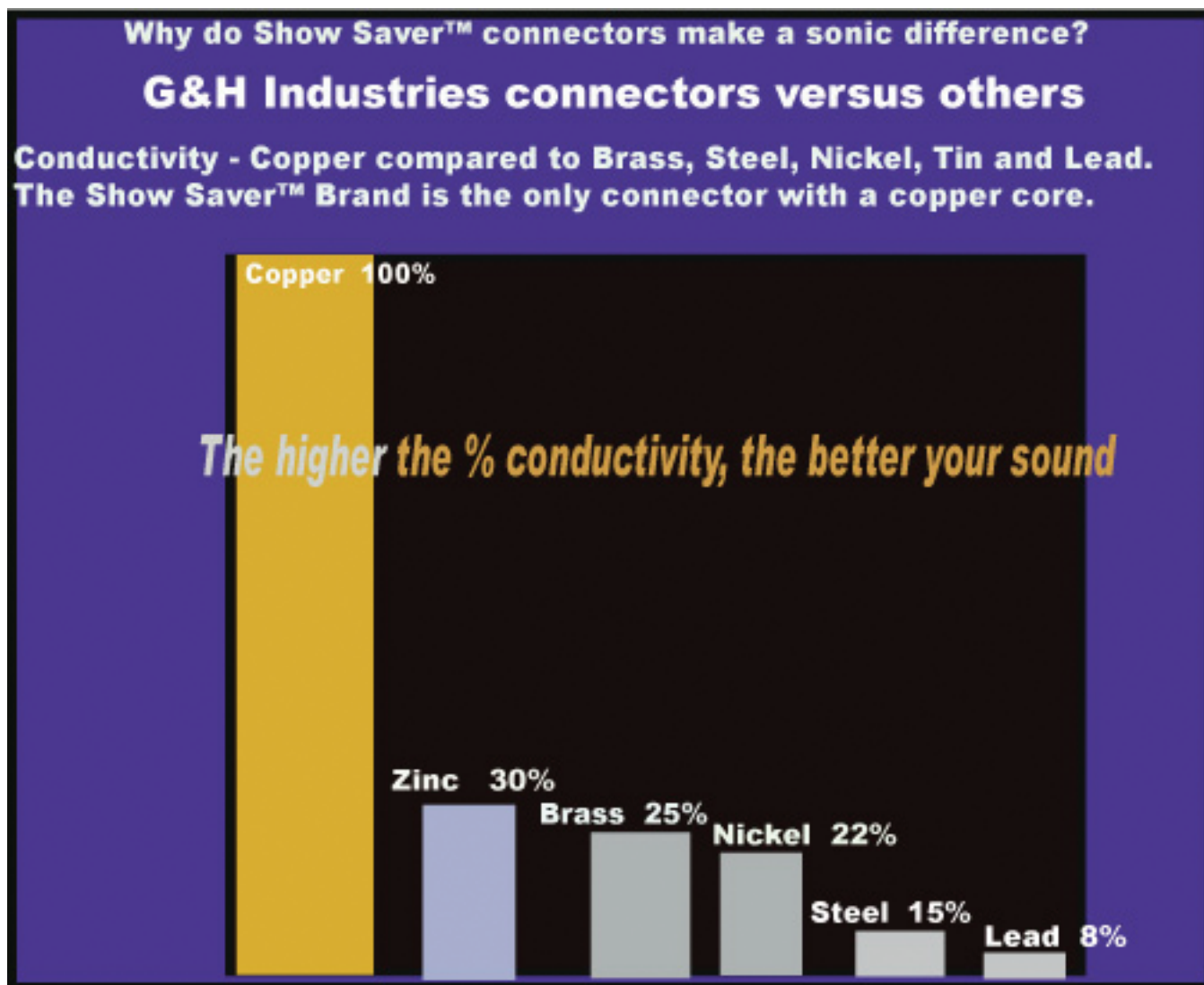




Fig.1



Fig.2



Fig.3



Fig.4



Fig.5



Fig.6



Fig.7



Fig.8



Fig.9



Fig.10



Fig.11



Fig.12

G & H Audio Connectors

Retail Part No.	Bulk Part No.	Figure No.	Description	Color	Quantity
BF2P-W1CNN	BF2P-W1CNN-BU	1	1/4" Phone Plug, Mono, Smooth-Nickel	Cocobolo	1 Each/10 Pack
BF2P-W1CGG	BF2P-W1CGG-BU	2	1/4" Phone Plug, Mono, Smooth-Gold	Cocobolo	1 Each/10 Pack
BF3PM-W1CGGG	BF3PM-W1CGGG-BU	3	1/4" Phone Plug, Stereo, Smooth-Gold	Cocobolo	1 Each/10 Pack
BF2P-W1ONN	BF2P-W1ONN-BU	4	1/4" Phone Plug, Mono, Smooth-Nickel	Oak	1 Each/10 Pack
BF2P-W1OGG	BF2P-W1OGG-BU	5	1/4" Phone Plug, Mono, Smooth-Gold	Oak	1 Each/10 Pack
BF3PM-W1OGGG	BF3PM-W1OGGG-BU	6	1/4" Phone Plug, Stereo, Smooth-Gold	Oak	1 Each/10 Pack
BF2P-W2CNN	BF2P-W2CNN-BU	7	1/4" Phone Plug, Mono, Grooved-Nickel	Cocobolo	1 Each/10 Pack
BF2P-W2CGG	BF2P-W2CGG-BU	8	1/4" Phone Plug, Mono, Grooved-Gold	Cocobolo	1 Each/10 Pack
BF3PM-W2CGGG	BF3PM-W2CGGG-BU	9	1/4" Phone Plug, Stereo, Grooved-Gold	Cocobolo	1 Each/10 Pack
BF2P-W2ONN	BF2P-W2ONN-BU	10	1/4" Phone Plug, Mono, Grooved-Nickel	Oak	1 Each/10 Pack
BF2P-W2OGG	BF2P-W2OGG-BU	11	1/4" Phone Plug, Mono, Grooved-Gold	Oak	1 Each/10 Pack
BF3PM-W2OGGG	BF3PM-W2OGGG-BU	12	1/4" Phone Plug, Stereo, Grooved-Gold	Oak	1 Each/10 Pack

POWERFLEXTM AUDIO CONNECTORS



Epitome®-Pro + (Best)
Fig. 1



Epitome®-Pro (Better)
Fig. 2



Epitome®-Pro + (Best)
Fig. 3



Epitome®-Pro (Better)
Fig. 4



Epitome®-Pro (Better)
Fig. 5



Epitome®-Pro + (Best)
Fig. 6



Epitome®-Pro + (Best)
Fig. 7



Epitome®-Pro + (Best)
Fig. 8



Epitome®-Pro + (Best)
Fig. 9



Epitome®-Pro (Better)
Fig. 10



Epitome® (Good)
Fig. 11



Epitome®-Pro (Better)
Fig. 12



Epitome® (Good)
Fig. 13

PowerFlexTM Audio Connectors

Retail Part No.	Bulk Part No.	Fig. No.	Description	Features
30-1200		1	<i>Epitome®-Pro + Spade Speaker Terminals-Gold</i>	Compression (Solderless) Spade Lugs
30-1204		2	<i>Epitome®-Pro Pins-Gold</i>	Crimp or Solder Flexible Pin, Color-coded Insulators
30-1205		3	<i>Epitome®-Pro + Pin-Gold</i>	Compression (Solderless) Pin Plugs
30-1208		4	<i>Epitome® Banana Plug-Gold</i>	Crimp or Solder Banana Plugs, Color-coded Insulators
30-1210		5	<i>Epitome®-Pro Banana Plug-Gold</i>	Compression (Solderless) Banana Plugs
30-1211	30-1211-BU	6	<i>Epitome®-Pro + Banana Plug-Gold</i>	Compression (Solderless) 9-Pin Spring Banana Plugs
SBN-SWC-G	SBN-SWC-G-BU	7	Short Wood Banana Plug-Gold	9 Springs, More Contact Surface, Terminates 8 AWG-1/2" Diameter Wire
SBN-LWC-G	SBN-LWC-G-BU	8	Long Wood Banana Plug-Gold	9 Springs, More Contact Surface, Terminates 8 AWG-1/2" Diameter Wire
BBN-BG	BBN-BG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Black-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-BLG	BBN-BLG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Blue-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-BRG	BBN-BRG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Brown-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-GG	BBN-GG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Green-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-GRG	BBN-GRG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Gray-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-OG	BBN-OG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Orange-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-RG	BBN-RG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, Red-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
BBN-WG	BBN-WG-BU	9	<i>Epitome®-Pro + Dual Banana Plugs, White-Gold</i>	30Amp Rating, Color-coded, Industry Standard Ground Tab on Neg. (-) Side
30-1212		10	<i>Epitome®-Pro RCA Powerflex Jacks-Gold</i>	RCA Jack to RCA Jack-Powerflex
30-1213		11	<i>Epitome® RCA Powerflex Plugs-Gold</i>	RCA Plug to RCA Plug -Powerflex
30-1215		12	<i>Epitome®-Pro RCA Powerflex Plug/Jacks-Gold</i>	RCA Plug to Dual RCA Jacks-Powerflex
30-474		13	<i>Epitome® RCA Powerflex 90° Plug/Jack-Gold</i>	Right Angle RCA Plug to RCA Jack-Powerflex