



**GREENLEE®**

A Textron Company

**There With You™**  
faster • safer • easier®

**8" Long Nose**

**Stripping Capacity:  
12 AWG Gauge**

Molded or dipped grip  
models available

0351-08SM



0351-08SD

## ***Wire stripping and looping perfected...***

The Greenlee hand tools line has just been augmented with two 8" long nose stripping pliers with laser hardened edges. The new 0351-08SM and 0351-08SD can cut, strip, and loop 12 AWG wire as well as be used for a range of other applications in tight spaces. These pliers are offered in both dual-material molded grips and dual-layer vinyl grips to allow for either user preference.

The ergonomic oval profile and tapered, flared handles give you a larger load surface and increased leverage while increasing comfort and reducing user fatigue. These features, along with the superior cutting capabilities, wear resistance and long life of the laser hardened cutting edges, give you a long nose stripping pliers you can use for a long time to come.

[www.greenlee.com](http://www.greenlee.com)

## Features

- Long-nose design for time savings in forming and looping wire and handling small parts
- 12 AWG wire stripper for easy removal of insulation
- Laser hardened cutting edges for superior cutting capability, wear resistance and long life
- Ergonomic flattened oval grip profile to allow for a larger load surface, increasing comfort and reducing user fatigue (0351-08SM)
- 'Pouchable', dual layer vinyl grip for user comfort (0351-08SD)
- Cross hatch jaws for maximum gripping
- Precision riveted joint for smooth action with minimum joint looseness
- Tapered, flared handles allows for increased leverage when cutting large diameter wire
- Polished finish for professional look
- Lacquer coated for corrosion protection
- Integral thumb stops to reduce slipping and allow user maximum tool control
- Designed to exceed ASME/ANSI standards
- Lifetime Limited Warranty



0351-08SD

## Specifications


	0351-08SM	0351-08SD
Width	2-1/4" (57mm)	2" (51mm)
Length	8-3/4" (222mm)	8-1/2" (216mm)
Height	3/4" (19mm)	1/2" (13mm)
Weight	.64 lbs. (.29kg)	.64 lbs. (.29kg)
Stripping Capacity	12 AWG Gauge	12 AWG Gauge

## Ordering Information

Cat#	UPC#	Description	Qty
0351-08SM	20958	PLIERS, LONGNOSE 8" MOLD STRIP	1
0351-08SD	20957	PLIERS, LONGNOSE 8" DIP STRIP	1

0351-08SM

### DISTRIBUTOR INFORMATION :

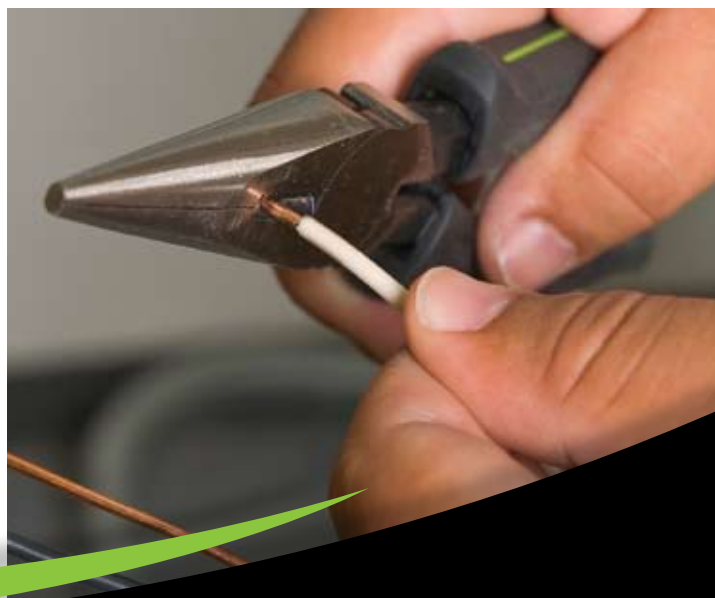

**USA**  
Tel: 800.435.0786  
Fax: 800.451.2632

**Canada**  
Tel: 800.435.0786  
Fax: 800.524.2853

**International**  
Tel: +1.815.397.7070  
Fax: +1.815.397.9247

