




GUARDIAN
Electric Manufacturing

ISO 9001 / AS9100 Certified Company

Woodstock, IL 60098 Ph. (815)334-3600 Fax (815)337-0377

Or visit us at our website www.guardian-electric.com

Model LT8 x 9 Long-Life DC Tubular Solenoid

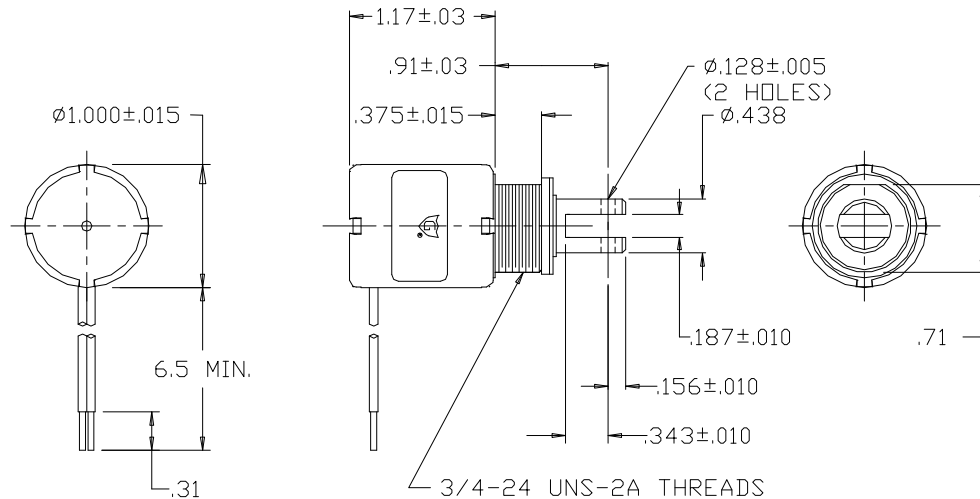

Solenoid shown energized and fully seated.

Supplied with mounting bracket, hex nut and lockwasher (not shown).

Spring kits are available (consult factory).

Total Weight: 3.7 oz.

Plunger Weight: 1.1 oz.

Model No.	Part No.	Duty Cycle	Voltage	Resistance (Ω)	Power (W)	Current
LT8x9-I-12	A420-064843-00	Intermittent	12VDC	11.1	13.6	1.08 A
LT8x9-C-12	A420-064842-00	Continuous	12VDC	27.6	5.5	435 mA
LT8x9-I-24	A420-064845-00	Intermittent	24VDC	44.6	13.6	538 mA
LT8x9-C-24	A420-064844-00	Continuous	24VDC	109	5.5	220 mA

When ordering, please refer to Part No., as listed above.

Consult factory for custom configurations.

Pull Force (oz.)									Holding Force (oz.)
Stroke (in.)	0.050	0.125	0.250	0.375	0.500	0.625	0.750	1.000	-
Continuous Duty	25	10	5	2	0.5	N/A	N/A	N/A	24
Intermittent Duty	50	27	10	6	2	N/A	N/A	N/A	60

UL Recognition

Recognized under the 
Component Recognition Program of
Underwriters Laboratories, Inc.

Continuous Duty

100% 'On' Time

Intermittent Duty

25% 'On' Time, (100 Seconds 'On' Max.
Followed By 300 Seconds 'Off' Min.)

RoHS

These parts comply with **RoHS** Directive 2002/95/EC