


Adjustable Depth Knockdown Steel 4-Post Rack **DC4R** Series

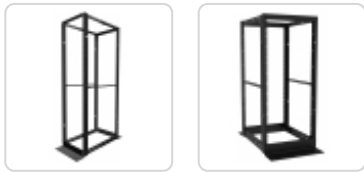

The Hammond DC4R Open Rack series is one of the most economical solutions to house IT equipment in wiring closets or data centers. In situations where the wiring closet itself is under lock and key and accessed by a limited number of people, full cabinets having locking doors and side panels may not be required resulting in a significant cost savings.

Standard Features

- Available in 24U and 44U and in two convenient adjusting depths.
 - 24"-36" for standard rackmount equipment.
 - 32"-48" for extra deep equipment.
- Two (2) pairs of 19" mounting EIA-310-D compliant square-hole rails.
 - Optional pair of rails available for multiple mounting depths.
 - Ships with a 50-pack of screws and cage nuts **1421CNABK50**.
- Mounting rails include permanent rack unit space indicators.
- Four (4) pairs of integrated 10-32 ground studs, at both the front and rear of the rack. Stud pairs are conveniently spaced 5/8" apart and located across from each other inside the rail channel. For added convenience, two (2) pairs are located near the top of the rack, while the others are near the bottom of the rack.
- Rail depth L-bracket restrict the installer from over-extending the rack. This ensures the integrity of the rack.
- Self-squaring design for a short assembly time.
- One (1) set of two (2) horizontal cable manager bars. Additional cable manager bars available by ordering part number **DC4RSHCM**.
- Finished in smooth black powder paint.
- Knockdown design ships unassembled for easy handling and shipping protection.

Specifications

- Constructed of 12-gauge steel.
- Suggested load capacity of 2,000 lb.
- RoHS Compliant.
- Manufactured in North America.

Accessories

Universal Rack Shelf

Two Post Mounting Keyboard & Equipment Shelf
Sliding Keyboard Shelf

Four Post Mounting Sliding Shelf
Hinged Acrylic Door Panel Cover

Two Post Mounting Adjustable Shelf

Rack Mount Locking Storage Drawer

Adjustable Depth 4-Post Rack Mount Shelf

Outlet Strips

Adjustable Depth Cable Manager

**Vertical Fingered Rack Cable
Manager with Door
Mounting Hardware
Grounding**

Rack Unit Label

Bolt Down Kit

Cable Management

Rack Panels

**Light Duty Caster Set for Open
Frame Rack**

Rack and Cabinet

Baying/Ganging/Joining Kit

Part No.	Overall Dimensions		Rack	Mounting Dimensions			
	Height	Width	Units	Height	Width	Min Depth	Max Depth
DC4R24	48.12	20.50	24U	42.00	19.00	24.00	36.00
DC4R2448	48.12	20.50	24U	42.00	19.00	32.00	48.00
DC4R44	83.13	20.50	44U	77.00	19.00	24.00	36.00
DC4R4448	83.13	20.50	44U	77.00	19.00	32.00	48.00

The base feet extending outwards add approx. 12 inches of overall depth.

Note: Product not available within the USA.

DC4R Specific Accessories

Part No.	Description
DC4RSHCM	Additional Horizontal Cable Bars (2)
DC4RPR24	Additional pair of rails for DC4R 24U
DC4RPR44	Additional pair of rails for DC4R 44U

Data subject to change without notice

© 2014. Hammond Manufacturing Ltd. All rights reserved.