




Quality Products. Service Excellence.

## Type 1 Unpainted Galvanized Steel Junction Box *CSG Series*

Screw Cover and without Knockouts

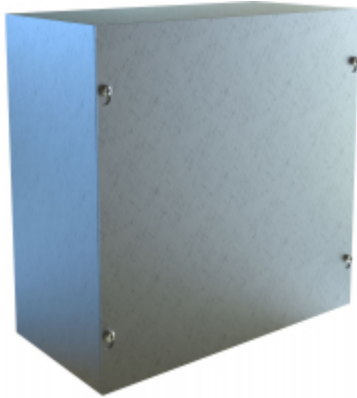

### Application

- Designed for general purpose indoor commercial use as a junction, pull or switch box.

### Standards

- UL-50 Type 1
- CSA Type 1
- Complies with
  - NEMA Type 1
  - IEC 60529, IP20

### Construction

- Formed and spot welded from 16 gauge (up to 30"x24"), 14 gauge (36"x24") or 12 gauge (36"x36") G90 steel.
- Flat steel covers fastened with plated steel screws.
- Keyhole slots permit cover to be lifted off without removing screws entirely.
- Through holes in back for wall mounting.
- Grounding location embossed in body.

### Finish

- Enclosure and cover are unpainted galvanized steel.



**New and improved PDF part drawing files with more detail now available.**

Click part number in table below to access PDF, DXF, and STEP files.

| Part No. | Enclosure |       |      |
|----------|-----------|-------|------|
|          | H         | W     | D    |
| CSG664   | 6.00      | 6.00  | 4.00 |
| CSG884   | 8.00      | 8.00  | 4.00 |
| CSG10104 | 10.00     | 10.00 | 4.00 |
| CSG12124 | 12.00     | 12.00 | 4.00 |
| CSG18184 | 18.00     | 18.00 | 4.00 |
| CSG24244 | 24.00     | 24.00 | 4.00 |
| CSG666   | 6.00      | 6.00  | 6.00 |
| CSG886   | 8.00      | 8.00  | 6.00 |
| CSG10106 | 10.00     | 10.00 | 6.00 |
| CSG12106 | 12.00     | 10.00 | 6.00 |
| CSG12126 | 12.00     | 12.00 | 6.00 |
| CSG16166 | 16.00     | 16.00 | 6.00 |
| CSG18126 | 18.00     | 12.00 | 6.00 |

| Part No.  | Enclosure |       |       |
|-----------|-----------|-------|-------|
|           | H         | W     | D     |
| CSG18186  | 18.00     | 18.00 | 6.00  |
| CSG24246  | 24.00     | 24.00 | 6.00  |
| CSG30306  | 30.00     | 30.00 | 6.00  |
| CSG36366  | 36.00     | 36.00 | 6.00  |
| CSG12128  | 12.00     | 12.00 | 8.00  |
| CSG18188  | 18.00     | 18.00 | 8.00  |
| CSG24248  | 24.00     | 24.00 | 8.00  |
| CSG30308  | 30.00     | 30.00 | 8.00  |
| CSG36368  | 36.00     | 36.00 | 8.00  |
| CSG181812 | 18.00     | 18.00 | 12.00 |
| CSG242412 | 24.00     | 24.00 | 12.00 |
| CSG303012 | 30.00     | 30.00 | 12.00 |
| CSG363612 | 36.00     | 36.00 | 12.00 |
| CSG484812 | 48.00     | 48.00 | 12.00 |
| CSG363616 | 36.00     | 36.00 | 16.00 |
| CSG484816 | 48.00     | 48.00 | 16.00 |

*Data subject to change without notice*

© 2020. Hammond Manufacturing Ltd. All rights reserved.