




Quality Products. Service Excellence.

Seismic 2-Post Open Frame Rack *DRZ4 Series*

UL2416 rated for up to 2,000 lbs (907 kg). Static Load tested to 8,000 lbs (3,628 kg). Seismic rated for up to 800 lbs (362 kg)

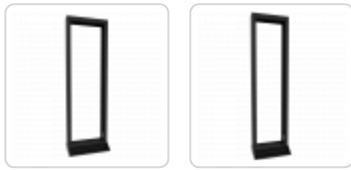

Tested by



Features

- Rugged design was engineered to perform in the most critical seismic environments.
- Increased overall width of 22.75 inches provides additional side-to-side load strength.
- EIA compliant 10-32 front and rear tapped (6.00" deep) rails with 19" mounting.
 - Includes marked rack unit dividers to aid in equipment mounting.
- Two (2) sets of side mounting holes on side of rack allows for Hammond cable managers to be mounted facing front and rear.
- The side mounting holes can also be used to gang racks together.
- Includes two (2) pairs of integrated 10-32 ground studs, spaced 5/8" apart. Stud pairs are located conveniently at both ends of the rack. The upper location is centered inside the upper channel and the lower location is centered on the front base of the rack. This upgrade ensures a secure and easy ground lug attachment.
- Includes top bracket mounting holes that are compatible with top cable accessories.
- Includes large base for freestanding support of equipment.
- Finished in smooth black powder paint.

Specifications

- Constructed in 10-gauge steel (rails) reinforced with structural angle base for maximum structure.
- UL Listed 2416 load rated for up to 2,000 lbs (907 kg). Static Load tested to 8,000 lbs (3,628 kg)
- Dynamic (seismic) load rated for up to 800 lbs (362 kg) of equipment installed and 50 lbs (22 kg) of cable weight. Requires a seismic bolt down kit such as the **C4K-Z4** (sold separately). Independently tested and certified to exceed established Seismic Zone 4 NEBS™ Telcordia® GR-63-CORE testing standards.
- TAA compliant for GSA Schedule purchases.
- RoHS Compliant.
- Manufactured in North America.



Looking for a Seismic 4-Post Open Frame Rack? See our RAAB Series for more information.

Accessories

- High-Density Vertical Finger Manager with Slam-Latching Door
- Vertical Rack Cable Manager with Door
- Horizontal Finger Cable Manager
- Two Post Mounting Adjustable Shelf
- Two Post Centered Shelf
- Two Post Heavy Duty Battery Shelf
- Vertical Finger Cable Manager with Door
- Horizontal Ring Cable Manager
- Universal Rack Shelf
- Two Post Mounting Deep Channel Shelf
- Two Post Mounting Keyboard & Equipment Shelf
- Two-Post Extension Support Bracket



- Open Frame Rack and Rack Cabinet
- Grounding & Bonding
- 10-32 Mounting Hardware
- PDUs and Outlet Strips

Part No.	Overall Dimensions			Rack Units	Mounting Dimensions			Rack Unit Indicator
	Height	Width	Depth		Height	Width	Depth	
DRZ477	84.00	22.75	18.00	44U	77.12	19.00	6.00	Hole Indicator
DRZ477S	84.00	22.75	18.00	44U	77.12	19.00	6.00	Numbered 1-44
DRZ42377	84.00	26.75	18.00	44U	77.12	23.00	6.00	Hole Indicator

4-Post Rack option also available.

Tags: **Relay Rack, H-Frame, Server Rack, Equipment Rack, Network Rack, Skeleton Rack, Telco Rack,** *Data subject to change without notice*
Two-Post Rack, seismic

© 2021. Hammond Manufacturing Ltd. All rights reserved.