

Path: [Home](#) > [Enclosure Index](#) > Development Board Plastic Enclosures

Plastic enclosures designed for the following boards
(boards NOT included):

Arduino LEONARDO,
M0 PRO, UNO or YÚN




Arduino Uno




Arduino Due



Arduino 101

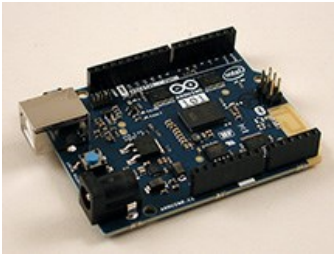

Arduino Mega 2560

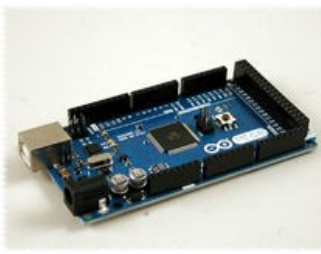

BeagleBone



BeagleBone black



BeagleBone Green



freescale KL-02Z/KL05Z



freescale FRDM-KL25Z



Intel Galileo GEN 2



Raspberry Pi B



Raspberry Pi B+ & Pi 2



Raspberry Pi 3 Model B



Key Features:

- Designs based on our popular [1593 series](#) plastic enclosures.

- Machined and/or molded to accept popular development boards - Arduino Due, Arduino Mega 2560, beaglebone, beaglebone black, freescale freedom KL-05Z, freescale freedom KL-02Z, freescale freedom KL-25Z, Intel Galileo GEN 2 or Raspberry Pi (all 4 versions).
- If you are using shields or require open access to your Arduino board we recommend our [Dev. Board Platforms](#)
- Molded in a choice of black, grey or **Translucent Blue** general purpose ABS plastic with a satin texture. Translucent clear is also available for the Raspberry Pi enclosure.
- Enclosure is machined to allow access to I/O connectors & often used controls and/or LEDs
- Enclosure is secured with self tapping screws.
- Black & Translucent Blue plastic enclosures include black screws, grey plastic enclosures include nickel finish screws.
- Includes four (4) self adhesive rubber feet & instruction sheet.
- **Development boards are NOT included.**



click to enlarge



click to enlarge

Use with Arduino
LEONARDO, M0 PRO, UNO or YÚN (boards NOT included)

Thumbnail Photo	Part Number	Color	PDF Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)
	1593HAMARBK	Black	 446K	5 Installation dependent on board model used	Inches	2.95	2.91	1.06
					mm	75	74	27
	1593HAMARGY	Gray			Inches	2.95	2.91	1.06
					mm	75	74	27
	1593HAMARTBU	Translucent Blue			Inches	2.95	2.91	1.06
					mm	75	74	27

For video information link to:



click to enlarge



click to enlarge

Use with Arduino Uno (board NOT included)

Thumbnail Photo	Part Number	Color	PDF Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)	Original Enclosure Used
	1593HAMUNOBK	Black			Inches	4.3	2.9	1.0	1593NBK
					mm	110	75	25	

	1593HAMUNOYG	Gray	 412K	2 (Front & Rear)	Inches	4.3	2.9	1.0	1593NGY
					mm	110	75	25	
	1593HAMUNOTBU	Translucent Blue			Inches	4.3	2.9	1.0	1593NTBU
					mm	110	75	25	

For video information link to:




click to enlarge



click to enlarge

Use with Arduino Due (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)	Original Enclosure Used
	1593HAMDUEBK	Black	 426K	2 (Front & Rear)	Inches	4.3	2.9	1.0	1593NBK
					mm	110	75	25	
	1593HAMDUEGY	Gray			Inches	4.3	2.9	1.0	1593NGY
					mm	110	75	25	
	1593HAMDUETBU	Translucent Blue			Inches	4.3	2.9	1.0	1593NTBU
					mm	110	75	25	

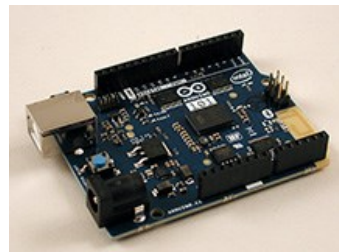



click to enlarge



click to enlarge

Use with Arduino
LEONARDO, M0 PRO, UNO, YÚN or 101 (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)
-----------------	-------------	-------	-----------------	------------------	-------	--------	-------	-----------------------------

	1593HAMAR2TBU	Translucent Blue	 399K	5 Installation dependent on board model used	Inches	4.3	2.9	1.0
					mm	110	75	25








click to enlarge



click to enlarge

Use with Arduino Mega 2560 (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)	Original Enclosure Used
	1593HAMMEGABK	Black	 260K	2 (Front & Rear)	Inches	4.3	2.9	1.0	1593NBK
					mm	110	75	25	
	1593HAMMEGAGY	Gray			Inches	4.3	2.9	1.0	1593NGY
					mm	110	75	25	
	1593HAMMEGATBU	Translucent Blue			Inches	4.3	2.9	1.0	1593NTBU
					mm	110	75	25	








click to enlarge



click to enlarge

Use with BeagleBone (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	AutoCAD .dwg Files (zipped)	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)	
	1593HAMDOGBK	Black	 390K	 220K	2 (Front & Rear)	Inches	3.75	3.04	1.18	
						mm	95	77	30	
	1593HAMDOGGY	Gray				Inches	3.75	3.04	1.18	1593NTBU
						mm	95	77	30	

	1593HAMBOGRTBU	Translucent Blue	Inches	3.75	3.04	1.18
			mm	95	77	30








click to enlarge



click to enlarge

Use with freescale freedom FRDM-KL02Z & FRDM-KL05Z (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)	Original Enclosure Used		
	1593HAMFREE1BK	Black	 248K	2 (Front & Rear)	Inches	3.6	2.6	1.1	1593LBK		
					mm	92	66	28			
	1593HAMFREE1GY	Gray			248K	2 (Front & Rear)	Inches	3.6	2.6	1.1	1593LGY
							mm	92	66	28	
	1593HAMFREE1TBU	Translucent Blue			248K	2 (Front & Rear)	Inches	3.6	2.6	1.1	1593LTBU
							mm	92	66	28	








click to enlarge



click to enlarge

Use with freescale freedom FRDM-KL25Z (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Removable Panels	Units	Length	Width	Enclosure Depth (assembled)	Original Enclosure Used		
	1593HAMFREE2BK	Black	 247K	2 (Front & Rear)	Inches	3.6	2.6	1.1	1593LBK		
					mm	92	66	28			
	1593HAMFREE2GY	Gray			247K	2 (Front & Rear)	Inches	3.6	2.6	1.1	1593LGY
							mm	92	66	28	

	1593HAMFREE2TBU	Translucent Blue			Inches	3.6	2.6	1.1	1593LTBU
					mm	92	66	28	







click to enlarge



click to enlarge

Use with the Intel Galileo GEN 2 (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	AutoCAD .dwg Files (zipped)	Units	Length	Width	Enclosure Depth (assembled)
	1593HAMGAL2TBU	Translucent Blue	 996K	 1.1M	Inches	5.71	3.09	1.79
					mm	145	78.5	45.5










click to enlarge




click to enlarge

Use with the Raspberry Pi B (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Instructions	Units	Length	Width	Enclosure Depth (assembled)
	1593HAMPIBK	Black			Inches	4.1	2.58	1.18
					mm	104.2	65.5	30.0
	1593HAMPICLR	Clear			Inches	4.1	2.58	1.18
					mm	104.2	65.5	30.0
	1593HAMPIGY	Gray	 944K	 1,720K	Inches	4.1	2.58	1.18
					mm	104.2	65.5	30.0
	1593HAMPITBU	Translucent Blue			Inches	4.1	2.58	1.18
					mm	104.2	65.5	30.0

Raspberry Pi B Enclosure - Photo Features

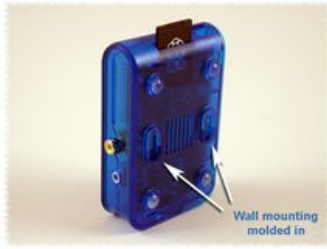

[click to enlarge](#)



[click to enlarge](#)



[click to enlarge](#)

1593HAMPITBU enclosure used in photos (Raspberry Pi board, camera & SD card NOT included)










[click to enlarge](#)



[click to enlarge](#)

Use with the Raspberry: Pi B+ OR Pi 2 Model B OR Pi 3 Model B (board NOT included)

Thumbnail Photo	Part Number	Color	 Reader File	Instructions	Units	Length	Width	Enclosure Depth (assembled)
	1593HAMP13BK	Black			Inches	3.88	2.74	1.16
					mm	98.54	69.49	29.6
	1593HAMP13CLR	Clear			Inches	3.88	2.74	1.16
					mm	98.54	69.49	29.6
	1593HAMP13GY	Gray	 1.5M	 2.4M	Inches	3.88	2.74	1.16
					mm	98.54	69.49	29.6
	1593HAMP13TBU	Translucent Blue			Inches	3.88	2.74	1.16
					mm	98.54	69.49	29.6

Raspberry Pi 3 Enclosure - Photo Features



[click to enlarge](#)



[click to enlarge](#)



[click to enlarge](#)

1593HAMP13TBU enclosure used in photos.
Board, camera & micro SD card NOT included.



668K

DOWNLOAD

catalog pages on this series (671K) [9C-Dev-Board.pdf](#)

Exactly what you are looking for???

Link to our stocking distributors - most have "on-line" pricing, stock check and ordering!!!

[Our Distributors](#)

[Order from your favorite distributor](#)

[Home](#) | [Products](#) | [Distributors](#) | [Technical](#) | [Contact Us](#) | [Other Options](#)

Copyright; © 2013-2016 Hammond Mfg Co Inc

URL: <http://www.hammondmfg.com>