




*Quality Products. Service Excellence.*

## Knockdown Economy Rack Cabinet *REFK Series*

1,000 lbs|454 kg Weight Capacity

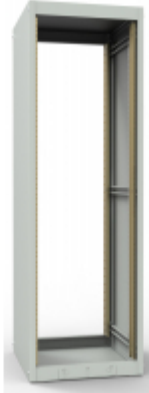

### Features




- Constructed in 16-gauge steel (body) and 10-gauge steel (rails).
- Two pairs of infinitely adjusting 19" mounting EIA-310-D compliant 10-32 tapped combination rails.
- Finished in either Black or Light Gray (RAL7035) rugged textured powder paint.
- Ships unassembled in a flat pack container for easy handling and shipping protection.
- Perfect for tight access areas or one person installations as unit is knocked down into five (5) easy to handle parts.

### Specifications

- Includes four (4) leveling feet.
- Rails are made of 10 gauge steel (zinc plated finish for grounding capabilities).
- Removable gland plate - over 10" (254 mm) long x 1.5" (38 mm) high opening - with knockouts on rear bottom of rack for easy cable access.
- Simple assembly using one bolt in each corner to lock the sides to the top and bottom (hardware included).
- Tested to nearly double the suggested load rating of 1,000 lbs (454 kg).
- TAA Compliant.
- RoHS Compliant.
- Manufactured in North America.




### Gallery

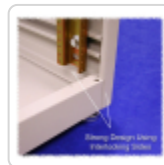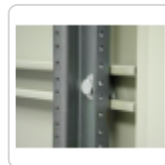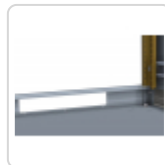

### Accessories

- Universal Rack Shelf
- Four Post Mounting Sliding Shelf
- Sliding Keyboard Shelf
- Adjustable Depth Shelf
- Rack Mount Locking Storage Drawer
- Four Post Mounting Zero Space Fixed Shelf
- Four Post Fixed Depth Shelf
- 10-32 Mounting Hardware
- Outlet Strips
- Rack Unit Label
- Adjustable Depth Cable Manager
- Horizontal Lacing Strip
- Horizontal Ring Cable Manager
- Horizontal Hinged Cable Manager
- Cable Management Arm
- Horizontal Steel Finger Cable Manager
- Rack Panels
- Grounding
- Lite Duty Caster Set
- Light Duty Caster Set
- 10-32 Tapped Formed Mounting Rail
- Square Hole Punched Mounting Rail

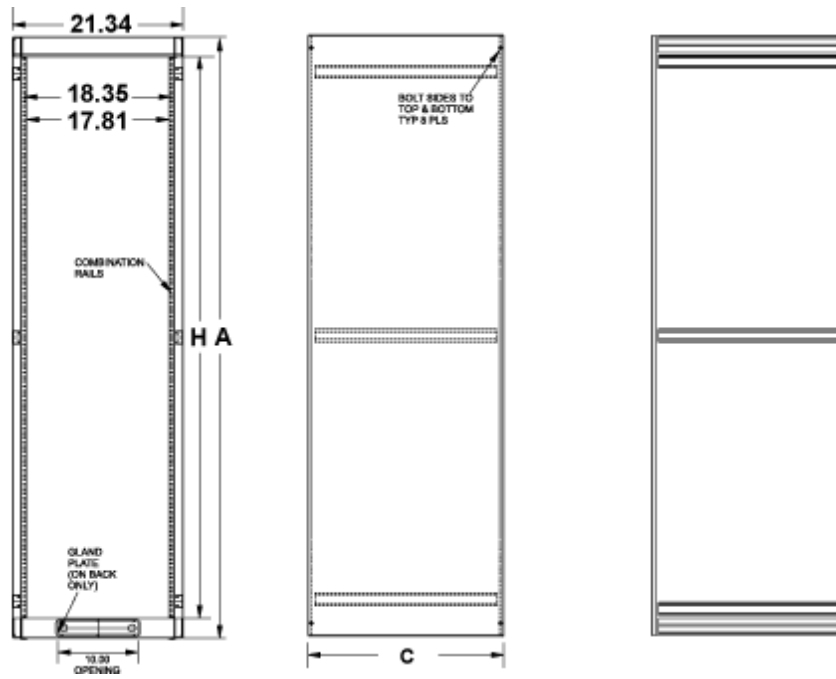

Part No. Black	Part No. RAL 7035 Light Gray	Overall Dimensions			Rack Units	Usable Mounting Dimensions		
		Height A	Width C	Depth		Height H	Depth	Depth (With Doors)
REFK1903517BK1	REFK1903517LG1	40.19	21.34	17.50	20U	35.19	16.50	16.00
REFK1904217BK1	REFK1904217LG1	47.19	21.34	17.50	24U	42.19	16.50	16.00
REFK1904917BK1	REFK1904917LG1	54.19	21.34	17.50	28U	49.19	16.50	16.00
REFK1905617BK1	REFK1905617LG1	61.19	21.34	17.50	32U	56.19	16.50	16.00
REFK1906317BK1	REFK1906317LG1	68.19	21.34	17.50	36U	63.19	16.50	16.00
REFK1907017BK1	REFK1907017LG1	75.19	21.34	17.50	40U	70.19	16.50	16.00
REFK1907717BK1	REFK1907717LG1	82.19	21.34	17.50	44U	77.19	16.50	16.00
REFK1903524BK1	REFK1903524LG1	40.19	21.34	24.50	20U	35.19	23.50	23.00
REFK1904224BK1	REFK1904224LG1	47.19	21.34	24.50	24U	42.19	23.50	23.00
REFK1904924BK1	REFK1904924LG1	54.19	21.34	24.50	28U	49.19	23.50	23.00
REFK1905624BK1	REFK1905624LG1	61.19	21.34	24.50	32U	56.19	23.50	23.00
REFK1906324BK1	REFK1906324LG1	68.19	21.34	24.50	36U	63.19	23.50	23.00
REFK1907024BK1	REFK1907024LG1	75.19	21.34	24.50	40U	70.19	23.50	23.00
REFK1907724BK1	REFK1907724LG1	82.19	21.34	24.50	44U	77.19	23.50	23.00
REFK1903531BK1	REFK1903531LG1	40.19	21.34	31.50	20U	35.19	30.50	30.00
REFK1904231BK1	REFK1904231LG1	47.19	21.34	31.50	24U	42.19	30.50	30.00
REFK1904931BK1	REFK1904931LG1	54.19	21.34	31.50	28U	49.19	30.50	30.00
REFK1905631BK1	REFK1905631LG1	61.19	21.34	31.50	32U	56.19	30.50	30.00
REFK1906331BK1	REFK1906331LG1	68.19	21.34	31.50	36U	63.19	30.50	30.00
REFK1907031BK1	REFK1907031LG1	75.19	21.34	31.50	40U	70.19	30.50	30.00
REFK1907731BK1	REFK1907731LG1	82.19	21.34	31.50	44U	77.19	30.50	30.00

**REFK Locking Doors**

Solid Door Part No. Black	Solid Door Part No. RAL 7035 Light Gray	Louvered Door Part No. Black	Louvered Door Part No. RAL 7035 Light Gray	Window Door Part No. Black	Use With REFK Frame		
				Height	Rack Units	Part No.	
RSDf19035BK1	RSDf19035LG1	RSDL19035BK1	RSDL19035LG1	REDFP19035BK1	35.00	20U	REFK1903524
RSDf19042BK1	RSDf19042LG1	RSDL19042BK1	RSDL19042LG1	REDFP19042BK1	42.00	24U	REFK1904224
RSDf19049BK1	RSDf19049LG1	RSDL19049BK1	RSDL19049LG1	REDFP19049BK1	49.00	28U	REFK1904924
RSDf19056BK1	RSDf19056LG1	RSDL19056BK1	RSDL19056LG1	REDFP19056BK1	56.00	32U	REFK1905624
RSDf19063BK1	RSDf19063LG1	RSDL19063BK1	RSDL19063LG1	REDFP19063BK1	63.00	36U	REFK1906324
RSDf19070BK1	RSDf19070LG1	RSDL19070BK1	RSDL19070LG1	REDFP19070BK1	70.00	40U	REFK1907024

Solid Door	Solid Door	Louvered Door	Louvered Door	Window Door	Use With REFK Frame		
Part No.	Part No.	Part No.	Part No.	Part No.	Height	Rack Units	Part No.
Black	RAL 7035 Light Gray	Black	RAL 7035 Light Gray	Black	77.00	44U	REFK1907724
RSD19077BK1	RSD19077LG1	RSDL19077BK1	RSDL19077LG1	REDFP19077BK1			

Tags: knock-down, knock down

Data subject to change without notice

© 2019. Hammond Manufacturing Ltd. All rights reserved.