



Features and Benefits

Weatherproof Cable Reels

- Powder coated, solid steel construction
- Multi-position roller guide can be mounted in four different positions
- Ratchet lock can be disengaged in field for constant tension application
- UL Type 4X enclosure protects spring motor, junction box, slip ring assembly and cable entrance from hosedown or corrosion
- Optional pivot base allows 340° rotation of reel and increases range of cable to nearly any direction



HBL501242W
with **HBL16PB**



HBL501242W
with **HBL16PB**

Weatherproof Cable Reels, 50 Ft. (15.2m)

| Description | Cable Type | Amps | Volts AC | Weight Lbs. (kg) | Catalog Number |
|--|-------------|------|----------|------------------|----------------------|
| 14" weatherproof reel. | #14/3 SOW-A | 15 | 600 | 55 (24.9) | HBL501431W* |
| 16" weatherproof reel. | #12/3 SOW-A | 20 | 600 | 80 (36.3) | HBL501232W* |
| 16" weatherproof reel, (white reel housing). | #12/3 SOW-A | 20 | 600 | 80 (36.3) | HBL501232WM1* |
| 16" weatherproof reel. | #12/4 SOW-A | 16 | 600 | 86 (39.0) | HBL501242W* |
| 16" weatherproof reel. | #10/3 SOW-A | 25 | 600 | 86 (39.0) | HBL501032W* |
| 16" weatherproof reel, (white reel housing). | #10/3 SOW-A | 25 | 600 | 86 (39.0) | HBL501032WM1* |
| 16" weatherproof reel. | #10/4 SOW-A | 20 | 600 | 92 (41.7) | HBL501042W* |

Note: *All weatherproof cable reels are supplied with wire leads and 3/4" NPT hub feed. Power supply cable not supplied.



HBL14PB

Accessories


| Description | Weight Lbs. (kg) | Description |
|-------------------|------------------|----------------|
| 14" pivot base. | 5 (2.3) | HBL14PB |
| 16" pivot base. | 13 (5.9) | HBL16PB |
| Replacement stop. | .2 (.09) | HBLWPBS |

Specifications

| | |
|-----------------------|--|
| Listing/Certification | UL 355 and CSA, C22.2 No. 21. |
| Environment | Type 4X enclosure, CAN/CSA - C22.2 No. 21. Dry, indoor and wet and damp outdoor non-hazardous location. |

Dimensions


| Inch (mm) | A | B | C | D | E | F | G | H | I | J |
|-----------|----------------|----------------|-----------------|-----------------|---------------|-----------------|----------------|----------------|----------------|----------------|
| 14" Reel | 6.50" (165) | 8.12" (206) | 16.25" (413) | 13.75" (349) | 3.00" (76) | 12.19" (310) | 3.00" (76) | 3.00" (76) | 3.00" (76) | 6.50" (165) |
| 16" Reel | 6.50" (165) | 9.12" (232) | 18.25" (464) | 15.75" (400) | 3.00" (76) | 14.19" (360) | 6.00" (152) | 6.00" (152) | 4.94" (125) | 6.50" (165) |

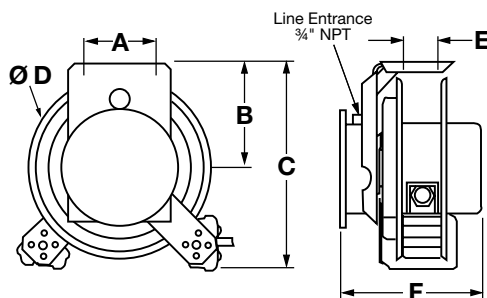

Dimensions in Inches (mm)

Pivot Base

340° Pivot Base (Optional)

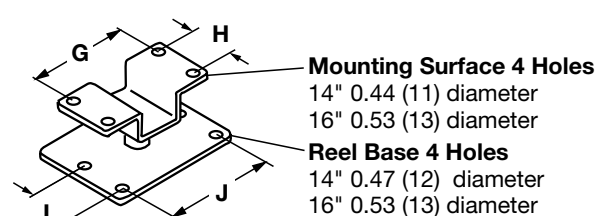

Note: Pivot base for use only with Weatherproof Cable Reel.