

2-Pole 3-Wire Grounding 15 Amp 125V Side Wired Heavy-Duty Receptacles

Features - Specifications

- Full-face, wraparound design is molded of high-impact, chemical-resistant nylon
- Heavy-duty wraparound steel yoke locked in for maximum strength and security
- Terminal screws: brass combination Phillips/slotted/Robertson binding head accepts up to #10 wire
- Approved for CU wire only
- Large green, combination Phillips/slotted/Robertson hex head grounding screw backed out and staked for easy wiring
- Grounding screw terminal plate forms retention cup for secure termination
- Center splined bushing interlocks with receptacle body to prevent rotation when fastening wall plates (5242)
- Easily accessible break-off tab for two-circuit wiring (5242)
- One-piece triple-wipe brass line contacts
- Double-wipe brass grounding contacts
- Thread cleaning captive mounting screws
- UL Listed File #E2258 – Guide #RTRT
- CSA Certified File #LR16215 – Guide #365E1
- Verified under Fed. Spec. #WC596
- Complies with NEMA Standards WD-1, WD-6 and UL 498
- NOM



5242




5251

CATALOG NUMBER		DESCRIPTION
DUPLEX	SINGLE	
5242	5251	Brown, nylon construction, self-grounding
5242C	—	Same as above except with Robertson head screws
5242BLK	—	Black, nylon construction, self-grounding
5242GRY	—	Gray, nylon construction, self-grounding
5242I	5251I	Ivory, nylon construction, self-grounding
5242IC	—	Same as above except with Robertson head screws
5242RED	—	Red, nylon construction, self-grounding
5242REDC	—	Same as above except with Robertson head screws
5242W	—	White, nylon construction, self-grounding
524244	—	Black, nylon construction with four .250 inch (6.4) quick connect terminals, less mounting yoke, mounting screws and ground clip



524244

PRODUCT DIMENSIONS – () Indicates mm dimensions

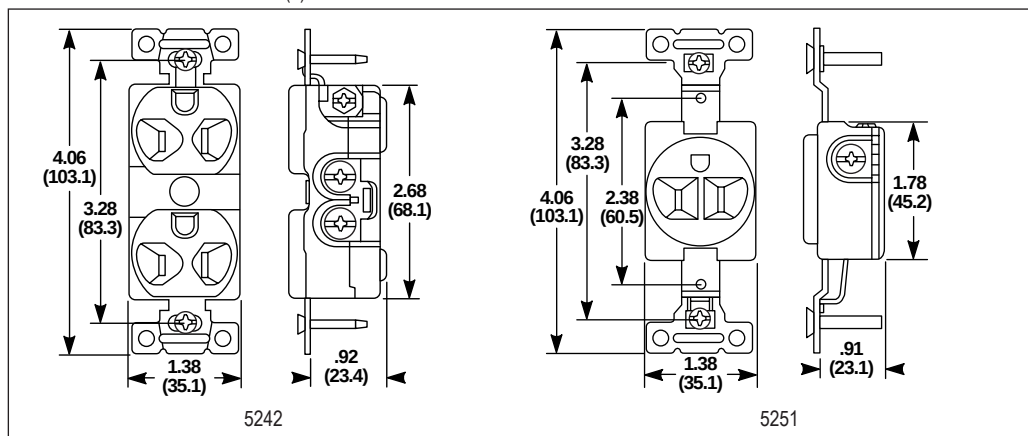

Specifications are subject to change without notice.