

**Features - Specifications**

- One-piece grounding system including integral self-grounding strap (BRY5262 series)
- Full-face, wraparound design is molded of high-impact, chemical-resistant nylon
- Extended barrier (shroud) on sides of cover surround wire terminals for added insulation and isolation of conductors
- Heavy-duty wraparound steel yoke locked in for maximum strength and security
- Double-plated yoke (nickel & brass) to resist corrosion (except 5284)
- Back wiring: eight wiring pockets for convenient feed thru wiring, clamp-type terminals accept up to #10 wire (5261, 5284 & 5258 – four wiring pockets)

- Terminal screws: brass combination Phillips/slotted/Robertson binding head accepts up to #10 wire
- Approved for CU wire only
- Large green, combination Phillips/slotted/Robertson hex head grounding screw
- Back wire ground clamp for quick and convenient wiring
- Center splined bushing interlocks with receptacle body to prevent rotation when fastening wall plates (BRY5262)
- Easily accessible break-off tab for two-circuit wiring (BRY5262)
- ID surface on cover for marking clear identification of circuits
- One-piece triple-wipe brass line contacts
- Double-wipe brass grounding contacts

- Strip gauge for accurate wiring
- Verified under Fed. Spec. #WC596 (where applicable)
- UL Listed File #E2258 – Guide #RTRT
- CSA Certified File #LR16215 – Guide #365E1
- Complies with NEMA Standards WD-1, WD-6 and UL 498
- NOM



BRY5262I



5261I



5284



5258

CATALOG NUMBER		DESCRIPTION
DUPLX	SINGLE	
BRY5262	5261	Brown, nylon construction, self-grounding
BRY5262BLK	5261BLK	Black, nylon construction, self-grounding
BRY5262GRY	5261GRY	Gray, nylon construction, self-grounding
BRY5262I	5261I	Ivory, nylon construction, self-grounding
BRY5262RED	5261RED	Red, nylon construction, self-grounding
BRY5262W	5261W	White, nylon construction, self-grounding
BRY5262BU	—	Blue, nylon construction, self-grounding
BRY5282	5281	5262/5261 on 4" round metal box cover

**SHORT YOKE RECEPTACLES**

—	5284	Brown, nylon construction, self-grounding 1.94 mounting dim.
—	5258	Brown, urea face, side wired, 1.75 mounting dim.


**CORROSION RESISTANT RECEPTACLES ①**

BRY5262BCR	—	Brown, nylon construction, self-grounding
BRY5262CR	5261CR	Yellow, nylon construction, self-grounding

**ISOLATED GROUND RECEPTACLES ②**

BRY5262IG	5261IG	Orange, nylon construction
BRY5262IGGRY	5261IGGRY	Gray, nylon construction
BRY5262IGI	5261IGI	Ivory, nylon construction
BRY5262IGW	5261IGW	White, nylon construction

**PRODUCT DIMENSIONS – ( ) Indicates mm dimensions**

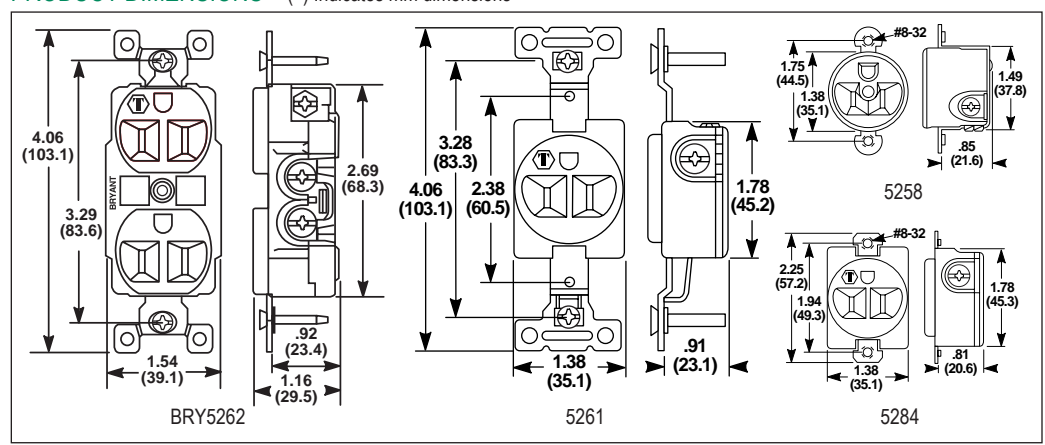

① See page I-3 for corrosion resistant Features - Specifications.  
 ② See page G-13 for isolated ground Features - Specifications.  
 Specifications are subject to change without notice.