

Isolated Ground Locking Receptacles

Features - Specifications

20/30 AMP SINGLE RECEPTACLE

- Impact/chemical-resistant nylon face
- Base molded of reinforced thermoplastic polyester
- Combination back and side wiring, clamp-type terminals, accept #14 through #8 AWG solid or stranded conductors
- Deep slotted #10 bronze terminal screws resist corrosion and are color-coded for easy identification
- One-piece rivetless copper-alloy contact design

15 AMP SINGLE RECEPTACLE

- Face and base molded of impact/chemical-resistant nylon
- One-piece rivetless copper-alloy contacts
- .050 (1.3) brass yoke
- Deep slotted #8 brass terminal screws; terminals accept up to #12 solid or stranded conductors

DUPLEX RECEPTACLE

- RTP ① construction
- Back wired, individual wiring pockets, clamp-type terminals
- Terminals accept up to #12 solid or stranded conductors

ALL RECEPTACLES

- UL Listed File #E2258 – Guide #RTRT
- CSA Certified File #LR16215 – Guide #365E1
- Comply with NEMA Standards WD-6; UL 498
- Comply with performance requirements of Federal Specification WC596
- NOM
- CE



NEW!

4700DRIG



4710IG



70520IG




72130IG

ISOLATED GROUND RECEPTACLES

CATALOG NUMBER	RATING	CONFIG.	NEMA NUMBER	DESCRIPTION
4700DRIG	2-Pole 3-Wire 15 Amp 125V		L5-15R	Duplex, back wired, orange RTP ①
4710IG ②	2-Pole 3-Wire 15 Amp 125V		L5-15R	Single, side wired, orange nylon face
70615DRIG ②	2-Pole 3-Wire 15 Amp 250V		L6-15R	Duplex, back wired, orange RTP ①
70615IG ②	2-Pole 3-Wire 15 Amp 250V		L6-15R	Single, side wired, orange nylon face
70520IG	2-Pole 3-Wire 20 Amp 125V		L5-20R	Single, back or side wired, orange nylon face
70620IG	2-Pole 3-Wire 20 Amp 250V		L6-20R	Single, back or side wired, orange nylon face
70530IG	2-Pole 3-Wire 30 Amp 125V		L5-30R	Single, back or side wired, orange nylon face
70630IG	2-Pole 3-Wire 30 Amp 250V		L6-30R	Single, back or side wired, orange nylon face
71420IG	3-Pole 4-Wire 20 Amp 125/250V		L14-20R	Single, back or side wired, orange nylon face
71430IG	3-Pole 4-Wire 30 Amp 125/250V		L14-30R	Single, back or side wired, orange nylon face
72120IG	4-Pole 5-Wire 20 Amp 120/208V 3ØY		L21-20R	Single, back or side wired, orange nylon face
72130IG	4-Pole 5-Wire 30 Amp 120/208V 3ØY		L21-30R	Single, back or side wired, orange nylon face

PRODUCT DIMENSIONS – () Indicates mm dimensions

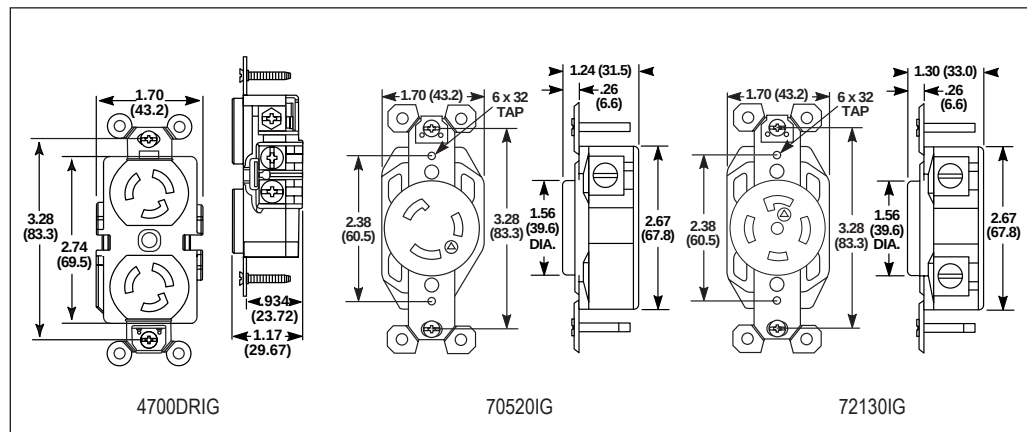

① Reinforced Thermoplastic Polyester
② See page H-8 and H-10 for dimensions on 4710 and 70615 series receptacles.

Specifications are subject to change without notice.