

Straight Blade Devices

15A, 250V, 2 Pole, 3 Wire Grounding

Heavy Duty Specification Grade Single Receptacle

Features

- One-piece brass integral ground strap
- Unique bypass contact design

Ordering Information

| Description          | Device Color | UPC          | Catalog Number |
|----------------------|--------------|--------------|----------------|
| Flush, back and side | Brown        | 783585013992 | HBL5661        |

Listings


UL Listed to UL498 File No. E2186  
Certified to CSA 22.2, No. 42 File 285  
NEMA® WD-6 Compliant  
NEMA® WD-6 Compliant

Specifications

|                          |                     |
|--------------------------|---------------------|
| Face                     | Nylon               |
| Base                     | PBT                 |
| Power Contacts           | .037 in. (.9) Brass |
| Ground Contact           | Brass               |
| Mounting Strap           | .050" (1.3) Brass   |
| Auto Self-grounding Clip | Stainless steel     |
| Mounting Screws          | Zinc plated steel   |

Performance

|                         |                                                          |
|-------------------------|----------------------------------------------------------|
| <b>Electrical</b>       |                                                          |
| Current Interrupting    | Certified for current interrupting at full rated current |
| Dielectric Voltage      | Withstands 2,000V minimum                                |
| <b>Mechanical</b>       |                                                          |
| Product Identification  | Ratings are a permanent part of the device               |
| Terminal Accommodation  | #12-#10 AWG copper stranded or solid conductor only      |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA   |
| <b>Environmental</b>    |                                                          |
| Flammability            | Top: UL 94V-2, Base: UL 94V-0                            |
| Operating Temperatures  | Maximum continuous 75°C; minimum -40°C (w/o impact)      |

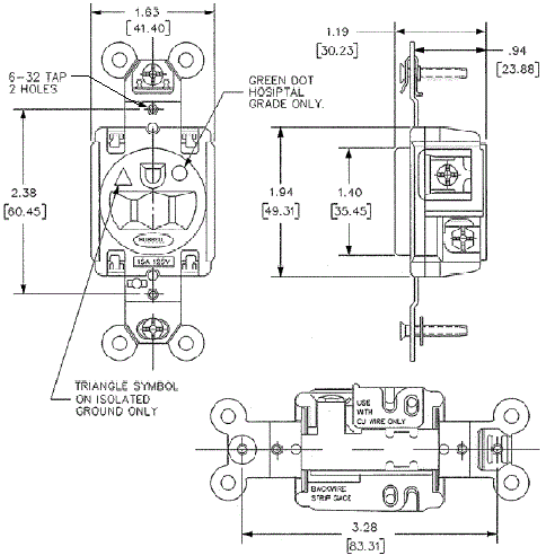

Online Resources

- Customer Use Drawing
- eCatalog
- Installation Instructions

Accessories

|                                 |               |
|---------------------------------|---------------|
| Wallplate or Weatherproof Cover | 1.40" Opening |
|---------------------------------|---------------|

