



**50A, 125V,  
2 Pole, 3 Wire Grounding,  
Receptacles and Plugs**

**IP20**  
SUITABILITY



**50A 125V  
NEMA 5-50R  
UL CSA  
2 HP**



**50A 125V  
NEMA 5-50P  
UL CSA  
2 HP**

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL9360</b>
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	<b>HBL9361</b>



**50A, 250V,  
2 Pole, 3 Wire Grounding,  
Receptacles and Plugs**

**IP20**  
SUITABILITY




**50A 250V  
NEMA 6-50R  
UL CSA  
3 HP**



**50A 250V  
NEMA 6-50P  
UL CSA  
3 HP**

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL9367</b>
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	<b>HBL9368</b>

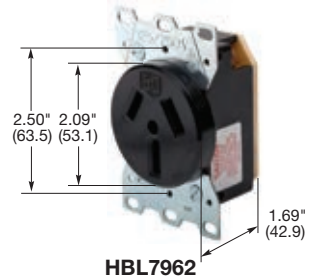

**50A, 277V AC,  
2 Pole, 3 Wire Grounding,  
Receptacles and Plugs**

**IP20**  
SUITABILITY




**50A 277V AC  
NEMA 7-50R  
UL CSA  
5 HP**



**50A 277V AC  
NEMA 7-50P  
UL CSA  
5 HP**

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	-	<b>HBL9365</b>
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	<b>HBL9379</b>

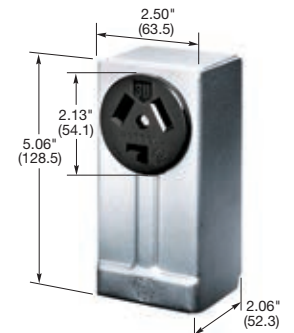

**50A, 125/250V,  
3 Pole, 3 Wire Non-Grounding,  
Receptacles, Connector Body and Plugs**



**IP20**  
SUITABILITY




**50A 125/250V  
NEMA 10-50R  
UL Listed  
3(2) HP**



**50A 125/250V  
NEMA 10-50P  
UL Listed  
3(2) HP**

Description	Cord Diameter	Catalog Number
Receptacle, black phenolic.	-	<b>HBL7962</b>
Receptacle, surface mount aluminum housing.	-	<b>HBL7940</b>
Connector body, Insulgrip, nylon.	.625"-1.218" (15.9-30.9)	<b>HBL7515C</b>
Plug, Insulgrip, nylon.	.625"-1.218" (15.9-30.9)	<b>HBL7513C</b>
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	<b>HBL7977</b>

Representative of surface mount receptacle

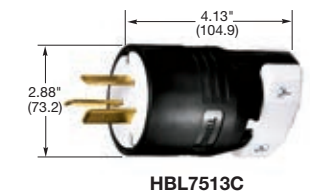

Note: RTP is an abbreviation for reinforced thermoplastic polyester.  
See page A-48 for accessories.

Dimensions in Inches (mm)