

## Straight Blade Devices 20 Ampere, 125/250 Volts and 3Ø 250 Volts AC

3 Pole, 3 Wire Non-Grounding; 3 Pole, 4 Wire Grounding; 4 Pole 4 Wire Non-Grounding  
Receptacles and Plugs



### 20A, 125/250V 3 Pole, 3 Wire Non-Grounding Receptacles and Plugs

**IP20**  
SUITABILITY



20A 125V/250V  
NEMA 10-20R  
UL Listed  
2(1) HP



20A 125V/250V  
NEMA 10-20P  
UL Listed  
2(1) HP



HBL6810

Description	Cord Diameter	Catalog Numbers
Receptacle, black phenolic.	-	HBL6810
Plug, Insulgrip®, nylon.	.385"-.780" (9.8-19.8)	HBL9977C

Notes: Horsepower ratings listed above are AC only.  
Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).  
Those in parentheses are phase to neutral (120V AC).  
See page A-44 for accessories.



HBL9977C



### 20A, 125/250V 3 Pole, 4 Wire Grounding Receptacles and Plugs

**IP20**  
SUITABILITY



20A 125V/250V  
NEMA 14-20R  
UL CSA  
2(1) HP




20A 125V/250V  
NEMA 14-20P  
UL CSA  
2(1) HP



HBL8410

Description	Cord Diameter	Catalog Numbers
Receptacle, black nylon body, back & side wired.	-	HBL8410
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	HBL8411C

Note: See page A-44 for accessories.

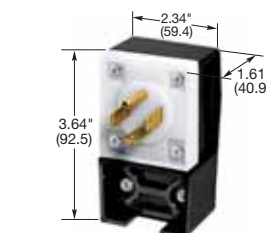

HBL8411C



### 20A, 3Ø 250V AC 3 Pole, 4 Wire Grounding Receptacles and Plugs


**IP20**  
SUITABILITY



20A 3Ø 250V AC  
NEMA 15-20R  
UL CSA  
3 HP



20A 3Ø 250V AC  
NEMA 15-20P  
UL CSA  
3 HP

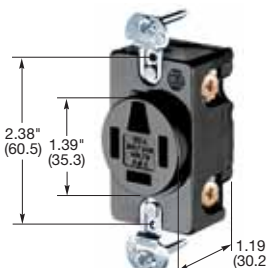

HBL8420

Description	Cord Diameter	Catalog Numbers
Receptacle, black nylon body, back & side wired.	-	HBL8420
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	HBL8421C

Notes: See page A-44 for accessories.  
Horsepower ratings listed above are AC only.  
Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).  
Horsepower ratings in parentheses are phase to neutral (120V AC).



HBL8421C



### 20A, 3ØY 120/208V AC 4 Pole, 4 Wire Non-Grounding Receptacles and Plugs

**IP20**  
SUITABILITY



20A 3ØY 120/208V AC  
NEMA 18-20R  
UL Listed  
2 HP



20A 3ØY 120/208V AC  
NEMA 18-20P  
UL Listed  
2 HP



HBL7250

Description	Cord Diameter	Catalog Numbers
Receptacle, black nylon body.	-	HBL7250
Plug, nylon, angle, 4-position.	.390"-.775" (9.9-19.7)	HBL7251C

Notes: Horsepower ratings are phase to phase (208 to 240V AC).  
Weatherproof boots for plugs not available.  
See page A-44 for accessories.