 



MULTI-CONNECT®

Recessed Wall Boxes


Screw and Snap-In Type Face Plates



 Duplex



Style Line

 

Toggle




Blank



Hubbell

Modular Face Plates*

Color	Catalog Numbers				
White	HBLST302SWA	HBLDE301SWA	HBLTO310SWA	HBLBL300SWA	HBL317SWA
Ivory	HBLST302SI	HBLDE301SI	HBLTO310SI	HBLBL300SI	HBL317SI
Black	HBLST302SBK	HBLDE301SBK	HBLTO310SBK	HBLBL300SBK	HBL317SBK
Gray	HBLST302SGY	HBLDE301SGY	HBLTO310SGY	HBLBL300SGY	HBL317SGY

 


AMP



AMP-ACO



 Krone/Leviton



Avaya (Lucent)



NORDX

Modular Face Plates*


Color	Catalog Numbers				
White	HBLAMP313SWA	HBLAM303SWA	HBLKR314SWA	HBLLT309SWA	HBLNO309SWA
Ivory	HBLAMP313SI	HBLAM303SI	HBLKR314SI	HBLLT309SI	HBLNO309SI
Black	HBLAMP313SBK	HBLAM303SBK	HBLKR314SBK	HBLLT309SBK	HBLNO309SBK
Gray	HBLAMP313SGY	HBLAM303SGY	HBLKR314SGY	HBLLT309SGY	HBLNO309SGY



NORDX DVO1



 
NORDX DVO2



Ortronics



 
Ortronics #2




Panduit

Modular Face Plates*

Color	Catalog Numbers				
White	HBLNO311SWA	HBLNO312SWA	HBLOR306SWA	HBLORT322SWA	HBLPA308SWA
Ivory	HBLNO311SI	HBLNO312SI	HBLOR306SI	HBLORT322SI	HBLPA308SI
Black	HBLNO311SBK	HBLNO312SBK	HBLOR306SBK	HBLORT322SBK	HBLPA308SBK
Gray	HBLNO311SGY	HBLNO312SGY	HBLOR306SGY	HBLORT322SGY	HBLPA308SGY

 

Siemon #1

 

Siemon #2

Modular Face Plates*

Color	Catalog Numbers	
White	HBLSI305SWA	HBLSI315SWA
Ivory	HBLSI305SI	HBLSI315SI
Black	HBLSI305SBK	HBLSI315SBK
Gray	HBLSI305SGY	HBLSI315SGY

Notes: *Catalog numbers listed above are traditional screw type. For snap-in style plates, eliminate "S" suffix from catalog number, (i.e. HBLST302SWA- screw type. HBLST302WA- snap-in type). See Page L-28 for technical information.

Floor and Wall Boxes

Raised Access Floor Boxes




Hubbell offers a complete line of recessed stamped steel floor boxes for raised floor applications. These multi-service boxes are available in four or eight gang options and utilize modular face plates. Single gang face plate options include blank, toggle, Style Line®, duplex and various manufacturers' data openings. The reversible metallic cover/flange assembly features a large cable door to provide ample room for exiting cables. Pour boxes are also available to allow raised access floor boxes to be used in concrete slab-on-grade applications. All Hubbell raised access floor boxes are acceptable for use in environmental air handling spaces other than ducts or plenums per NEC article 300.22(C) other space used for environmental air and are UL Listed.




HBLAFB301BASE




HBLTCGNT

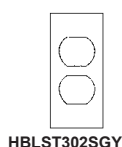


HBLST302SGY

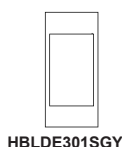


HBLDE301SGY

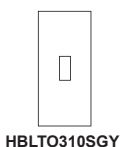


HBLTO310SGY

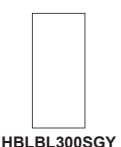



HBLBL300SGY

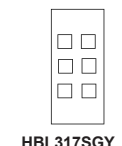


HBL317SGY

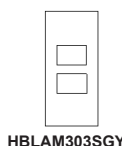


HBLAM303SGY

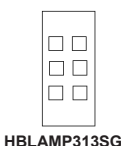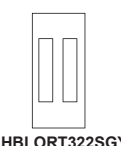HBLAMP313SGY
HBLKR314SGY


HBLORT322SGY

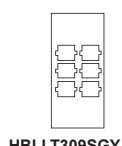


HBLLT309SGY

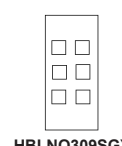


HBLNO309SGY

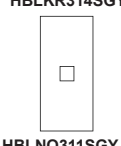


HBLNO311SGY

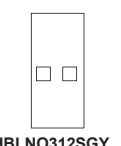


HBLNO312SGY

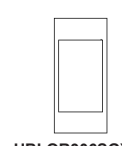


HBLOR306SGY

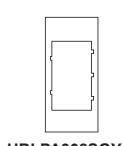

HBLPA308SGY

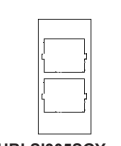

HBLSI305SGY

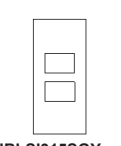

HBLSI315SGY

Raised Access Floor Box

Step 1: Select recessed floor box.

Description	Catalog Numbers
Stamped steel, 4-gang, deep.	HBLAFB301BASE
Stamped steel, 4-gang, shallow.	HBLAFB401BASE
Stamped steel, 8-gang, deep.	HBLAFB501BASE
Stamped steel, 4-gang, deep, Chicago approved.	HBLAFB301BASEC**
Stamped steel, 4-gang, shallow, Chicago approved.	HBLAFB401BASEC**
Stamped steel, 8-gang, deep, Chicago approved.	HBLAFB501BASEC**
Pour box for 4-gang box.	HBL301401PB*
Pour box for 8-gang box.	HBL501PB*

Notes: * Converts raised access floor box to be used in concrete applications.

** City of Chicago Approved, Construction Meets Requirements For CCEA-2000.

Step 2: Select cover assembly.

Description	Color	Catalog Numbers
Steel cover and flange assembly, reversible.	Granite Black	HBLTCGNT HBLTCGNTBK

Step 3: Select screw type modular face plate, gray.

Description	Catalog Numbers
Duplex.	HBLST302SGY
Style Line.	HBLDE301SGY
Toggle.	HBLTO310SGY
Blank.	HBLBL300SGY
Hubbell.	HBL317SGY
AMP-ACO.	HBLAM303SGY
AMP.	HBLAMP313SGY
Krone/Leviton.	HBLKR314SGY
Avaya (Lucent).	HBLLT309SGY
NORDX.	HBLNO309SGY
NORDX DVO1.	HBLNO311SGY
NORDX DVO2.	HBLNO312SGY
Ortronics.	HBLOR306SGY
Ortronics #2.	HBLORT322SGY
Panduit.	HBLPA308SGY
Siemon.	HBLSI305SGY
Siemon #2.	HBLSI315SGY

Specifications

Catalog Numbers	L Length	W Width	H Height	Wiring Chamber Cubic Inch Cap.	Conduit Knockouts▽
HBLAFB301BASE(C)	10.00" (254.0)	10.00" (254.0)	4.00" (101.6)	4 x 29.5 (483.0)	1/2", 3/4", 1", 1 1/4"
HBLAFB401BASE(C)	10.00" (254.0)	10.00" (254.0)	2.63" (66.7)	4 x 25.5 (418.0)	1/2", 3/4"
HBLAFB501BASE(C)	10.00" (254.0)	10.00" (254.0)	5.13" (130.2)	4 x 49.5 (811.0)	1/2", 3/4", 1", 1 1/4"
HBL301401PB	12.00" (304.8)	12.00" (304.8)	4.30" (109.2)	-	-
HBL501PB	12.00" (304.8)	12.00" (304.8)	5.25" (133.4)	-	-
Catalog Numbers	Gangs	Cubic Inch Capacity (mm)	Notes: ▽ Chicago approved series do not include knockouts UL File no. E197203. CSA File No. LR702145.		
HBLAFB301BASE	4	283.0 (4632.0)			
HBLAFB401BASE	4	212.5 (3482.0)			
HBLAFB501BASE	8	448.0 (7341.0)			