

2-Pole 3-Wire Grounding Corrosion-Resistant Straight Blade Devices

Features - Specifications

RECEPTACLE

- Metal parts have .0003 nickel plating to resist corrosion
- Copper-alloy contacts, terminals and self-grounding strap
- Stainless steel mounting screws
- Nickel-plated brass yoke
- Back wiring: eight wiring pockets for convenient feedthru wiring, clamp-type terminals accept up to #10 wire
- Approved for CU wire only
- Terminal screws: brass combination Phillips/slotted/Robertson binding head, accepts up to #10 wire
- Verified under Fed. Spec. #WC596. See page P-1 for complete listing.

- One-piece grounding system with built-in self-grounding strap
- High-visibility yellow color
- Molded of impact/chemical-resistant nylon
- UL Listed File #E2258 – Guide #RTRT
- CSA Certified File #LR16215 – Guide #365E1

NYLON PLUG AND CONNECTOR

- Metal parts have .0003 nickel plating
- Copper-alloy blades, contacts and terminals
- Silicon bronze assembly screws
- Impact/chemical-resistant nylon/polymer construction with automatic cord grip
- High-visibility yellow color

- Pre-attached TPE dust seal
- UL Listed File #E1381 – Guide #AXUT
- CSA Certified File #LR16215 – Guide #20T2

ALL DEVICES

- Comply with NEMA Standards WD-1, WD-6 and UL 498
- NOM
- CE



BRY5362CR



5361CR



 
 

 


5266NCR

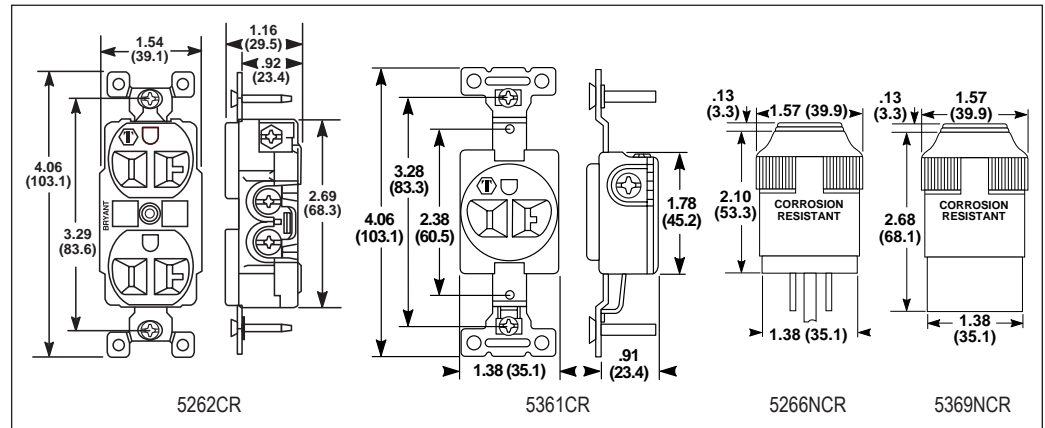


5269NCR

RECEPTACLES, ATTACHMENT PLUGS AND CONNECTORS ①

CATALOG NO.	NEMA CONFIGURATION		DESCRIPTION
	RECEP. & CONN.	PLUGS	
5261CR BRY5262CR BRY5262BCR	15 AMP 125V		Single receptacle, yellow nylon, back and side wired Duplex receptacle, yellow nylon, back and side wired Duplex receptacle, brown nylon, back and side wired
	 5-15R	 5-15P	
5266NCR 5269NCR	15 AMP 250V		Attachment plug, yellow nylon/polymer Connector body, yellow nylon/polymer
5661CR BRY5662CR	15 AMP 250V		Single receptacle, yellow nylon, back and side wired Duplex receptacle, yellow nylon, back and side wired
	 6-15R		
5361CR BRY5362CR	20 AMP 125V		Single receptacle, yellow nylon, back and side wired Duplex receptacle, yellow nylon, back and side wired
	 5-20R	 5-20P	
5366NCR 5369NCR	20 AMP 250V		Attachment plug, yellow nylon/polymer Connector body, yellow nylon/polymer
5461CR BRY5462CR	20 AMP 250V		Single receptacle, yellow nylon, back and side wired Duplex receptacle, yellow nylon, back and side wired
	 6-20R		

PRODUCT DIMENSIONS – () Indicates mm dimensions



① See page I-16 for information on weather protective boots.
See page P-3 for horsepower ratings.
Specifications are subject to change without notice.