
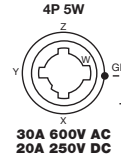
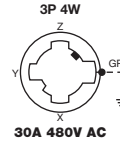


IP30
SUITABILITY

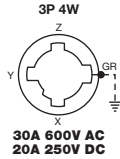


Connector Bodies

Description	Cord Dia.	Column 1	Column 2	Column 3
Black nylon housing, thermoplastic interior.	.70"-1.20" (17.78-30.5)	HBL21414B	-	-
Same as above except corrosion resistant.	.70"-1.20" (17.78-30.5)	HBL21CM414B	-	-
Red nylon housing, thermoset interior.	.70"-1.20" (17.78-30.5)	-	HBL20444B	-
Black nylon housing, thermoplastic interior.	.70"-1.20" (17.78-30.5)	-	-	HBL25414B

Accessories on page B-68.



HBL21414B

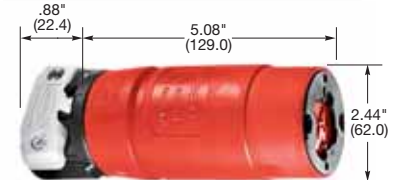

HBL20444B




HBL25414B


Receptacles

Description	Column 1	Column 2	Column 3
Black phenolic.	HBL20403	-	-
Weathertight, corrosion resistant, nickel plated brass plate, for FS/FD box mounting. IP44 SUITABILITY.	HBL22CM427	-	-
Aluminum angle housing, with 3/4" topped hub for surface mounting. IP44 SUITABILITY.	HBL21420	-	-
Black phenolic, red center insert.	-	HBL20443	-
Black phenolic interior, aluminum housing, blue finish, for FS/FD box mounting.	-	-	HBL25403
Black phenolic interior, aluminum weatherproof housing, blue finish, for FS/FD box mounting. IP44 SUITABILITY.	-	-	HBL25250


Accessories on page B-68.

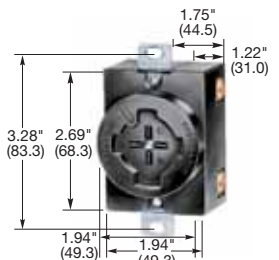


HBL20403

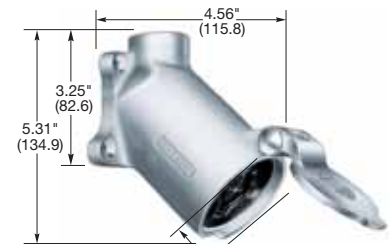


HBL21420

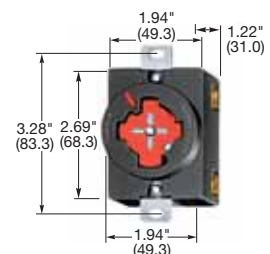

HBL20443

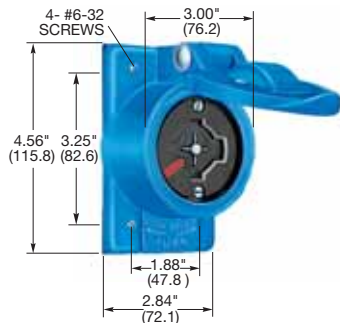

HBL25250

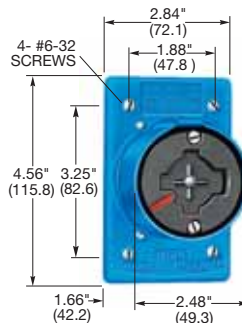

HBL25403