


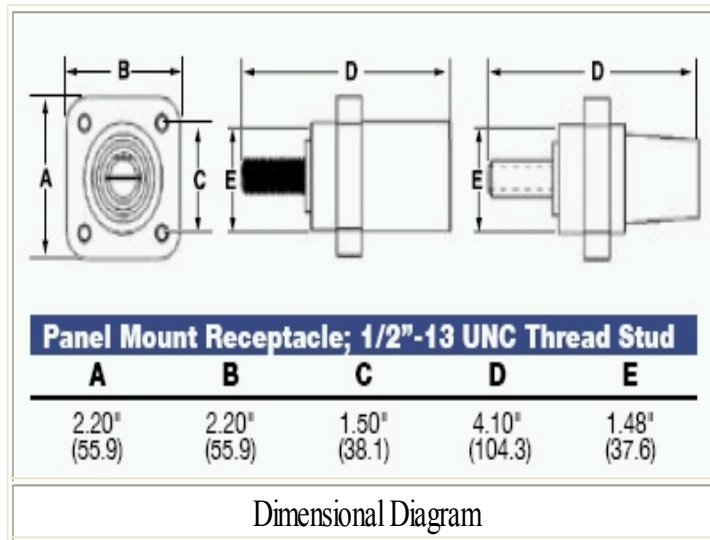
# HBLFRSBK -- Single Pole Devices



400 Amp Stud Type Panel Mount Female Receptacle, Black

Male Receptacle, Threaded

Product Specifications	
Product Version	section-f/images/receptacles-tn.jpg
Receptacle Type	Panel Mount Female Receptacle
Type	For Through Mounting Holes
Amperage	400 A
Connection Means	Stud Type
Color	 Black
Link to Drawing Library	<a href="#">Click here for Library</a>
Link to PDF Catalog	<a href="#">Click here for Catalog</a>



Ampacity Chart (Type SC/PPC Wire)	
Cable Size	Ampacity*
#4	140
#2	190
2/0	300
4/0	405

\* 90 Deg. C column NEC Table 400.5(B).

Ampacity Table

