


HBL20403 -- Hubbellock Receptacle

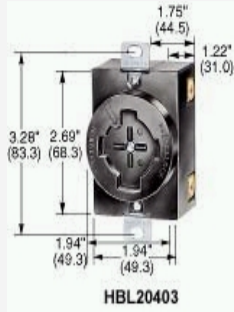

3P4W, 30A 600V AC Max, Black Phenolic


Product Specifications

Product Type



Hubbellock
Devices

Product Item	Single Receptacle
Wiring Scheme	3-Pole, 4-Wire Grounding
Multi-Rating	30A 600V AC, 20A 250V DC
Item Style	Standard
Device Color	Black
Terminal Screw Material	Steel pressure screw- zinc plate
Ground Screw Material	Steel pressure screw- zinc plate
Body Contact Carrier Material	Black Polyester
Contact Spring Material	.031" Brass
Mounting Screw Material	Steel, zinc plated
Cover (Top) Material	Black Thermoset
Base Material	Black Thermoset
Ground Contact Material	.031" Brass
Bridge (Mounting Strap) Material	.062" Steel, Zinc Plate
Ratings	Molded In or Stamped On
Catalog No	Permanently ink marked on product
Dielectric Voltage Withstand	2,000V minimum
Current Interrupting	Certified for current interrupting at full rated current
Temperature Rise	Max 30C temperature rise at full rated current after 50 cycles of overload at 150% of rated current at a power factor of .75.
Terminal Accommodation	20A #12AWG; 30A #10AWG
Terminal Identification	Terminals identified in accordance with UL 498 (X, Y, Z, White, Green)
Flammability	UL 94 VO for Receptacles and Inlets. HB or better for Plugs and Connectors.
Operating Temperatures	Maximum Continuous 75 C Minimum -40 C (w/o impact)
Moisture Resistance	IP30
Listings	UL/CSA
UPC Number	783585017280
Weight in LBs	0.55
Link to Drawing Library	Click here for Library
Link to PDF Catalog	Click here for Catalog

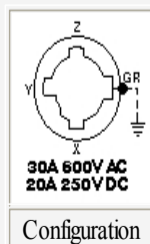

Configuration

