


NP138BK -- Wallplates

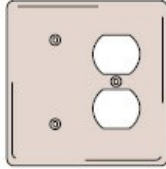

Combination Plates, 2-Gang, Standard Size,
Black Nylon

Product Specifications	
Product Type	<p>Wall Plates</p>
Plate Material	Non-Metallic
Gangs	2
Plate Group	Combination Plates
Plate Size	Standard
Combination Plate Group	Blank/Duplex Combos
Gang 1 Openings	<p>Box Mounted Blank</p>
Gang 2 Openings	<p>Duplex Opening</p>
Color/Material	Black Nylon
Listings	UL Standard 514D
Certification	UL Listed E92074, CSA Certified
Thickness	.25" (6.35)
Mounting Screws	6/32" X 3/8" Oval Milled Head, Painted
Operating Temp	-40 deg. C to 85 deg. C
Appearance	Curved Corners, Smooth Finish
Product Dimensions	4.625" (117.48) X 4.72" (119.88)
UPC Number	88377810435
Weight in LBs	0.05
Link to Drawing Library	Click here for Library
Link to PDF Catalog	Click here for Catalog

