

RESIDENTIAL Delivery Systems

Power and Voice/Data/Video Exactly Where You Need It.



Floor Boxes

Under Cabinet/Counter

Space Limited Areas

homeSELECTTM
Setting the standard, wire to wire.

Your complete source for home electrical and voice/data products.


Residential Delivery Systems

Floor Boxes For Wood Floors



Floor Box for Wood Floors


homeSELECT™ Wood Floor Boxes allow for the placement of electrical power or a combination of power and voice/data devices. Boxes easily mount into the floor and are height adjustable (up to 3/4 inch) for optimal alignment and fit. UL Listed and CSA Certified.

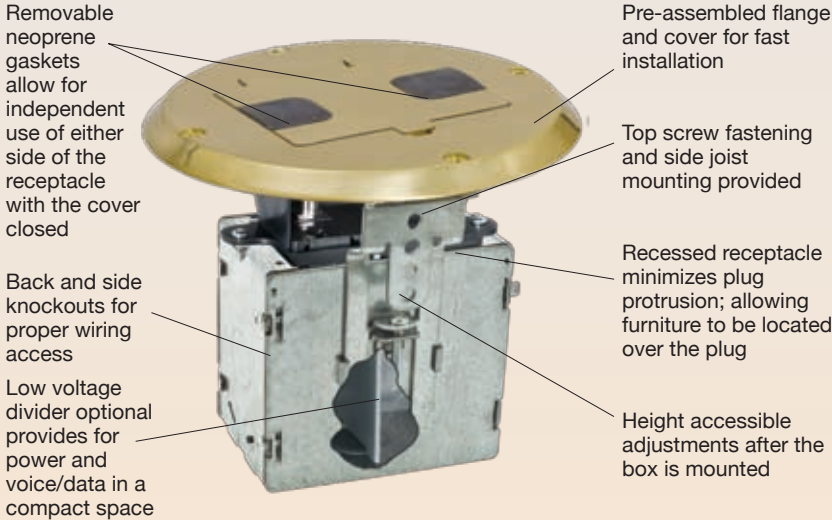

Template cutout provided with instructions for proper installation.

Drop-In Floor Box

homeSELECT™ Drop-In Floor Boxes are perfect for quick and easy installation of power or low voltage. Simply cut a hole between the floor and joists and drop through. The flange lip holds it in place.

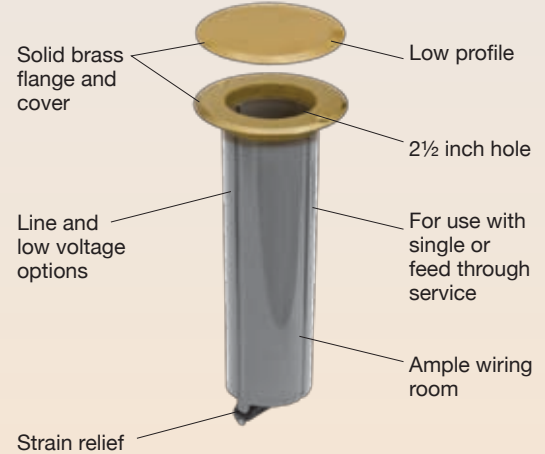

Floor Boxes For Structural Wood Floors

Description	Material	Finish	Catalog Number	Finish	Catalog Number
Decorator duplex receptacle floor box kit; includes steel box, flange and hinged door cover assembly with 15A 125V tamper-resistant duplex receptacle; designed for installation in wood floors; mounts to sub-floor or joists	Solid Brass	Clear Lacquer	RF515BR	Brass Plated	RF515BP
	Aluminum	Stainless Paint	RF515SS	Chrome	RF515CH
	Aluminum	Almond Paint	RF515AL	Plated	RF515CU
	Aluminum	Black Paint	RF515BK	Copper Plated	RF515NI
	Aluminum	Chestnut Brown Paint	RF515BN	Nickel Plated	
Flange and hinged door cover assembly; includes tamper-resistant duplex receptacle; neoprene gaskets; for use with steel box RF500	Solid Brass	Clear Lacquer	RF506BR	Brass Plated	RF506BP
	Aluminum	Stainless Paint	RF506SS	Chrome	RF506CH
	Aluminum	Almond Paint	RF506AL	Plated	RF506CU
	Aluminum	Black Paint	RF506BK	Copper Plated	RF506NI
	Aluminum	Chestnut Brown Paint	RF506BN	Nickel Plated	
Adjustable floor box; 3 inches deep; three 1/2 inch knockouts: one on bottom; one on each side; non-metallic sheathed cable clamps on each side	Steel	—	RF500	—	—




Drop-In Floor Box For Structural Wood Floors



Description	Material	Rating	Catalog Number
Drop-in floor box; mounts in 2.50 inch hole opening; includes solid brass cover; single 125V tamper-resistant receptacle; optional device mounts for two voice/data video ports; suitable for feed through circuitry; impact resistant box	Solid Brass	15 Amp	RF151R
	Solid Brass	20 Amp	RF201R



Product Dimensions Inches (mm)

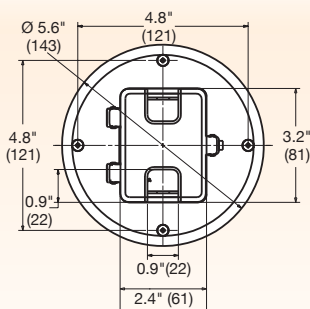

Wood Floor Boxes

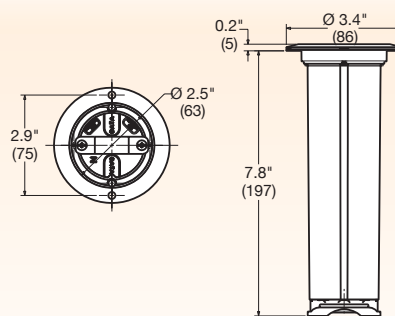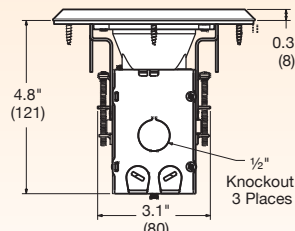

Drop-In Floor Box


Residential Delivery Systems

Floor Boxes For Concrete Floors




Floor Box for Concrete Floors

homeSELECT™ Round Non-Metallic Floor Box offers an economical solution for electrical power or a combination of power and voice/data applications. Designed specifically for slab-on-grade installation. Quick and easy installation is assured using a push in place leveling system. UL Listed.

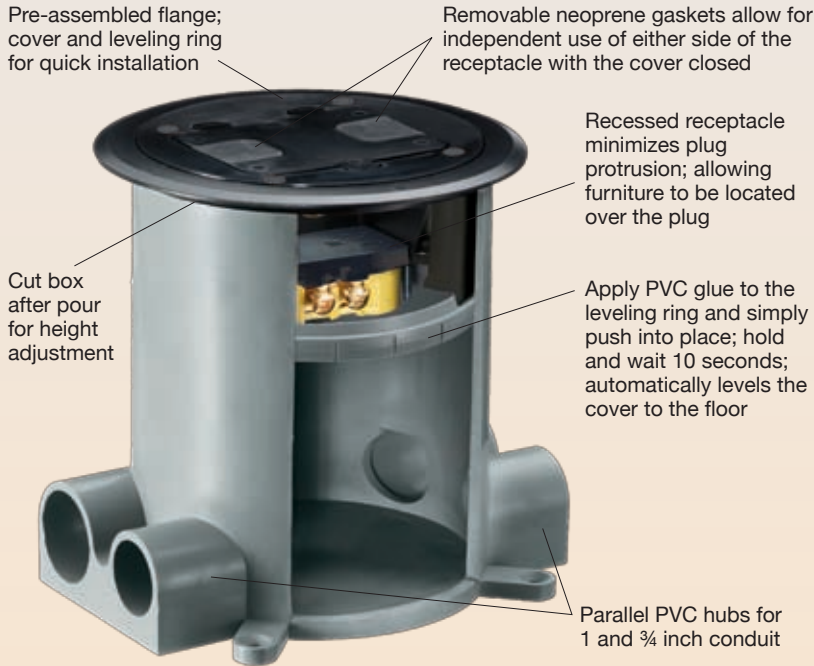

The Right Choice For That Perfect Finishing Touch!

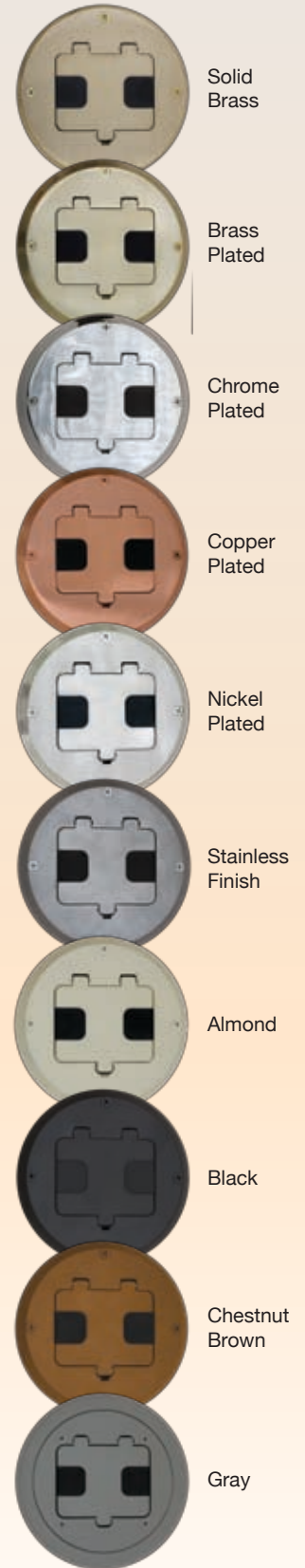


Floor Boxes For Structural Concrete Floors

Description	Material	Color	Catalog Number
Flange and hinged door cover assembly; includes tamper-resistant duplex receptacle 15A 125V; gasket; floor leveling PVC ring; high impact and chemically resistant nylon; factory pre-assembled for easy drop-in installation	Solid Brass	—	RF406BR
	Thermoplastic	Almond	RF406AL
	Thermoplastic	Black	RF406BK
	Thermoplastic	Chestnut Brown	RF406BN
	Thermoplastic	Gray	RF406GY
Floor box with concrete protective cover; accepts 3/4 in. and 1.0 in. schedule 40 and schedule 80 PVC conduit; includes round box (4 7/8 in. dia. x 6.0 in. deep); four reducers; closure plugs; and concrete cover with locator flag	PVC	Gray	RF400
Hinged nylon replacement door cover; includes neoprene gasket to seal plug openings; replacement cover for RF406 series	Solid Brass	—	RF407BR
	Thermoplastic	Almond	RF407AL
	Thermoplastic	Black	RF407BK
	Thermoplastic	Chestnut Brown	RF407BN
	Thermoplastic	Gray	RF407GY
Low voltage divider; for use in PVC box RF400; when JLOAD™ multimedia outlet is used	Thermoplastic	Gray	RF408



Product Dimensions Inches (mm)

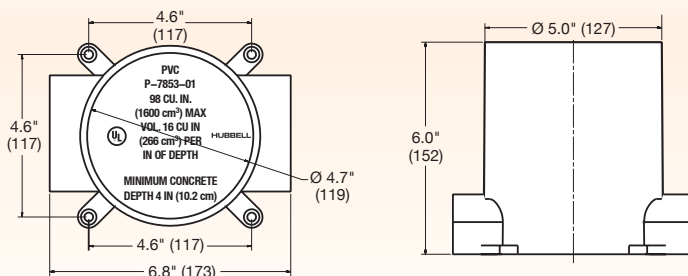

Concrete Floor Boxes


Residential Delivery Systems

Under Cabinet/Counter Power Distribution



Under Cabinet Power Distribution Has Never Been So Convenient

homeSELECT™ Slim Fit and GFCI Fit Surface Boxes enable receptacles and voice/data products to be surface mounted exactly where they are needed. Similar to under cabinet lighting products, these surface boxes provide a precise fit—horizontally or vertically.

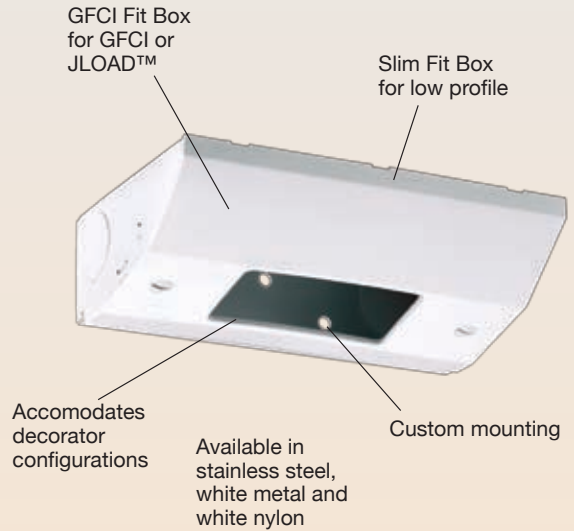

RU100W



RU200SS

Under Cabinet/Counter Power Distribution

Description

Slim fit box; offers the slimmest; sleekest; most stylish option for low profile; out-of-sight mounting; devices sold separately

Material/Color

Stainless Steel
White Metal
White Nylon

Catalog Number

RU100SS
RU100W
RU170W*

GFCI fit box; designed specifically for GFCI or JLOAD™ accommodation where internal wiring space is needed; devices sold separately


Stainless Steel
White Metal
White Nylon

RU200SS
RU200W
RU270W*


Note: * Steel box with nylon cover.

Installation Options

Vertical Mount

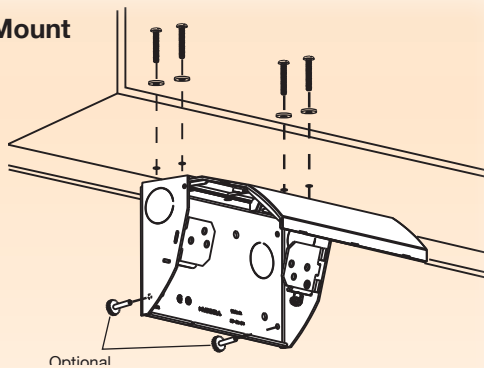


Horizontal Mount

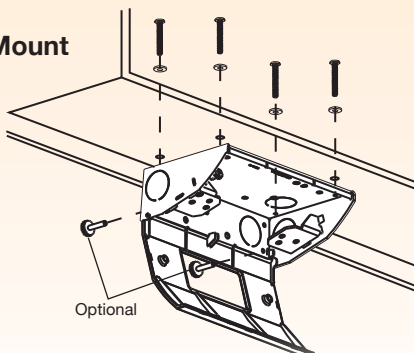


Product Dimensions Inches (mm)

Slim Fit

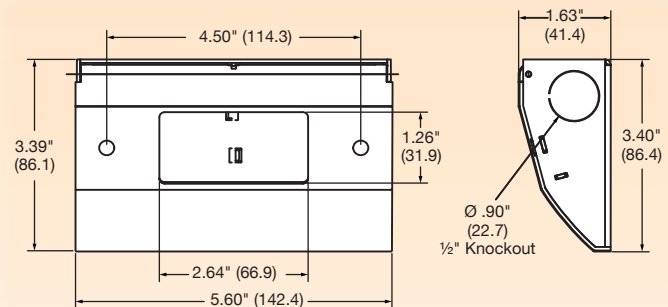

GFCI Fit

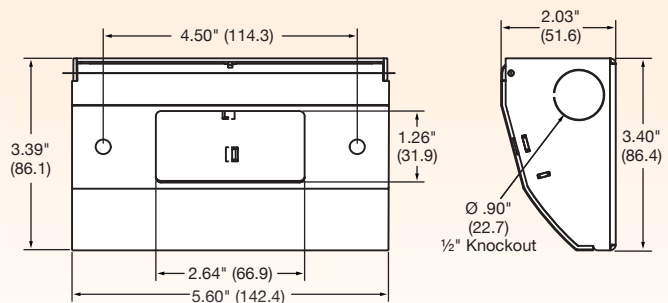

Residential Delivery Systems

JLOAD™ Multimedia Outlet



Make The Most Of A Perfect Location

Install receptacles and voice/data devices exactly where they are needed, in the smallest space possible.



Provides for data, telephone and coaxial



Accepts snap fit jack configuration

Divider isolates low voltage and power in the same box

Available in 15 or 20 amp

Custom mounting

Requires RJ600 box shown below.



NEMA 5-15
15A 125V



NEMA 5-20
20A 125V

JLOAD™ Multimedia Outlet

Description	Color	Catalog Number		Catalog Number	
		Tamper-Resistant	Standard	Tamper-Resistant	Standard
JLOAD™ multimedia outlet; specifically designed to provide power, cat. 5e and coaxial in a single gang box; requires JLOAD™ multimedia box RJ600; perfect for HDTV and computer use where a combination of power and data are needed; includes decorator frame; one cat. 5e; one F-connector and one power receptacle 125V with voltage divider	Almond	RJ650ALTR	RJ650AL	RJ620ALTR	RJ620AL
	Black	RJ650BKTR	RJ650BK	RJ620BKTR	RJ620BK
	Gray	RJ650GYTR	RJ650GY	RJ620GYTR	RJ620GY
	Ivory	RJ650ITR	RJ650I	RJ620ITR	RJ620I
	Light Almond	RJ650LATR	RJ650LA	RJ620LATR	RJ620LA
	White	RJ650WTR	RJ650W	RJ620WTR	RJ620W
JLOAD™ multimedia outlet; includes decorator frame with two open ports for custom configuration and one power receptacle 125V with voltage divider	Almond	RJ65ALTR	RJ65AL	RJ62ALTR	RJ62AL
	Black	RJ65BKTR	RJ65BK	RJ62BKTR	RJ62BK
	Gray	RJ65GYTR	RJ65GY	RJ62GYTR	RJ62GY
	Ivory	RJ65ITR	RJ65I	RJ62ITR	RJ62I
	Light Almond	RJ65LATR	RJ65LA	RJ62LATR	RJ62LA
	White	RJ65WTR	RJ65W	RJ62WTR	RJ62W
JLOAD™ multimedia box; 3 inches deep with seven ½ inch knockouts; non-metallic sheathed cable clamps on each side; screw in mounting to stud	Steel	RJ600	RJ600	RJ600	RJ600



RJ620W




RJ62W





RJ600

Product Dimensions Inches (mm)

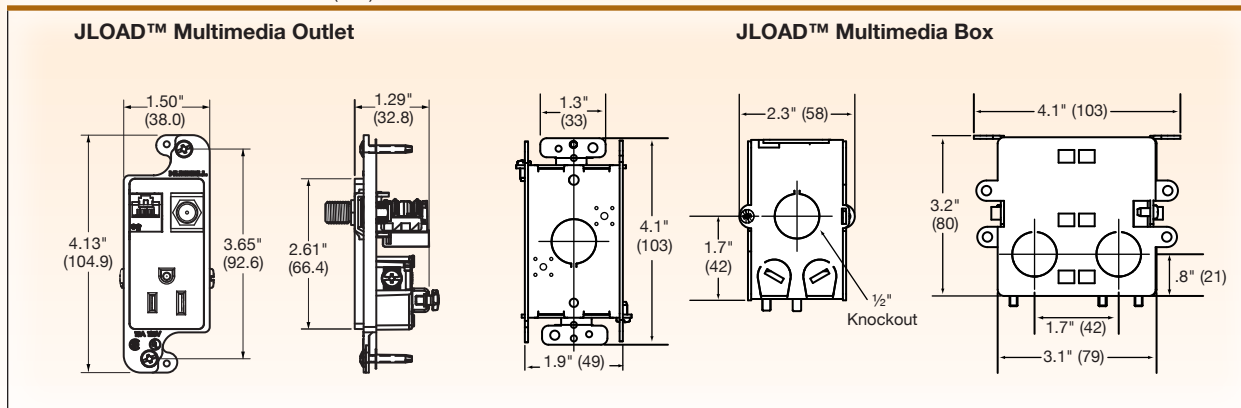

Installation Tips and Techniques*

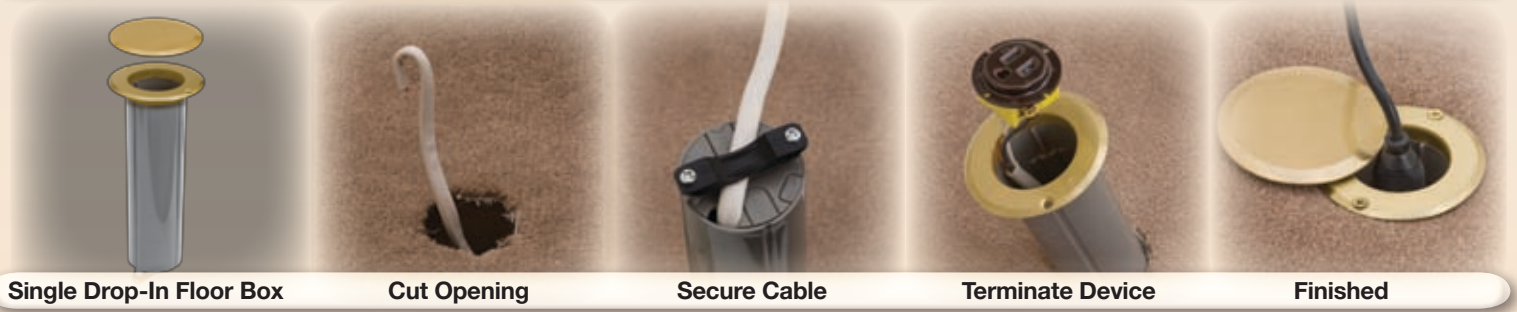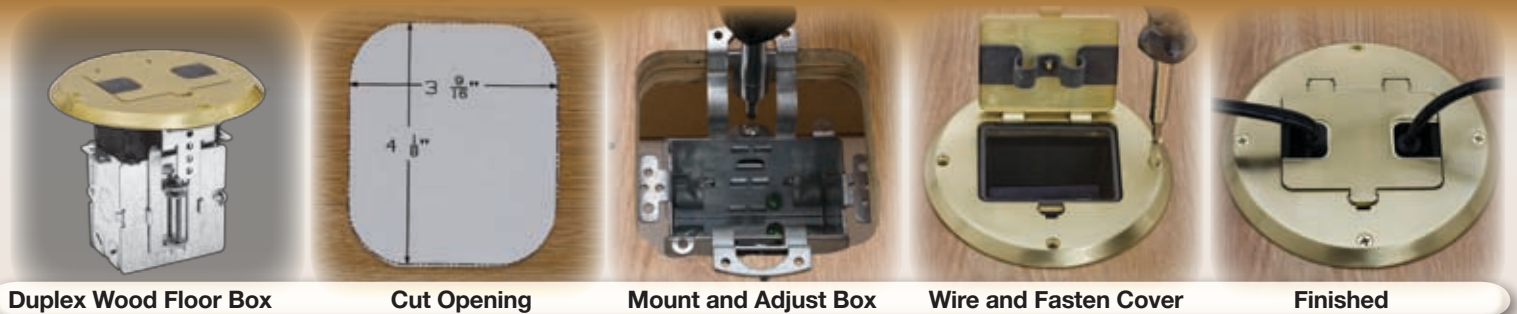

Note: * Complete instructions supplied with products

Hubbell Wiring Device-Kellems
 185 Plains Road • Milford, CT 06461-2420
 (203) 882-4800 • Fax (800) 255-1031
www.hubbell-wiring.com

Bryant Electric
 185 Plains Road • Milford, CT 06461-2420
 (800) 323-2792 • Fax (800) 543-0538
www.bryant-electric.com

Hubbell Premise Wiring
 14 Lord's Hill Road • Stonington, CT 06378-0901
 (860) 535-8326 • (800) 626-0005 • Fax (860) 535-8328
www.hubbell-premise.com

Hubbell Canada LP
 870 Brock Road South • Pickering, Ontario L1W 1Z8
 (800) 263-4622 • (905) 839-1138 • Fax (905) 839-9108
www.hubbell-canada.com

Hubbell De Mexico, S.A. de C.V.
 Ave. Coyoacan No. 1051 • Col. Del Valle C.P. 03100 Mexico D. F.
 (01 55) 91 51 99 99 • Fax (01 55) 91 51 99 88
www.hubbell.com.mx

