



# ◆ PERSONAL & FACILITY SAFETY ◆



## Safety Shroud Twist-Lock® Full Line Catalog Section 'B'

### Plugs, 2-Pole, 3-Wire

Amps	Volts	Cat. No.
20A	125V	<b>HBL2311S</b>
20A	250V	<b>HBL2321S</b>
20A	277V AC	<b>HBL2331S</b>
30A	125V	<b>HBL2611S</b>
30A	250V	<b>HBL2621S</b>



### Plugs, 3-Pole, 4-Wire

Amps	Volts	Cat. No.
20A	125/250V	<b>HBL2411S</b>
20A	3Ø250V AC	<b>HBL2421S</b>
20A	3Ø480V AC	<b>HBL2431S</b>
30A	125/250V	<b>HBL2711S</b>
30A	3Ø250V AC	<b>HBL2721S</b>
30A	3Ø480V AC	<b>HBL2731S</b>



## Switched Enclosures Full Line Catalog Section 'B'

### Unwired NEMA Twist-Lock®

Use With	Cat. No.
2P/3W to 4P/5W grounding receptacle	<b>SETL3</b>
3P/4W Hubbell lock receptacle	<b>SEHBL3</b>



### Prewired with Twist-Lock® Receptacle

NEMA Configuration	Voltage	Cat. No.
L15-30R	3Ø250V AC	<b>SE2720A</b>
L16-30R	3Ø480V AC	<b>SE2730A</b>

## Lock-Out Devices Full Line Catalog Section 'U'

Description (key type)	Cat. No.
Small, lockout	<b>HLDMP</b>
Medium, lockout	<b>HLD</b>
Large, lockout	<b>HLD2</b>
Switchout	<b>HSLDPK2</b>
Lockout kit	<b>HLDKIT</b>
Keyed PLUGOUT® (different)	<b>HKLD</b>
Keyed PLUGOUT® (alike)	<b>HLKLDPK2</b>



## Mechanical Interlock Enclosures Full Line Catalog Section 'B' & 'E'

### 3-Pole, 4-Wire, Unfused

Amps	Voltage	Cat. No.
30A	3Ø240	<b>HBL430MI9W</b>
30A	3Ø480	<b>HBL430MI7W</b>
60A	3Ø240	<b>HBL460MI9W</b>
60A	3Ø480	<b>HBL460MI7W</b>
100A	3Ø240	<b>HBL4100MI9W</b>
100A	3Ø480	<b>HBL4100MI7W</b>



### 3-Pole, 4-Wire, Fused

Amps	Voltage	Cat. No.
30A	3Ø240	<b>HBL430MIF9W</b>
30A	3Ø480	<b>HBL430MIF7W</b>

### Twist-Lock Receptacle, Watertight Safety-Shroud

Amps	Voltage	Cat. No.
20 or 30A	3Ø480	<b>HBLMITL</b>

 
## Trak Systems

Full Line Catalog Section 'Q'

### TredTrak® 5-Channel System

Desc.	Male/ Female	Color	Cat. No.
Track	-	Blue/Yellow	<b>HBLTRED5B</b>
End Cap	1M/1F	Yellow	<b>HBLTRED5ECB</b>
End Cap	2F	Yellow	<b>HBLTRED5ECFB</b>
X Fitting	-	Blue/Yellow	<b>HBLTRED5XB</b>
Y Fitting	-	Blue/Yellow	<b>HBLTRED5YB</b>


End Caps are sold in pairs only



### TrukTrak® 5-Channel System

Desc.	Male/ Female	Color	Cat. No.
Track	-	Blue/Yellow	<b>HBLTT5B</b>
End Cap	1M/1F	Yellow	<b>HBLTT5ECB</b>
45° Right	-	Blue/Yellow	<b>HBLTT545RB</b>
45° Left	-	Blue/Yellow	<b>HBLTT545LB</b>

 End Caps are sold in pairs only.



### 3-Channel System

Desc.	Male/ Female	Color	Cat. No.
Track	-	Blue/Yellow	<b>HBLTT3B</b>
End Cap	1M/1F	Yellow	<b>HBLTT3ECB</b>

End Caps are sold in pairs only.

### 2-Channel System

Desc.	Male/ Female	Color	Cat. No.
Track	-	Blue/Yellow	<b>HBLTT2B</b>



### AccessTrak® 5-Channel System

Desc.	Color	Cat. No.
Track Kit*	Gray/Blue	<b>HBLAT5KIT</b>
Trough	Gray/Blue	<b>HBLAT5</b>
Trough End Rails**	Gray	<b>HBLAT5ER</b>
Ramps**	Blue	<b>HBLAT5RAMP</b>
Ramp End Rails**	Gray	<b>HBLAT5RAMPER</b>


\*Includes 1-HBLAT5, 1-HBLAT5ER, 1-HBLAT5RAMP, 2-HBLRAMPER

\*\*Sold in sets

### FloorTrak® Floor Cable Cover

	FloorTrak 2 width 2.75"	FloorTrak 3 width 3.00"	FloorTrak 4 width 3.25"
Color	Cat. No.	Cat. No.	Cat. No.
Black	<b>FT2BK10</b>	<b>FT3BKXX*</b>	<b>FT4BKXX*</b>
Brown	<b>FT2BR10</b>	<b>FT3BRXX*</b>	-
Beige	<b>FT2BG10</b>	<b>FT3BGXX*</b>	-
Gray	<b>FT2GY10</b>	<b>FT3GYXX*</b>	<b>FT4GY25</b>
Yellow	<b>FT2Y10</b>	<b>FT3YXX*</b>	<b>FT4YXX</b>

\* Last two digits indicate the length, change XX to 5 for 5' or 25 for 25'.

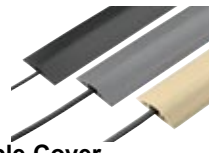

## Ground Fault Receptacles Full Line Catalog Section 'H'

### GFCI Duplex Receptacles, 15A/125V

Color	Cat. No.
Brown	<b>GFR5252A</b>
Ivory	<b>GFR5252IA</b>
Gray	<b>GFR5252GYA</b>
White	<b>GFR5252WA</b>
Black	<b>GFR5252BKA</b>
Office White	<b>GFR5252OWA</b>
Red	<b>GFR5252RA</b>

### 20A/125V

Color	Cat. No.
Brown	<b>GFR5352A</b>
Ivory	<b>GFR5352IA</b>
Gray	<b>GFR5352GYA</b>
White	<b>GFR5352WA</b>
Black	<b>GFR5352BKA</b>
Office White	<b>GFR5352OWA</b>
Red	<b>GFR5352RA</b>



## GFCI Portables Full Line Catalog Section 'H'

### Single Outlet, 15A/120V AC

Length	Set	Cat. No.
2'	Automatic	<b>GFP2CA</b>
2'	Manual	<b>GFP2CM</b>
25'	Automatic	<b>GFP25CA</b>
25'	Manual	<b>GFP25CM</b>

### Triple Tap Outlet, 15A/120V AC

Length	Set	Cat. No.
2'	Automatic	<b>GFP2TTA</b>
2'	Manual	<b>GFP2TTM</b>
25'	Automatic	<b>GFP25TTA</b>
25'	Manual	<b>GFP25TTM</b>



## 30A GFCI

Length	Voltage	Manual Cat. No.	Automatic Cat. No.
2'	120V AC	<b>GFP1301</b>	<b>GFP1311</b>
2'	240V AC	<b>GFP2301</b>	<b>GFP2311</b>
6'	120/240V AC	<b>GFP3305</b>	<b>GFP3315</b>
6'	3Ø250V AC	<b>GFP5305</b>	<b>GFP5315</b>
6'	3Ø120/208V AC	<b>GFP4305</b>	<b>GFP4315</b>
25'	120V AC	<b>GFP1302</b>	<b>GFP1312</b>
25'	240V AC	<b>GFP2302</b>	<b>GFP2312</b>



## Security Wall Plates Full Line Catalog Section 'K'

Description	Cat. No.
Toggle Switch	<b>SWP1</b>
Duplex Receptacle	<b>SWP8</b>
Style Line®	<b>SWP8</b>



© Hubbell Wiring Device-Kellems  
Hubbell Incorporated (Delaware)  
1-203-882-4800  
www.hubbell-wiring.com

www.hubbell-solutions.com/edu