




# Heyco® Nylon PCB Supports - Threaded Male

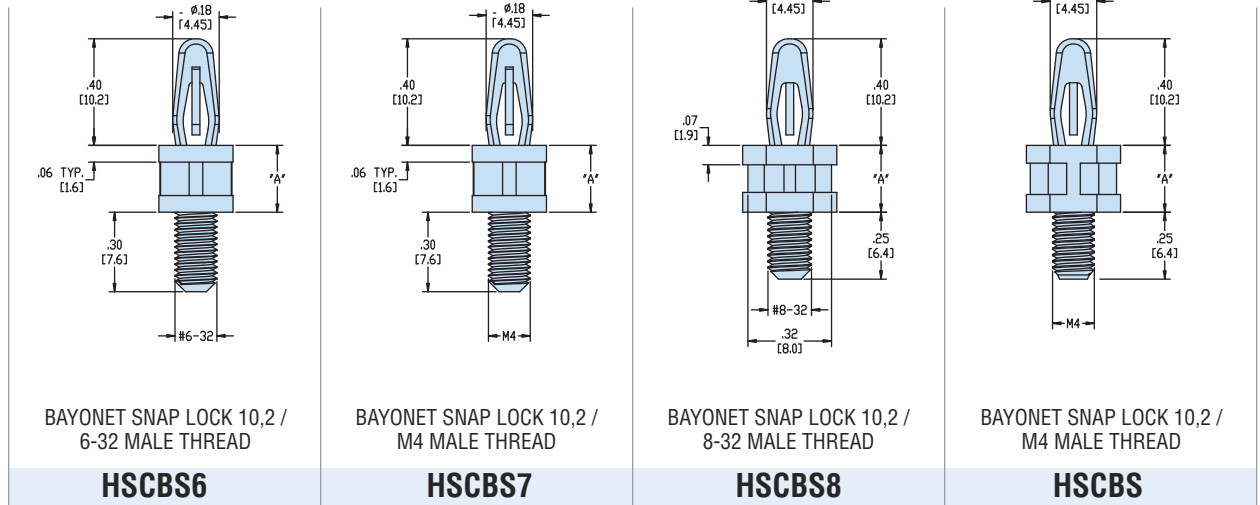

	Maximum Thread Lg †		Mounting Hole Diameter		Maximum Thread Lg †		Mounting Hole Diameter		Maximum Thread Lg †		Mounting Hole Diameter		Maximum Thread Lg †		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
<b>PCB</b>	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
<b>Chassis</b>	.300	7,6	6-32		.300	7,6	M4		.250	6,4	8-32		.250	6,4	M4	

A		PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION
in.	mm.								
.250	6,4	<b>10746</b>	HSCBS6-04	<b>10754</b>	HSCBS7-04	<b>10762</b>	HSCBS8-04	<b>10678</b>	HSCBS-04
.375	9,5	<b>10747</b>	HSCBS6-06	<b>10755</b>	HSCBS7-06	<b>10763</b>	HSCBS8-06	<b>10679</b>	HSCBS-06
.500	12,7	<b>10748</b>	HSCBS6-08	<b>10756</b>	HSCBS7-08	<b>10764</b>	HSCBS8-08	<b>10680</b>	HSCBS-08
.625	15,9	<b>10749</b>	HSCBS6-10	<b>10757</b>	HSCBS7-10	<b>10765</b>	HSCBS8-10	<b>10681</b>	HSCBS-10
.750	19,1	<b>10750</b>	HSCBS6-12	<b>10758</b>	HSCBS7-12	<b>10766</b>	HSCBS8-12	<b>10682</b>	HSCBS-12
.812	20,6							<b>10683</b>	HSCBS-13
.875	22,2	<b>10751</b>	HSCBS6-14	<b>10759</b>	HSCBS7-14	<b>10767</b>	HSCBS8-14	<b>10684</b>	HSCBS-14
1.000	25,4	<b>10752</b>	HSCBS6-16	<b>10760</b>	HSCBS7-16	<b>10768</b>	HSCBS8-16	<b>10685</b>	HSCBS-16
1.125	28,6					<b>10769</b>	HSCBS8-18	<b>10686</b>	HSCBS-18
1.406	35,7					<b>10770</b>	HSCBS8-22.5	<b>10687</b>	HSCBS-22.5

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix “F” to Part No.

†Thread length at Chassis

Quick  
Specs

Material Nylon 6/6  
 Flammability Rating 94V-2  
 Temperature Range .4°F (-18°C) to 185°F (85°C)