

Heyco® Original Strain Relief Bushings

Straight-Thru for Flat Cables

.560" (14,2 mm) to .875" (22,2 mm) Mounting Holes

WILL FIT THESE CABLES				PANEL DIMENSIONS						PART NO.	DESCRIPTION	PART DIM.		Mounting Hole Plug
UL Type	AWG/ Conductors	Approximate Size		A Mounting Hole Dia.		B To Prevent Rotation		Finished Fit Panel Thickness*		Black		C BODY LENGTH		PART NO.
		in.	mm.	in.	mm.	in.	mm.	in.	mm.					
SPT-2	18/3	.15 x .40	3,8 x 10,2	.562	14,3	.530	13,5	.125	3,2	1174	SR 5W-1	.609	15,5	2494
	16/3	.16 x .41	4,1 x 10,4											
HPN	16/2	.16 x .37	4,1 x 9,4	.562	14,3	.530	13,5	.125	3,2	1174	SR 5W-1	.609	15,5	2494
	16/3	.16 x .42	4,1 x 10,5											
SPT-3	18/2	.19 x .35	4,8 x 8,9	.562	14,3	.530	13,5	.062	1,6	1170	SR 5KN-4	.609	15,5	2494
	16/2	.20 x .37	5,1 x 9,4											
SPT-2	18/3	.15 x .40	3,8 x 10,2	.562	14,3	.530	13,5	.062	1,6	1170	SR 5KN-4	.609	15,5	2494
SPT-2 & HPN	16/3	.16 x .41	4,1 x 10,4											
Same as SR 5KN-4 above except								.125	3,2	1167	SR 5K-4	.609	15,5	2494
SPT-2	18/3	.15 x .40	3,8 x 10,2	.560	14,2	.730	18,5	.125	3,2	1484	SR 30-1**	.672	17,1	consult Heyco
	16/3	.16 x .41	4,1 x 10,4											
SPT-3	18/2	.19 x .35	4,8 x 8,9	.560	14,2	.730	18,5	.125	3,2	1484	SR 30-1**	.672	17,1	consult Heyco
	18/3	.19 x .39	4,8 x 9,9											
	16/2	.20 x .37	5,1 x 9,4											
	16/3	.20 x .43	5,1 x 10,9											
SPT-2	18/3	.15 x .40	3,0 x 7,6	.625	15,9	.550	14,0	.062	1,6	1160	SR 6N4-4	.578	14,7	2497
	16/3	.16 x .41	4,1 x 10,4											
Same as SR 6N4-4 above except								.125	2,5	1163	SR 6P4-4	.578	14,7	2497
SPT-3	16/2	.20 x .37	5,1 x 9,4	.750	19,0	.875	22,2	.125	3,2	1504	SR 33-1**	.781	19,8	consult Heyco
	16/3	.20 x .43	5,1 x 10,9											
	14/2	.24 x .42	6,1 x 10,7											
	14/3	.24 x .51	6,1 x 12,9											

Fit 1/2" Electrical Knock-out Hole

SPT-3	14/2	.24 x .42	6,1 x 10,7	.875	22,2	.840	21,3	.125	3,2	1517	SR 34-2	.813	20,7	2509
	14/3	.24 x .51	6,1 x 12,9											
	12/2	.29 x .51	7,4 x 12,9											
	12/3	.29 x .65	7,4 x 16,5											
SPT-3	12/3	.32 x .65	8,1 x 16,5	.875	22,2	.835	21,2	.125	3,2	1497	SR 31-2	.812	20,6	2509
	10/3	.32 x .65	8,1 x 16,5											

Standard color black. Consult Heyco for white and other colors.



* Maximum Panel Thickness. Part has additional clearance. Consult Heyco for your Custom Finished Fit Panel Thickness.

**Use Elongated Mounting Hole.




- Protects the lifeline of your electric/electronic products by absorbing the forces of pull, push, and twist that may be exerted on the flexible power cord.
- Securely anchors, insulates, and protects cables at panel entry points.
- Consult Heyco for other wire types and sizes.
- See page 4-38 for corresponding **Mounting Hole Plugs** which can be used to fill blank/unused Mounting Holes and thus allow for a single panel design for multiple applications.
- See pages 4-27 & 4-28 for SR assembly tools.
- For Double D Mounting Hole Punches, see page 4-30.

DOUBLE D MOUNTING HOLE

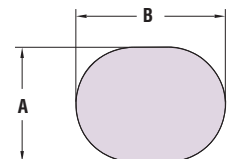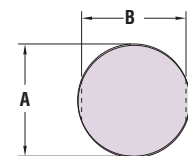

ELONGATED MOUNTING HOLE

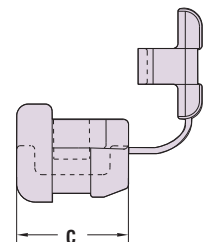

Material
Certifications

Nylon 6/6
Recognized under the Component Program of Underwriters' Laboratories
File E15331

Certified by the Canadian Standards Association File 8919

Flammability Rating
Temperature Range

94V-2
-04°F (-18°C) to 221°F (105°C)

Quick
Specs