


KEMET Part Number: C4AEJBW5200A3JJ
(4AEJBW5200A3JJ)

Film, Metallized Polypropylene, DC Link, KEMET, C4AE, 20 uF, 5%, 700 V, 70C, Lead Spacing = 37.5mm

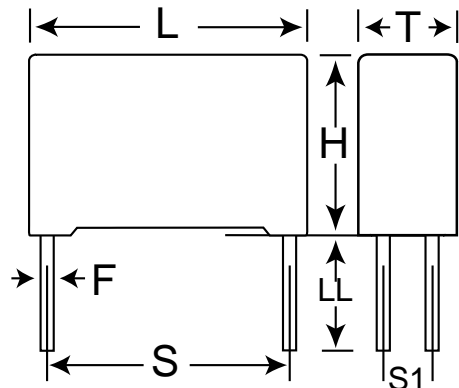

Dimensions	
L	42.5mm NOM
H	37mm NOM
T	28mm NOM
S	37.5mm +/-0.4mm
LL	6mm -2mm

Packaging Specifications	
Packaging:	Bulk

General Information	
Dielectric:	Metallized Polypropylene
Style:	Radial
Supplier:	KEMET
Series:	C4AE
RoHS:	Yes
Lead:	4 Wire Leads
Miscellaneous:	Thermal Resistance = 44 C/W

Specifications	
Capacitance:	20 uF
Capacitance Tolerance:	5%
Voltage DC:	700 VDC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Max dVdt:	13 V
Resistance:	4.7 mOhms (10kHz 70C)
Current:	12.5 Amps (10kHz 70C), 262 Amps (Peak)
Inductance:	30 nH