


MOUNTING DIMENSIONS

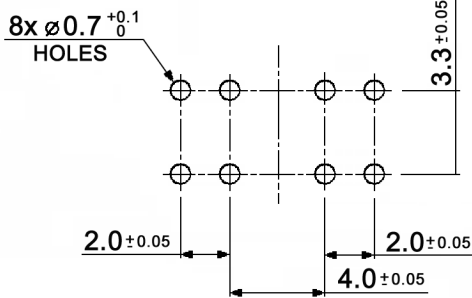

Specifications:

- Contact rating: 0.2A, 12V DC
- Contact resistance: 50mOhm max. at 1.5mA, 200µV AC (1kHz)
- Insulation resistance: 100MOhm min. at 500V DC
- Dielectric strength: 500V RMS
- Electrical life: 5 000 cycles
- Operating force: 50-400gf
- Soldering conditions: 270 +/-10°C max., 3sec.
- Contact timing: non-shorting type
- Switching function: on - on - on
- Material:
 - Frame: stainless steel
 - Lever: polyamide resin (PA), natural
 - Movable contact: phosphor bronze, silver plated
 - Terminal: brass, silver plated
 - Case: polyphenylene sulfide (PPS), black



Tolerances: <6: ±0.2mm 6-18: ±0.4mm	Date	Name
	02/08	dr
Modifications	Date	Name

MMP 231-R

knitter-switch

30 13 76

Page

1/1