


671 RZ Series - Double Row Terminal Blocks

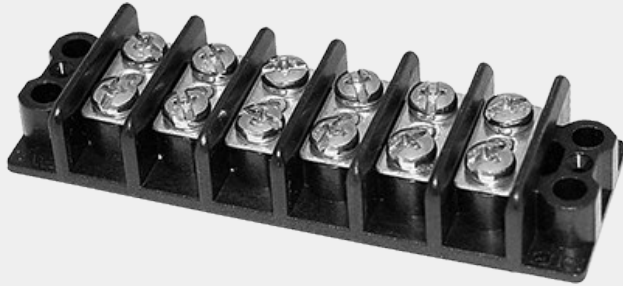

671 RZ 06

Double Row Terminal Blocks - 671 RZ Series

Catalog #	# of Poles	Dimensions	
		A	B
671 RZ 01	1	1.19	0.88
671 RZ 02	2	1.62	1.31
671 RZ 03	3	2.06	1.75
671 RZ 04	4	2.50	2.19
671 RZ 05	5	2.94	2.63
671RZ 06	6	3.37	3.06
671 RZ 07	7	3.81	3.50
671 RZ 08	8	4.25	3.94
671 RZ 09	9	4.69	4.38
671 RZ 10	10	5.12	4.81
671 RZ 11	11	5.56	5.25
671 RZ 12	12	6.00	5.69
671 RZ 13	13	6.44	6.13
671 RZ 14	14	6.87	6.56
671 RZ 15	15	7.31	7.00
671 RZ 16	16	7.75	7.44
671 RZ 17	17	8.19	7.88
671 RZ 18	18	8.62	8.31
671 RZ 19	19	9.06	8.75
671 RZ 20	20	9.50	9.19
671 RZ 21	21	9.94	9.63
671 RZ 22	22	10.37	10.06
671 RZ 23	23	10.81	10.50
671 RZ 24	24	11.25	10.94
671 RZ 25	25	11.69	11.38
671 RZ 26	26	12.12	11.81
671 RZ 27	27	12.56	12.25
671 RZ 28	28	13.00	12.69
671 RZ 29	29	13.44	13.13
671 RZ 30	30	13.87	13.56

mm = dim X 25.4

Specifications

- 30 amps
- 150 volts Class C, 300 Volts Class B
- Base, thermoplastic, 125°C (UL RTI)
- Screws, steel, #6-32 phil-slot
- Terminals, plated brass
- Closed back
- 1-30 poles at 7/16" centers
- Accepts lugs w/max width of .33"
- Bare wire range #14-#22 AWG

Standards

- UL recognized file no. XCFR2.E62806
- CSA certified file no. LR19766
- CE Compliant (IEC 60947-7-1)
- RoHS compliant

Hardware Options

(Hardware options may affect ratings - Consult Customer Service)

Catalog #	Product Description	Reference Sheet
KT37	Full Quick Connect (0° Flat)	Reference
KT38	Full Quick Connect (45° Bend)	
KT39	Full Quick Connect (90° Bend)	
KT43	Half Quick Connect (0° Flat)	
KT44	Half Quick Connect (45° Flat)	
KT45	Half Quick Connect (90° Flat)	Reference
ST	Full Solder	
3/4 ST	Half Solder	
J 601	Line-to-Line Jumper	Reference
601RJ(S)	Multiple Position Jumper	
3765	SEMS Pressure Saddle Screw*	Consult Customer Service
3767	SEMS Pressure Saddle Screw with external tooth lock washer*	
PSB	Phil-Slot Brass Screw	Consult Customer Service
	Covers - Top-Mounted	Reference
	Marking Strips & Insulator Strips - Sub-Mounted	Reference

Quick Connects: .032" x .250"

*Bare wire range with SEMS screw of #12-22 AWG, stranded copper wire only

CONTACT

Marathon Special Products
427 Van Camp Road
P.O. Box 468
Bowling Green, Ohio 43402

LINKS

[About Us](#)
[Contact Us](#)
[Terms & Conditions](#)

ABOUT

Marathon Special Products is an industry leader for supplying power blocks, terminal blocks, and fuse holders in North America. We've achieved this by providing one of the broadest line offerings with various sizes, terminal styles, electrical ratings and features.

tel: 419-352-8441
fax: 419-352-0875
email: marketing@marathonsp.com

Locate a Distributor



CUSTOMER SERVICE HOURS

Mon-Fri 8am-5pm EST