

28W76

30 Amp, 480 Volt 3-Phase, NEMA L16-30P, 3P, 4W, Locking Plug, Industrial Grade, Grounding, Wetguard - YELLOW



UPC Code: 078477969038

Country Of Origin: United States

NEMA:
L16-30P



Leviton's Wetguard line of industrial watertight wiring devices are the most versatile, well-engineered watertight devices on the market. They meet IP67 and NEMA ratings for water ingress protection, and offer many significant advantages over competitive brands.

Technical Information

Electrical Specifications

Amperage: 30 A

Current Limiting: Full Rated Current

Dielectric Voltage: Withstands 2000V per UL498

Grounding: Grounding

Phase: 3-Phase

Pole: 3

Temperature Rise: Max 30C after 250 cycles OL at 200 percent rated current

Voltage: 480 VAC

Wire: 4

Environmental Specifications

Environment: Wet

Flammability: Rated V-2 per UL 94

Operating Temperature: -40°C to 60°C

Material Specifications

Assembly Screws: Stainless Steel 300

Blades/Contacts: Nickel-Plated Brass

Body Interior: Nylon

Body Material: EPTR Rubber

Bushing: Santoprene TPV

Compression Nut, Strain Relief: Nylon

Terminal Screws: Electroless Nickel-coated Brass

Wire Module: Nylon

Mechanical Specifications

Cord Grip Range (in): 0.625 to 1.125

Product ID: Ratings and NEMA I.D. permanently marked on device

Terminal Accom.: #12 to #8

Terminal ID: Brass-Hot, Green-Ground, Silver-Neutral

Product Features

Assembly Screws: Stainless Steel 300

Blades/Contacts: Nickel-Plated Brass

Body Material: EPTR Rubber

Brand: Wetguard

Color: Yellow

Device Type: Locking Plug

NEMA: L16-30P

Standards and Certifications: UL/CSA

Standards and Certifications

ANSI: C-73

CSA C22.2 No. 42: File LR-406



NEMA: WD-6

NOM: 057

UL: 498

Warranty: Lifetime Warranty

Dimensional Diagram

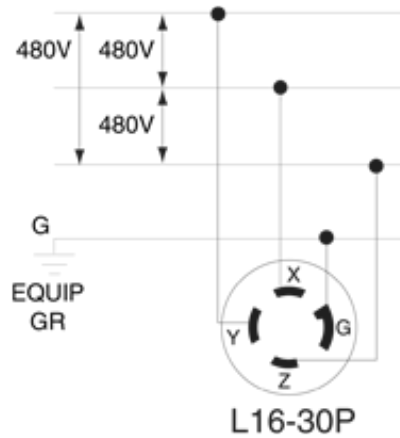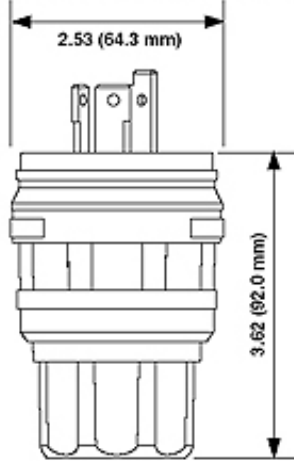

SPECIFICATION SUBMITTAL

| | | |
|----------------------|----------------------|----------------------|
| JOB NAME: | CATALOG NUMBERS: | |
| <input type="text"/> | <input type="text"/> | <input type="text"/> |
| JOB NUMBER: | <input type="text"/> | <input type="text"/> |

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):

+1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-

1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/

