



**UPC Code :** 078477795262

**Country Of Origin :** United States



**Available Colors :**



## 8215-C

15 Amp, 125 Volt, NEMA 5-15P, 2P, 3W, Plug, Straight Blade, Hospital Grade, Grounding, - BLACK-WHITE

Leviton's Black &White line of industrial grade plugs and connectors offer superior performance, long-lasting reliability and features that are backed by a lifetime warranty. Available in many NEMA and non-NEMA configurations, you'll be sure to find the right device for your needs.

### Technical Information

#### Electrical Specifications

**Amperage :** 15 A

**Current Interrupting :** Certified for current interrupting at full rated current

**Dielectric Voltage :** Withstands 2000V per UL498

**Grounding :** Grounding

**Pole :** 2

**Temperature Rise :** Max 30C after 250 cycles OL at 200 percent rated current

**Voltage :** 125 VAC

**Wire :** 3

#### Environmental Specifications

**Environment :** Dry

**Flammability :** Rated V-2 per UL 94

**Operating Temperature :** -40°C to 60°C

#### Material Specifications

**Assembly Screws :** Steel, Zinc Plated

**Back Cover :** Thermoplastic

**Blades/Contacts :** Solid Brass

**Body Material :** Impact Modified Nylon

**Clamp Insert :** Nylon

**Color :** Black-White

**Cord-Clamp :** Nylon

**Terminal Screws :** Brass

**Wire Module :** Nylon

#### Mechanical Specifications

**Cord Range :** 0.230 to 0.685

**Product ID :** Ratings and NEMA I.D. permanently marked on device

**Terminal Accom. :** 18-10 AWG

**Terminal ID :** Brass-Hot, Green-Ground, White-Neutral

#### Product Features

**Brand :** Black and White

**Color :** Black-White

**Device Type :** Straight Blade Plug

**Grade :** Hospital

**NEMA :** 5-15P

#### Standards and Certifications

**ANSI :** C-73

**CSA C22.2 No. 42 :** File LR-406

**NEMA :** WD-6



**NOM :** 057

**UL 498 :** File E13399

**UL Fed Spec WC-596 :** File E13393

**Warranty :** Limited Lifetime Warranty

## Dimensional Diagram

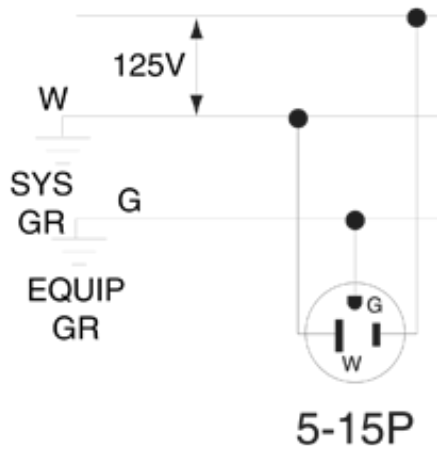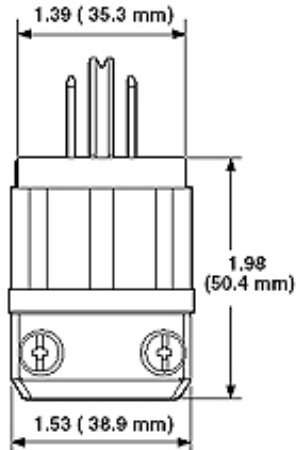

### SPECIFICATION SUBMITTAL

JOB NAME: <input style="width: 95%;" type="text"/>	CATALOG NUMBERS: <input style="width: 95%;" type="text"/>
JOB NUMBER: <input style="width: 95%;" type="text"/>	<input style="width: 95%;" type="text"/>

**Leviton Manufacturing Co., Inc.**

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):

+1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-

1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:

[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

