


OBSOLETE- USE AST100TRQ

Specificat

Resonant Frequency (Hz)	4000 ± 500
Operating Voltage Max (Vp-p)	15
Rated Voltage (Vp-p)	5.0
Current Consumption Max. (mA)	1.5 at Rated Voltage
Sound Pressure Level Min. (dB)	80 at 10cm at Rated Voltage
Capacitance (pF)	10,000 ±30% @ 120Hz
Soldering Condition (°C)	250°C / 15 sec (max)
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	PPS UL94HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	1.4
Options	For other options contact factory

PS: Vp-p = 1/2duty, square wave

Dimensions: (units: mm)

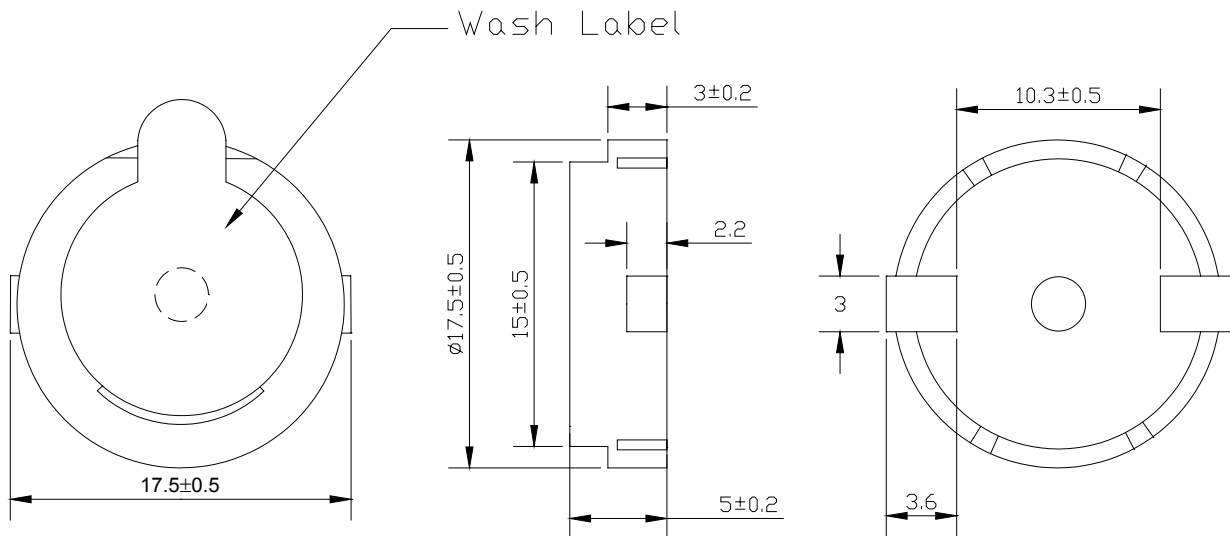

Packaging:

Parts are supplied on reels (500 pcs per tape and reel).