

COLORED VINYL CAPS

For Sub-Miniature Toggle Switches



- 41-901-0** Black
- 41-902-0** Red
- 41-909-0** White

WATERPROOF BOOTS

M6.3 (1/4-40) size for UNC thread switches -M6 for metric switches.



- 41-899-0** M6.3 x .635 thread
- 41-899-3** Package (3)
- 41-900-0** M6 x 0.75 thread
- 41-900-3** Package (3)



WATERPROOF BOOTS

Premium 1/4-40 waterproof boot.



- 41-900T-0** 1/4-40 thread
- 41-900T-3** Package (3)

STANDARD TOGGLE SWITCHES

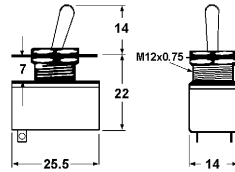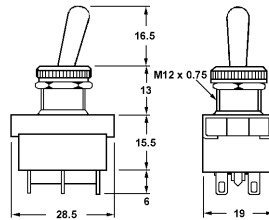


MAX
4A @ 125V
2A @ 250V



- 42-210-0** SPST on-off
- 42-210-1** Display Package

10 amp @ 125VAC (6 amp @ 250VAC)
Solder terminals and dress panel nut.


- 42-115-0** SPDT on-off-on
- Use -1 for Display Package*

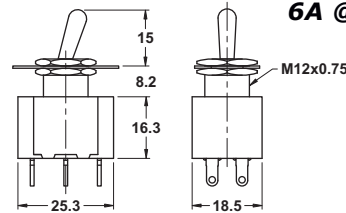

6A @ 125V




- 42-223-0** DPDT on-on
- 42-223-1** Display Package

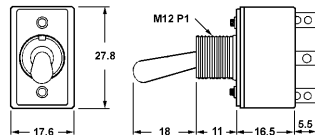

- 42-130-0** DPST on-off **5A/125V** CSA
- 42-143-0** DPDT on-on **5A/125V** CSA
- 42-145-0** DPDT on-off-on **5A/125V** CSA/UL


Use -1 for Display Package

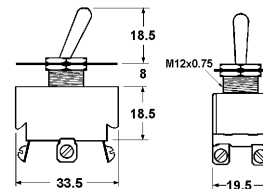

6A @ 125V



- 42-225-0** DPDT on-off-on
- 42-225-1** Display Package

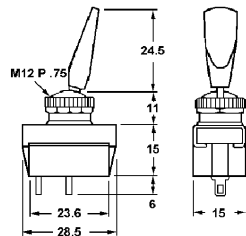


10A @ 125V
6A @ 250V



Black plastic bat handle. Solder terminals.

- 42-310-0** SPST on-off
- 42-310-0** Display Package

Visit our Web Site at
<http://www.mode-elec.com>

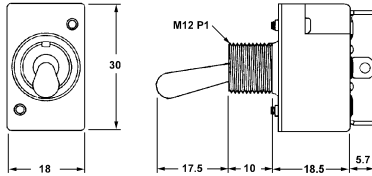


NKK

- 42-310N-0** SPST on-off 10A/125VAC (10A/30VDC)
 - 42-410N-0** SPST on-off 15A/125VAC (20A/30VDC) **UL/CUL**
- Use -1 for Display Package*




() Denotes momentary contact

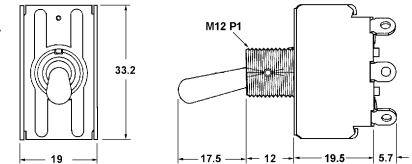


NKK **AS NOTED**

- 42-444-0** DPDT on-(on) 15A/125VAC (20A/30VDC) **CSA/UL**
 - 42-446-0** DPDT on-off-(on) 15A/125VAC (20A/30VDC) **UL**
 - 42-447-0** DPDT (on)-off-(on) 15A/125VAC (20A/30VDC) **UL**
 - 42-630-0** DPST on-off 25A/125VAC (25A/30VDC) **CSA**
 - 42-643-0** DPDT on-on 25A/125VAC (25A/30VDC) **CSA**
 - 42-645-0** DPDT on-off-on 25A/125VAC (25A/30VDC) **CSA**
- Use -1 for Display Package*

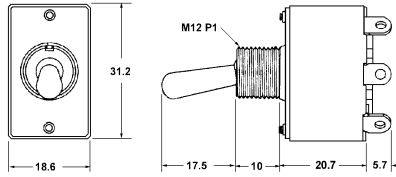

NKK **AS NOTED**

- 42-340-0** DPDT on-on 10A/125VAC (10A/30VDC) **CSA/UL**
 - 42-543-0** DPDT on-on 20A/125VAC (20A/30VDC) **CSA/UL**
 - 42-545-0** DPDT on-off-on 20A/125VAC (20A/30VDC) **CSA**
- Use -1 for Display Package*

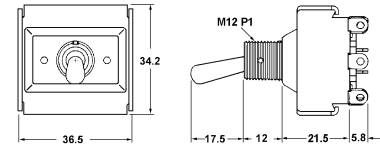


NKK

- 42-683-0** 4PDT on-on 25A/125VAC (20A/30VDC)
 - 42-685-0** 4PDT on-off-on 25A/125VAC (20A/30VDC)
- Use -1 for Display Package*




() Denotes momentary contact

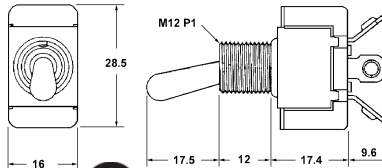

NKK **AS NOTED**
15A/125V 6A/250VAC(20A/30VDC)

- 42-410-0** SPST on-off **CSA/UL**
 - 42-424-0** SPDT on-(on) **CSA/UL**
 - 42-425B-0** SPDT on-off-on **CSA/UL**
 - 42-426-0** SPDT on-off-(on) **CSA**
 - 42-427-0** SPDT (on)-off-(on) **CSA**
- Use -1 for Display Package*

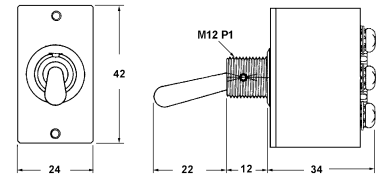

NKK

- 42-745-0** DPDT on-off-on 30A/125VAC(30A/30VDC)
- Use -1 for Display Package*

SWITCH ACCESSORIES

WATERPROOF BOOTS



For M12 P1 thread



For M12 P0.75 thread

- 42-900-0** Bulk
- 42-900-1** Pkg.

- 42-900T-0** Bulk
- 42-900T-1** Pkg.

SWITCH PLATE



On-off switchplate for M12 barrel


- 42-901-0** Bulk

RED TOGGLE GUARD



Safety Cover for toggle switch. 12mm mounting size.

- 42-903-0** Bulk
- 42-903-1** Pkg.

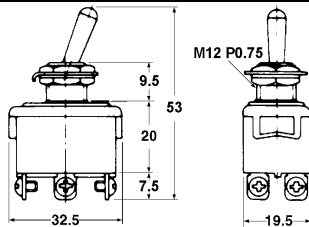


Rating: 15A/125V 10A/250V screw terminals

- 42-413-0** SPDT on-on
 - 42-415-0** SPDT on-off-on
 - 42-423-0** DPDT on-on
 - 42-425-0** DPDT on-off-on
- Use -1 for Display Package*



NKK

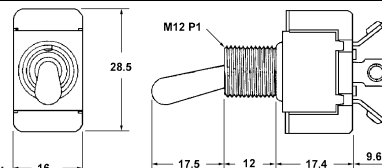

15A/125V 6A/250VAC (20A/30VDC) screw terminals

- 42-424S-0** SPDT on-(on) **CSA/UL**
 - 42-425S-0** SPDT on-off-on **CSA**
 - 42-427S-0** SPDT (on)-off-(on) **CSA**
- Use -1 for Display Package*