



# NAN (M8) Series Field Wireable Plugs

3 & 4 Conductor NAN Series Field Wireable Plugs, 22-24AWG




Field Wireable Plugs | Screw Terminals | 30V, 3 amps | IP67 Rating




Male Faceview	# of Poles	Wire AWG Rating	Cable O.D. Range	Male Plugs	Female Plugs
<p>M8 x 1</p>	<b>3</b>	20-26 AWG 30V 3A	3-5 mm	NAN-T-3MP-FW-ST	NAN-T-3FP-FW-ST
<p>M8 x 1</p>	<b>4</b>	20-26 AWG 30V 3A	3-5 mm	NAN-T-4MP-FW-ST	NAN-T-4FP-FW-ST

### Specifications:

- Body: Polyamide
- Insulator: Polyamide
- Contacts: Copper Alloy with Gold Plating
- O-Ring: NBR
- Coupling Nut: Nickel Plated Brass
- Grommet: NBR
- Connections: Screw Terminals
- Temperature: -40°C to +85°C (-40°F to +185°F)

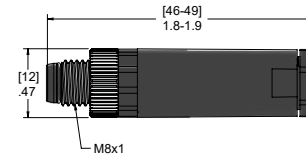

**Male Plug**

 

**Female Plug**

J

NAN (M8) Series